

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300270052

Status:

Active

Overview:


DeviceNet Solutions

Description:

Micro-Change (M12) Single-Ended Cordset, 5 Poles, Female (Straight) to Pigtail, 22 AWG, Gray DeviceNet Cable Plus Drain, 5.0m (16.40') Length

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	130027
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	DeviceNet Solutions
Product Name	DeviceNet, Micro-Change (M12)
Protocol	N/A
Region	Europe
Type	Single Ended
UPC	78678830007
Physical	
Cable Diameter	7.24mm (.285")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Gray
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	TPE
Material - Coupling Nut	Die-Cast Zinc
Material - O-Ring	Nitrile Rubber
Material - Plating Mating	Gold
Net Weight	123.910/g
Orientation	Straight to Pigtail
Poles	5
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	22
Wire/Cable Type	Thin (Drop)
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	DND20A-M050
Reference - Drawing Numbers	
Sales Drawing	SD-130027-007-001

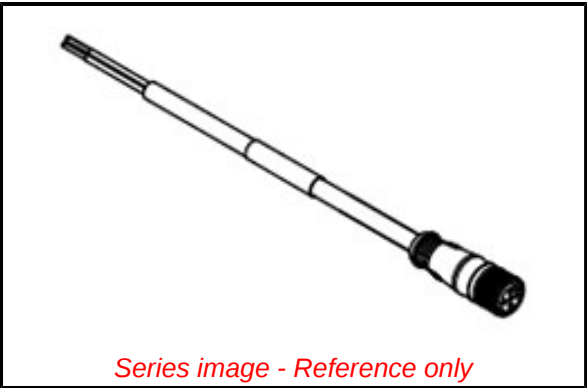

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China RoHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

ZZCERT_CE -

CER_4000380987_00_000.pdf

Declaration of

Conformity

Search Parts in this Series

130027 Series

This document was generated on 02/04/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1300270052](#)