

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2002771108](#)
Status: **Active**
Overview: [Nano-Fit Power Connectors](#)
Description: Nano-Fit Plug Housing, TPA Capable, 2.50mm Pitch, Single Row, 8 Circuits, Black, Glow-Wire Capable

Documents:

3D Model	Packaging Specification 2002771000-PK-000 (PDF)
Drawing (PDF)	Datasheet (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification 2014471000-PS-000 (PDF)	

Agency Certification

CSA LR19980

General

Product Family	Crimp Housings
Series	200277
Application	Power, Wire-to-Wire
Overview	Nano-Fit Power Connectors
Product Name	Nano-Fit
UPC	191130030163


Physical

Circuits (maximum)	8
Color - Resin	Black
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1.112/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Pitch - Termination Interface	2.50mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C, -40° to +115°C

Material Info

Reference - Drawing Numbers

Packaging Specification	2002771000-PK-000
Product Specification	2014471000-PS-000
Sales Drawing	2002771000-SD-000

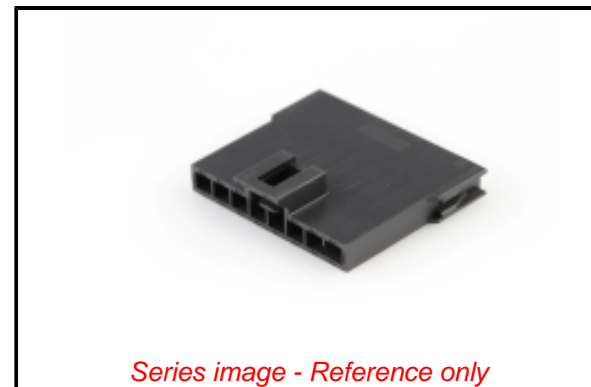

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[200277 Series](#)

Mates With

Nano-Fit Receptacle Housing [1053071208](#)
 . Nano-Fit Cable Assembly [1451300800](#) ,
[1451300801](#) , [1451300803](#) , [1451300810](#)

Use With

Nano-Fit Crimp Terminal [201447](#)

 Nano-Fit TPA Retainer [105325](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[200277-1108](#)