

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 5010834010
Status: Active
Overview: Micro IDT Coaxial Connectors
Description: 0.40mm Pitch Wire-to-Board PCB Receptacle, Vertical, 40 Circuits

Documents:

[3D Model](#) [Product Specification PS-501083-001-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

Product Family PCB Receptacles
Series 501083
Application Signal, Wire-to-Board
Overview Micro IDT Coaxial Connectors
Product Name Micro IDT Coaxial Cable Jumper
UPC 822348337361

Physical

Circuits (Loaded) 40
Circuits (maximum) 40
Color - Resin Black
Durability (mating cycles max) 10
Glow-Wire Capable No
Lock to Mating Part Yes
Material - Metal Phosphor Bronze, Stainless Steel
Material - Plating Mating Gold
Material - Plating Termination Gold
Material - Resin High Temperature Thermoplastic
Net Weight 168.214/mg
Number of Rows 1
Orientation Vertical
PCB Locator No
PCB Retention Yes
Packaging Type Embossed Tape on Reel
Pitch - Mating Interface 0.40mm
Polarized to Mating Part Yes
Polarized to PCB Yes
Temperature Range - Operating -30° to +75°C
Termination Interface: Style Surface Mount


Electrical

Current - Maximum per Contact 0.2A
Voltage - Maximum 30V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Product Specification PS-501083-001-001
Sales Drawing SD-501083-001, SD-501083-002

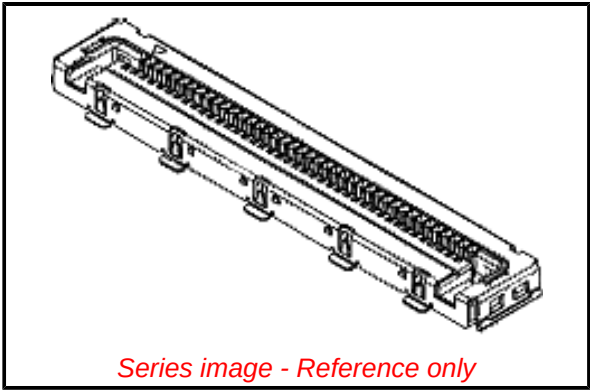

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ECHA_01_2020 (16
January 2020

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

501083 Series

Mates With

Contact Molex for mating plug harness details

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

501083-4010