


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010231](#)
Status: **Active**
Overview: [GWconnect Heavy Duty Connectors \(HDC\)](#)
Description: GWconnect Screw Terminal Insert, Female, 10-Pole, 16A, with Wire Protection, Silver (Ag) Plated Contacts, Size 10B «57x27»

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification		
CSA		256883
UL		E249674
General		
Product Family		Industrial Connectors / Enclosures
Series		93601
Component Size		10B «57X27»
Component Type		Inserts - Screw Terminal
Insert Series		S-E
Overview		GWconnect Heavy Duty Connectors (HDC)
Product Category		Heavy Duty Connectors
Product Name		GWconnect
Standard		CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
UPC		887191877891
Physical		
Durability (mating cycles max)		700
Flammability		UL 94V-0
Gender		Female
Insert Color		Grey
Material - Contact		Copper Alloy
Material - Insert		Polycarbonate
Material - Plating		Silver
Net Weight		63.000/g
Number of Rows		2
Packaging Type		Bag
Polarized to Mating Part		Yes
Poles		10
Stripping Length		7.00mm
Temperature Range - Operating		-40° to +125°C
Tightening Test Torque		0.50 Nm
Wire Size AWG		14-20
Wire Size mm²		0.50-2.50
Electrical		
Current - Maximum per Contact		16.0A
Voltage - Maximum		500V
Wire Protection		Yes
Material Info		
Engineering Number		7310.6004.0

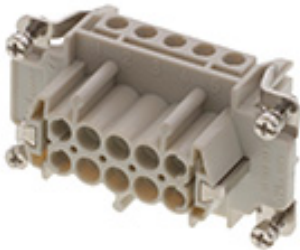

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Contained Per - D(2021)4569-DC (8 July 2021) Lead Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[93601](#) Series

Mates With
[936010238](#) Male Screw Terminal Insert

Use With
Size 10B «57x27» Hoods and Housings

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0231](#)