

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300240180

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change Single-Ended Cordset, 5 Poles, Female (90°) to Pigtail, 16 & 20 AWG, DeviceNet Mid Cable, 5.0m (16.40') Length

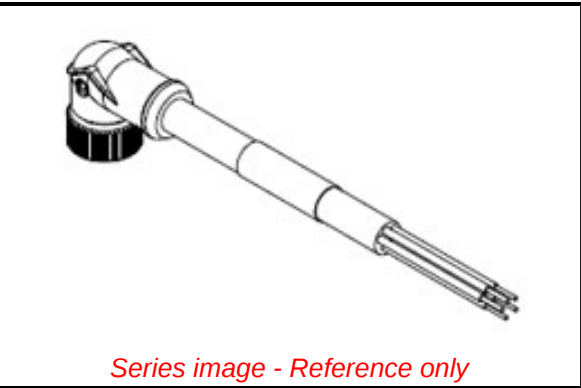

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
General	
Product Family	Industrial Cordsets
Series	130024
Connector End A	Mini-Change
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Brass
Overview	Brad Mini-Change Connectors
Product Name	DeviceNet Trunk, Mini-Change
Region	Europe
Type	Single Ended
UPC	78678890208
Physical	
Cable Diameter	8.38mm (.330")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Gray
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PVC
Material - Coupling Nut	Die-Cast Zinc
Material - Plating Mating	Gold
Orientation	90° to Pigtail
Poles	5
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	16, 20
Wire/Cable Type	Mid Cable
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	300V AC/DC
Material Info	
Engineering Number	DNB90A-M050
Reference - Drawing Numbers	
Sales Drawing	SD-130024-006

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

130024 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300240180