

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300500507](#)
Status: **Active**
Overview: [Brad Industrial Ethernet Solutions](#)
Description: Brad RJ-Lnxx RJ-45 Double-Ended Cordset, 8 Poles, Male (Straight) to Male (Straight), 24 AWG, PVC Cable, 1.0m (3.28') Length

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General	
Product Family	Industrial Cordsets
Series	130050
Connector End A	RJ-45 (standard)
Connector End B	RJ-45 (standard)
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Brad, RJ-Lnxx
Protocol	N/A
Region	America, Asia, Europe
Type	Double Ended
UPC	78172504467

Physical	
Cable Diameter	6.35mm (.250")
Cable Length	1.0m (3.28')
Color - Cable Jacket	Black
Coupling Style	N/A
Gender	Male-Male
Keyway	None
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PVC
Material - Coupling Nut	N/A
Material - Plating Mating	N/A
Orientation	Straight to Straight
Poles	8
Temperature Range - Operating	-10°C to +60°C
Wire Size AWG	24
Wire/Cable Type	Unshielded-Twisted Pair

Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	30V

Material Info	
Engineering Number	ENQ3335M010

Reference - Drawing Numbers	
Sales Drawing	SD-130050-007

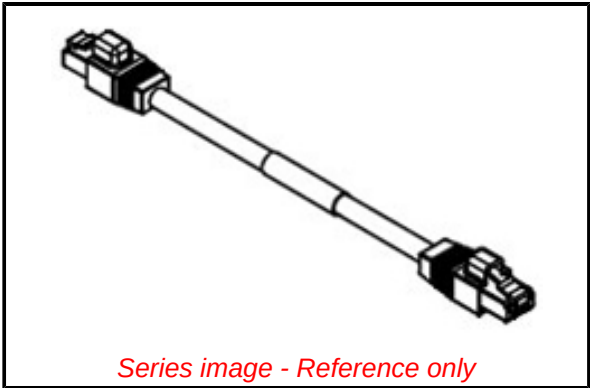

EU ELV
Not Reviewed

EU RoHS Not Reviewed	China RoHS
REACH SVHC Not Reviewed	
Halogen-Free Status Not Reviewed	

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[130050](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300500507