

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300500336

Status:


Active

Overview:

Brad Industrial Ethernet Solutions

Description:

Brad RJ-Lnxx Industrial RJ-45 Double-Ended Cordset, 8 Poles, Male (Straight) to Male (Straight), 24 AWG, PUR Cable, 1.0m (3.28') Length

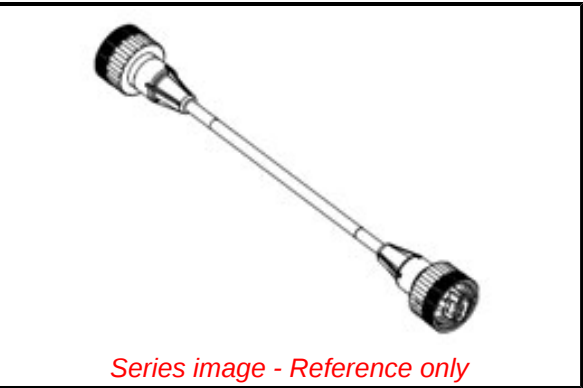

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Industrial Cordsets
Series	130050
Connector End A	RJ-45 (industrial)
Connector End B	RJ-45 (industrial)
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Brad, RJ-Lnxx
Protocol	N/A
Region	America, Asia, Europe
Type	Double Ended
UPC	78678844387
Physical	
Cable Diameter	6.35mm (.250")
Cable Length	1.0m (3.28')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Male-Male
Keyway	None
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	ABS
Material - Plating Mating	N/A
Orientation	Straight to Straight
Poles	8
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	24
Wire/Cable Type	Shielded-Twisted Pair
Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	30V
Material Info	
Engineering Number	ENS2115M010
Reference - Drawing Numbers	
Sales Drawing	SD-130050-032

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130050 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300500336