



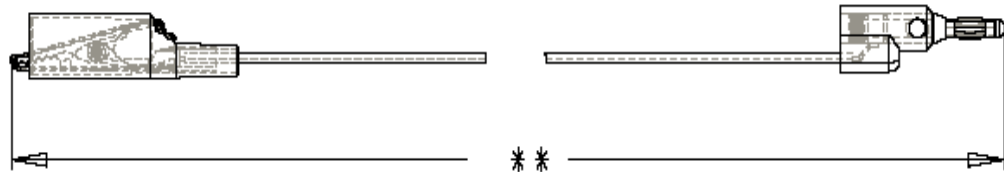

**Part Number:** BU-2030-A-\*\*- \*  
**Description:** Insulated Alligator Clip to Stackable Banana Plug

2607

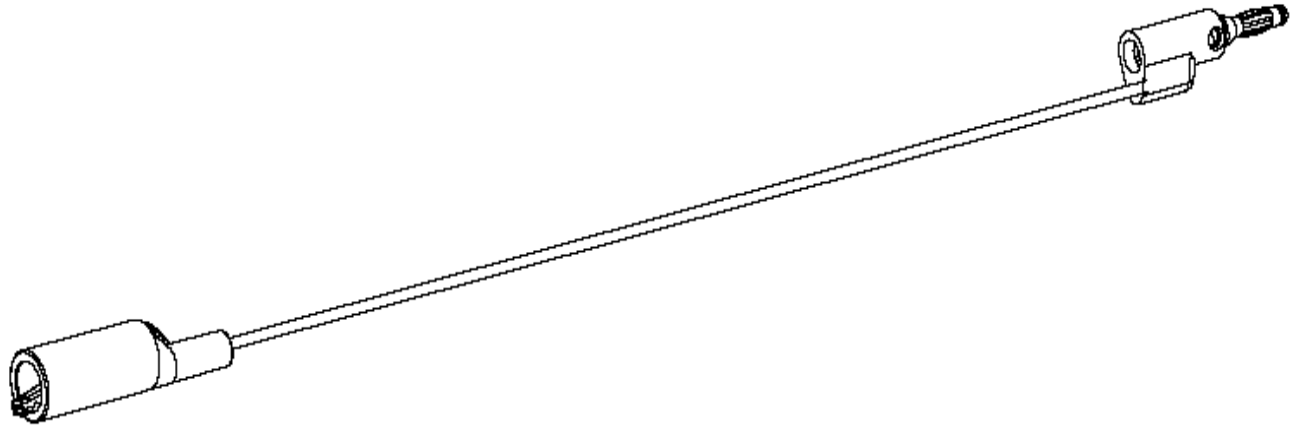

- Insulated Alligator Clip to Stackable Banana Plug
- **Material:** Banana Plug: ABS housing, brass body and beryllium copper, Nickel-plated, nine-leaf cage spring;  
Alligator Clip: Nickel plated steel with PVC insulator  
Hook-up wire: #20(41/36) AWG tinned copper with 105° C PVC insulation
- \*\* Length: -12"(.3m), -24"(.6m), -36"(.9m), -48"(1.2m), -60"(1.5m)
- \*Std Colors: -0 Black -2 Red
- Rating: Hands free testing at 300V Category II, 10 Amps
- RoHS Compliant

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mueller Electric:](#)

[BU-2030-A-60-0](#)