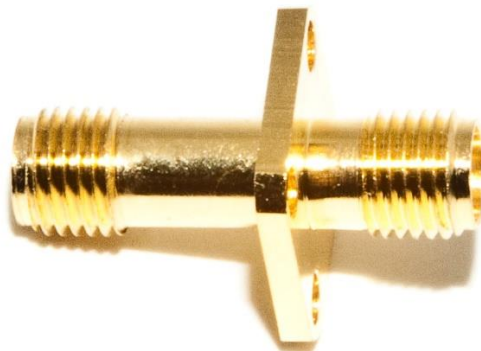


BU-P72973**(SMA Flange Mount Connector, Female to Female)**

- The BU-P72973 is a female to female SMA flange mount connector. High bandwidth and durability for confident connections.
- Overall length 0.87" (22.2mm), overall width 0.5" (12.7mm)
- Holes are spaced 0.34" (8.6mm) center-to-center.
- Material:

Body	Gold-plated brass
Contacts	Gold-plated beryllium copper
Insulator	PTFE
- Rating:

Frequency Range	0 to 18 GHz
Voltage	Hands-free testing to 500 VRMS Max.
Impedance	50 Ohms
Temperature	-50°C (-58°F) to 105°C (221°F)
- RoHS 3 compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mueller Electric:](#)

[BU-P72973](#)