


C4C10UXXX

(M12 Cordset, 4 Position, 22 AWG Unshielded Female Straight to Free End)

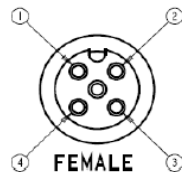

Pin Out		
End 1	Color	End 2
1	Brown	Free End
2	White	
3	Blue	
4	Black	

- Mueller's C4C10UXXX is an unshielded, M12 4-pin single ended instrumentation cable with a straight female connector on one end and free at the other.
- Keyway – A Coding
- Utilizes a 4-conductor 22 AWG, PVC-insulated, unshielded cable.
- Ratings:
 - Current: 4 A
 - Voltage: 250 V AC/DC
- Material:
 - Coupling Nuts – Nickel Plated Brass
 - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mueller Electric:](#)

[C4C10M006](#) [C4C10M003](#) [C4C10M001](#) [C4C10M002](#) [C4C10M020](#) [C4C10M008](#) [C4C10M000.5](#) [C4C10M010](#)
[C4C10M015](#)