


C5BC06UXXX

(M12 Cordset, 5 Position, 22 AWG Shielded, Male Right Angle to Female Straight)

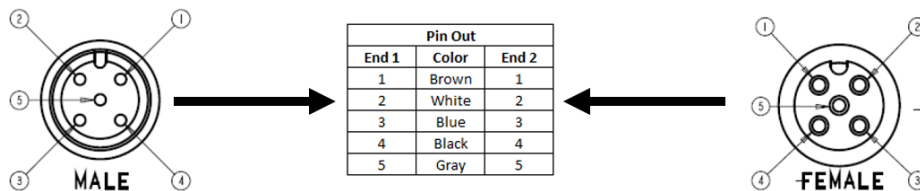

- Mueller's C5BC06UXXX is an M12 5-pin double ended, shielded instrumentation cable with a right angle male connector on one end and a straight female at the other.
- Keyway – A Coding
- Utilizes our 5-conductor 22 AWG PVC-insulated, shielded cable.
- Ratings:
 - Current: 4 A
 - Voltage: 250 V AC/DC
- Material:
 - Coupling Nuts – Nickel Plated Brass
 - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mueller Electric:](#)

[C5BC06M010](#) [C5BC06M005](#)