


C84A02UXXX

(M8 Cordset, 4 Position, 24 AWG Unshielded PVC, Male Straight to Open End)



MALE FACE VIEW

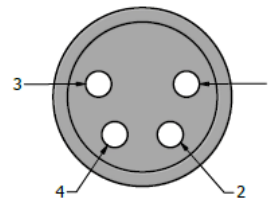

1 → BROWN
2 → WHITE
3 → BLUE
4 → BLACK

- Mueller's C84A02UXXX is an M8 4-pin single ended, unshielded instrumentation cable with a straight male connector on one end and an open stripped end on the other.
- Keyway – A Coding
- Utilizes a 4-conductor 24 AWG PVC-insulated, black cable.
- Ratings:
 - Current: 3 A
 - Voltage: 30 V AC/DC
- Material:
 - Coupling Nuts – Nickel Plated Brass
 - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mueller Electric:](#)

[C84A02M002](#) [C84A02M001](#)