


C8AC13UXXX

(M12 Cordset, 8 Position, 24 AWG Shielded, Male Straight to Female Straight)




MALE FACE VIEW

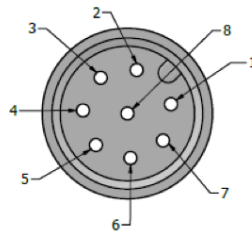

1 → WHITE
2 → BROWN
3 → GREEN
4 → YELLOW
5 → GRAY
6 → PINK
7 → BLUE
8 → RED

FEMALE FACE VIEW

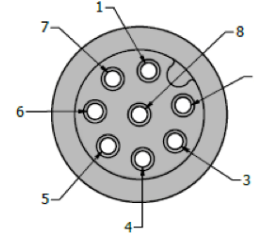

1 → WHITE
2 → BROWN
3 → GREEN
4 → YELLOW
5 → GRAY
6 → PINK
7 → BLUE
8 → RED

- Mueller's C8AC13UXXX is an M12 8-pin double ended, shielded instrumentation cable with a straight male connector on one end and a straight female connector on the other.
- Keyway – A Coding
- Utilizes an 8-conductor 24 AWG PVC-insulated, shielded cable.
- Ratings:
 - Current: 2 A
 - Voltage: 30 V AC/DC
- Material:
 - Coupling Nuts – Nickel Plated Brass
 - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mueller Electric:](#)

[C8AC13M010](#)