

SPADE TERMINAL SELECTION GUIDE



BU-191420007



BU-191440020




BU-191640071

- Mueller offers a wide range of spade terminals that are suitable for a variety of applications.
- 3 different wire ranges
 - 12-10AWG
 - 16-14AWG
 - 22-18AWG
- 3 stud sizes
 - #6
 - #8
 - #10
- 3 different insulation styles
 - Nyax heat shrink
 - Nylon
 - Vinyl
- Temperature Rating
 - 75°C Nylon and Vinyl insulated
 - 125°C Nyax insulated
- Rated Voltage: 600V
- Single crimp terminals
- Solid or stranded wire accepted
- Recommended strip length: 1/4"
- All spade terminals are UL and CSE listed except the Nyax heat shrink insulated spades.
 - UL Listed, investigated to UL 486 A-B, File NO. ZMVB.E68376
 - CSA 22.2 No. 65-03, Certification NO. 207131

12-10AWG SPADE TERMINALS

PART NUMBER	AWG SIZE	STUD SIZE	INSULATION MATERIAL	BARREL LENGTH	LENGTH	W	STUD DIAMETER (SD)	F
BU-191640071	12-10	#10	NYAX HEAT SHRINK	.250	1.16	.370	.206	.294
AI-50270N	12-10	#6	NYLON	.250	1.02	.350	.149	.294
AI-50280N	12-10	#8	NYLON	.250	1.020	.350	.175	.294
AI-50290N	12-10	#10	NYLON	.250	1.020	.370	.203	.294
BU-191440037	12-10	#6	VINYL	.250	1.020	.350	.149	.294
BU-191440039	12-10	#8	VINYL	.250	1.020	.350	.175	.294
BU-191440042	12-10	#10	VINYL	.250	1.020	.370	.203	.294

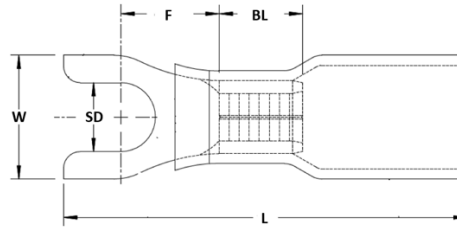


MATERIAL:
 110 COPPER ALLOY 0.038 THICK
 ELECTRO-TIN PLATED .00025"-.0004"

*ALL DIMENSIONS ARE IN INCHES **CELL COLOR DEPICTS INSULATION COLOR

16-14AWG SPADE TERMINALS

PART NUMBER	AWG SIZE	STUD SIZE	INSULATION MATERIAL	BARREL LENGTH	LENGTH	W	STUD DIAMETER (SD)	F
BU-191640029	16-14	#8	NYAX HEAT SHRINK	.250	1.250	.344	.175	.303
BU-191640030	16-14	#10	NYAX HEAT SHRINK	.250	1.170	.344	.206	.303
AI-50140N	16-14	#6	NYLON	.250	.930	.250	.150	.303
AI-50150N	16-14	#8	NYLON	.250	.950	.344	.175	.303
AI-50160N	16-14	#10	NYLON	.250	.950	.344	.205	.303
BU-191440015	16-14	#6	VINYL	.250	.930	.250	.150	.303
BU-191440020	16-14	#8	VINYL	.250	.950	.344	.175	.303
BU-191440026	16-14	#10	VINYL	.250	.950	.344	.205	.303

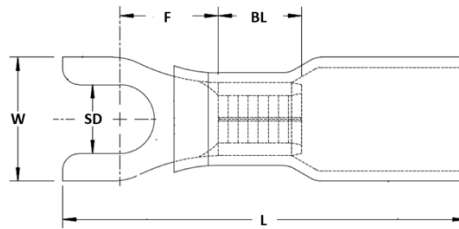


MATERIAL:
110 COPPER ALLOY 0.03 THICK
ELECTRO-TIN PLATED .0001"-.0003"

*ALL DIMENSIONS ARE IN INCHES **CELL COLOR DEPICTS INSULATION COLOR

22-18AWG SPADE TERMINALS

PART NUMBER	AWG SIZE	STUD SIZE	INSULATION MATERIAL	BARREL LENGTH	LENGTH	W	STUD DIAMETER (SD)	F
BU-191640007	22-18	#8	NYAX HEAT SHRINK	.250	1.240	.312	.175	.322
BU-191640008	22-18	#10	NYAX HEAT SHRINK	.250	1.180	.312	.203	.320
AI-50050N	22-18	#6	NYLON	.250	.950	.250	.149	.321
AI-50060N	22-18	#8	NYLON	.250	.950	.312	.175	.321
AI-50070N	22-18	#10	NYLON	.250	.950	.312	.203	.321
BU-191420003	22-18	#6	VINYL	.250	.950	.250	.149	.321
BU-191420005	22-18	#8	VINYL	.250	.950	.312	.175	.321
BU-191420007	22-18	#10	VINYL	.250	.950	.312	.203	.321

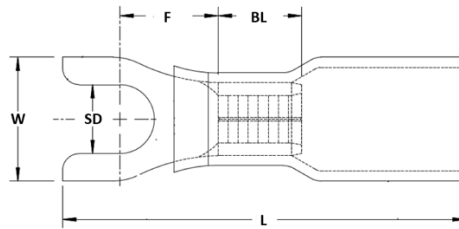

MATERIAL:
110 COPPER ALLOY 0.028 THICK
ELECTRO-TIN PLATED .0001"-.0003"

*ALL DIMENSIONS ARE IN INCHES **CELL COLOR DEPICTS INSULATION COLOR

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mueller Electric:

[AI-50290N](#) [AI-50150N](#) [AI-50050N](#) [BU-191640029](#) [BU-191640007](#) [BU-191440026](#) [AI-50060N](#) [AI-50160N](#) [BU-191440042](#) [BU-191440015](#) [BU-191420005](#) [BU-191440037](#) [AI-50280N](#) [AI-50270N](#) [BU-191440039](#) [BU-191440020](#)
[AI-50140N](#) [BU-191420003](#) [BU-191640030](#) [AI-50070N](#) [BU-191640008](#) [BU-191640071](#) [BU-191420007](#)