




Part Number: BU-1120-A-**- *
Description: Mini-plunger to Stackable
Banana Plug

2607

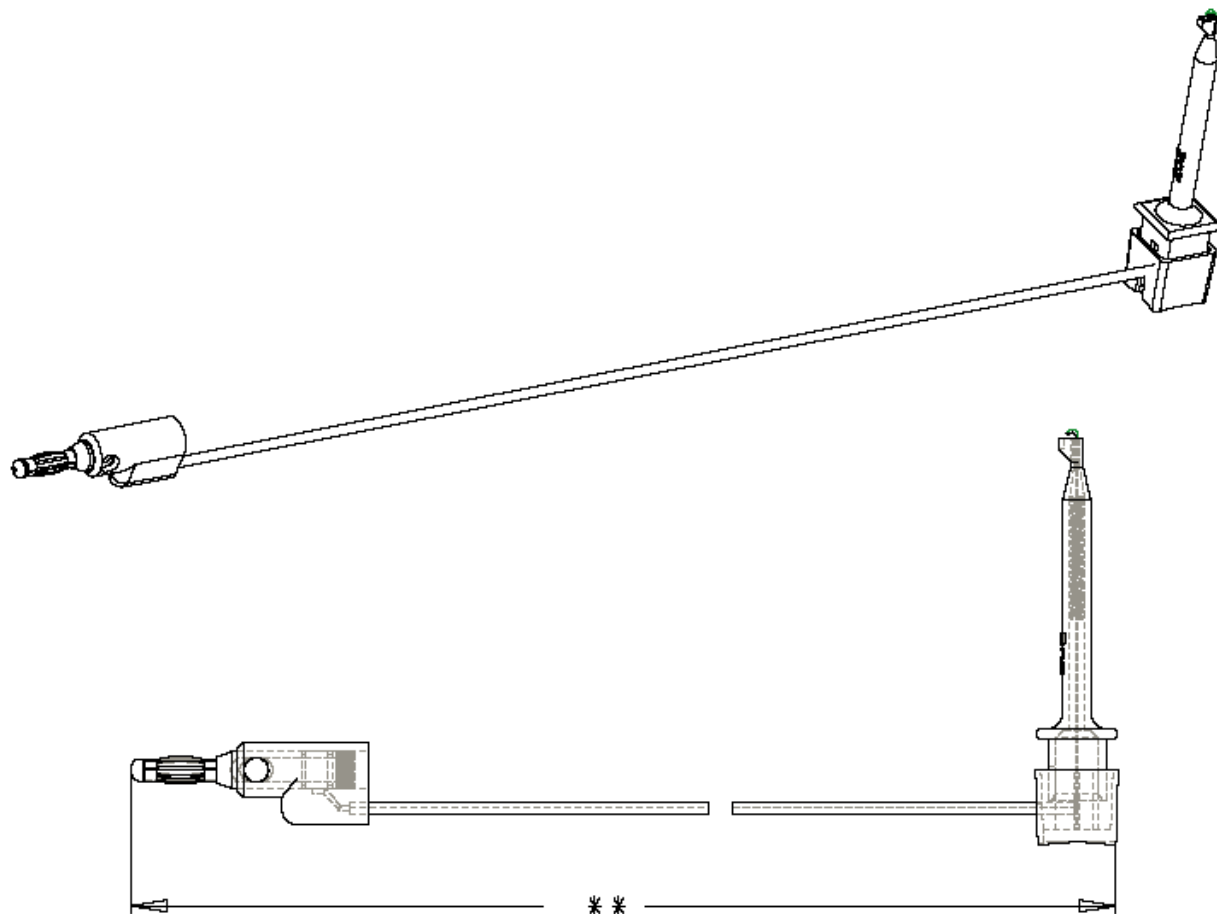

- Mini-plunger to Stackable Banana Plug
- Material: Banana Plug: ABS housing, brass body and beryllium copper, Nickel-plated, nine-leaf cage spring;
Hook-up wire: #20(41/36) AWG tinned copper with 105° C PVC insulation; Plunger: Nylon housing; Stainless steel spring Beryllium copper contact
- ** Length: -12"(.3m), 24"(.6m), -36"(.9m), -48"(1.2m), -60"(1.5m)
- *Std Colors: -0 Black -2 Red
- Rating: Hands free testing at 300V Category II, 5 Amps
- RoHS Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mueller Electric:](#)

[BU-1120-A-24-0](#) [BU-1120-A-24-2](#) [BU-1120-A-12-0](#) [BU-1120-A-12-2](#) [BU-1120-A-60-0](#) [BU-1120-A-60-2](#) [BU-1120-A-48-0](#) [BU-1120-A-48-2](#) [BU-1120-A-36-0](#) [BU-1120-A-36-2](#)