


SERIES

**4214R
4214**

RoHS
Compliant
Traditional
First Quality

Wound Beads

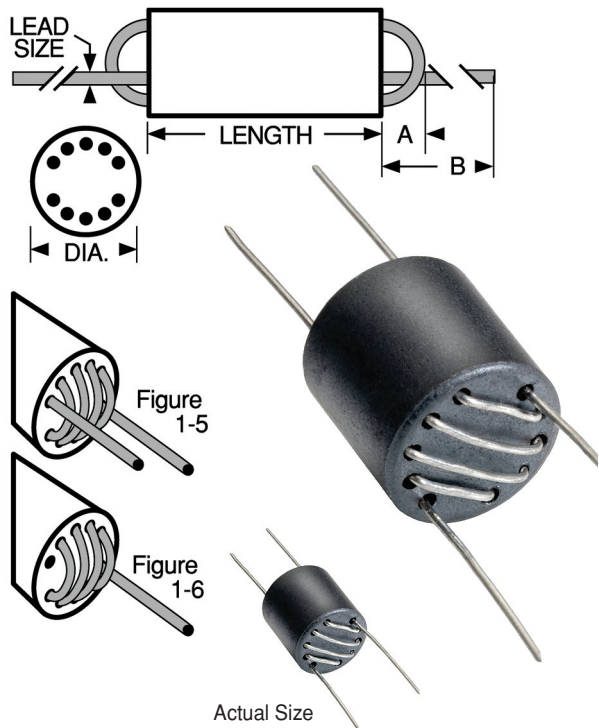

DASH NUMBER*	FIGURE	TURNS	MINIMUM IMPEDANCE					Supply
			10 MHz	50 MHz	100 MHz	150 MHz	200 MHz	
			SERIES 4214R / 4214					
-2	1-5	2 1/2 x2	370	590	450	350	280	
-4	1-6	4 1/2	700	1100	650	350	270	

*Complete part # must include series # PLUS the dash #

For surface finish information, refer to www.delevanfinishes.com

Wide Band Chokes 10 hole ferrite slugs, made in API-2 Material, with 2 x 2.5 or 4.5 turns of tinned copper wire.

Applications Interference suppression

Physical Parameters

	Inches	Millimeters
Length	0.388 to 0.402	9.98 to 10.02
Diameter	0.388 to 0.402	9.98 to 10.02
Lead Size		
AWG #24 TCW	0.0185 to 0.0215	0.47 to 0.55
A	0.14 Max.	3.55 Max.
B	1.10 Min.	28.0 Min.


Impedances measured on HP 4191A Impedance Analyzer.

High resistivity ferrite material eliminates the need to insulate windings.

Lead Wire Plated copper

Packaging Bulk only

For more detailed graphs, contact factory

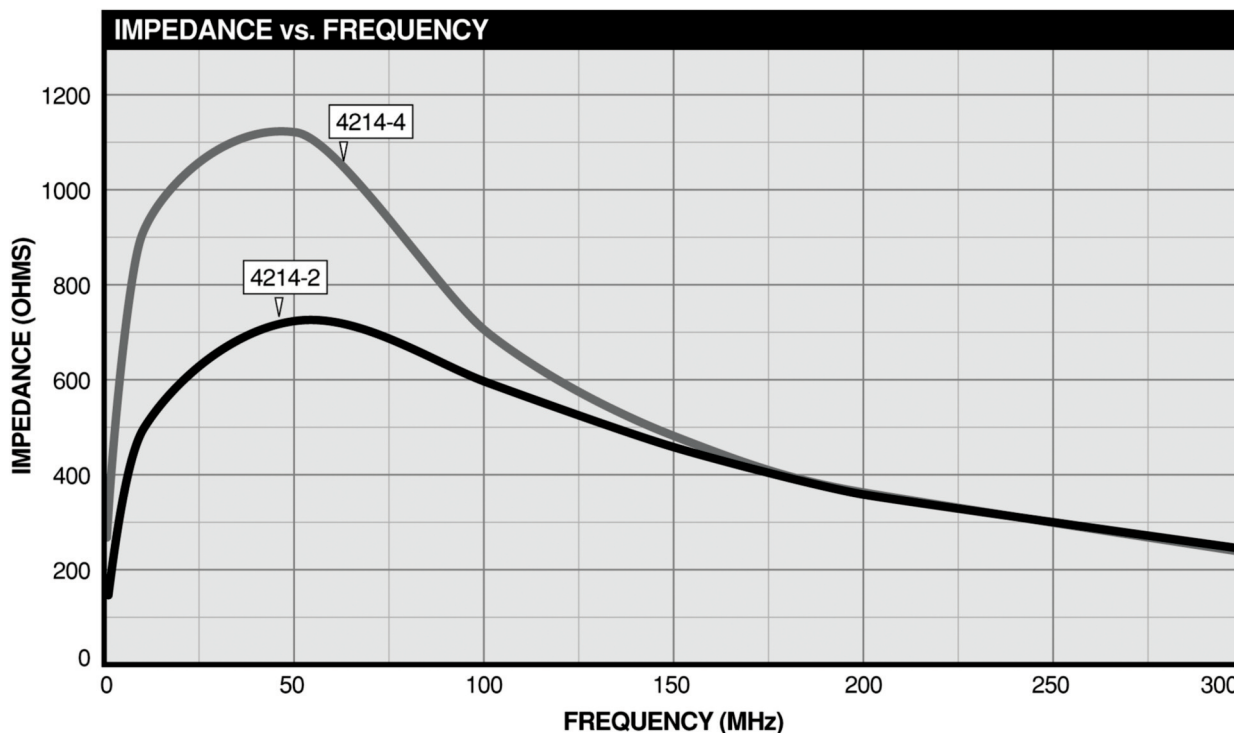

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[API Delevan:](#)

[4214-4](#)