


935242521437-xxT

In Production

Recommended



Appearance & Shape

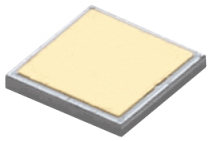

Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

935242521437-xxT



Specifications

Series	WBSC
Applications	Power Amp for RF, Automotive
Mounting Method	Wire-bonding vertical
Operating Temperature Range	-55°C to 150°C
Size Code (in inch)	02065
L x W (size)	0.50 x 1.624mm
Breakdown Voltage (For the rated voltage, please see the FAQ.)	150Vdc
Capacitance	3.7nF
Thickness	250μm

Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Murata:

[935242521437-T3T](#)