
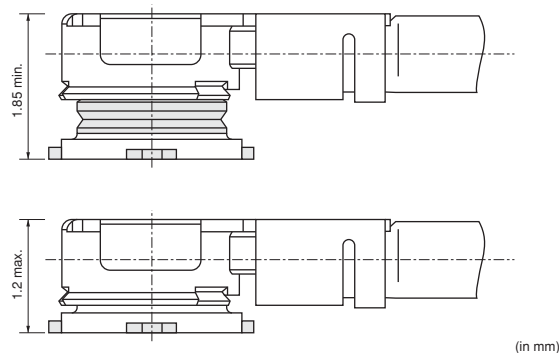


Microwave Coaxial Connectors

muRata



Coaxial Cable Connectors

MM4829-2702

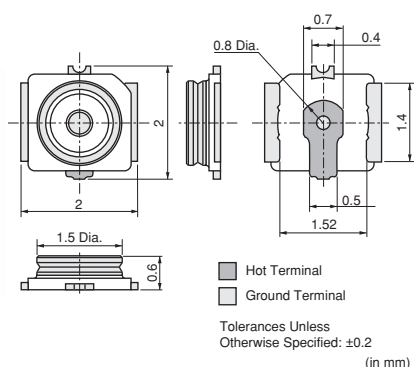



Dimensions

MM5829-2700

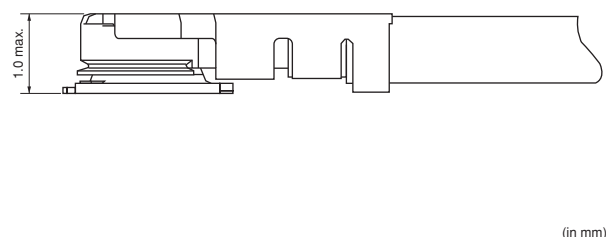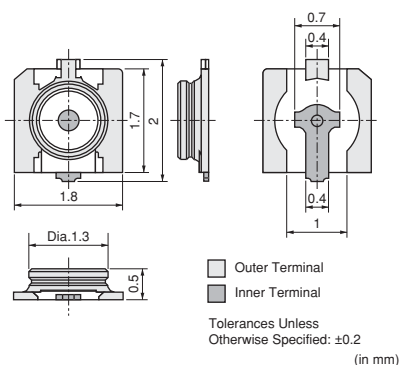

Dimensions

MM9329-2700

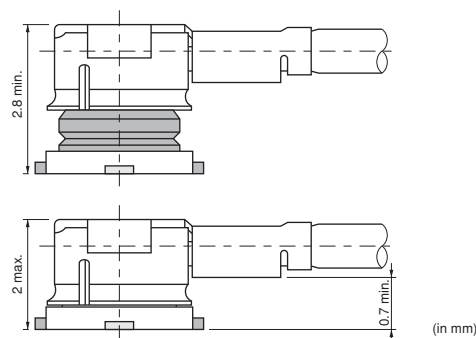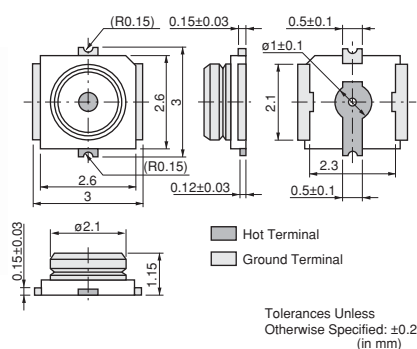

Dimensions

Part Number	Rated Voltage (Vrms)	Frequency Rating (GHz)	Temperature Range	VSWR
MM4829-2702	30	to 6.0	-40 to +85°C	1.3 max. (DC to 3GHz)
MM5829-2700	30	to 12	-40 to +85°C	1.3 max. (DC to 3GHz)
MM9329-2700	30	to 6.0	-40 to +90°C	1.2 max. (DC to 3GHz)
MXHP32	30	to 6.0	-40 to +85°C	1.3 max.(DC to 3GHz)
MXJA01	30	to 12	-40 to +85°C	1.3 max.(DC to 3GHz)
MXTK92	30	to 6.0	-40 to +90°C	1.2 max.(DC to 3GHz)


Impedance: 50ohm

Microwave Coaxial Connectors


muRata

Coaxial Connectors with Switch


MM8030-2610

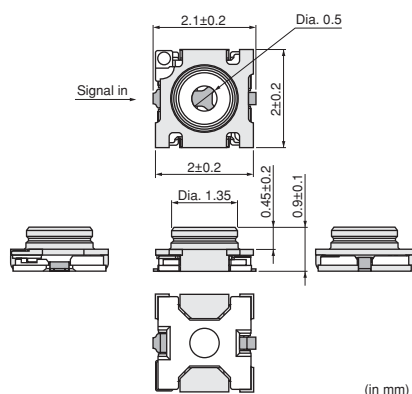


MM8130-2600

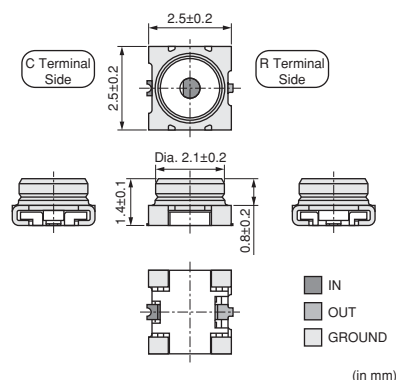


MM8430-2610

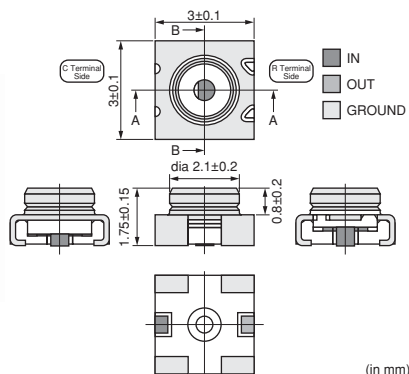


Measurement Probe for MM8030-2610
(P/N: MM126310)

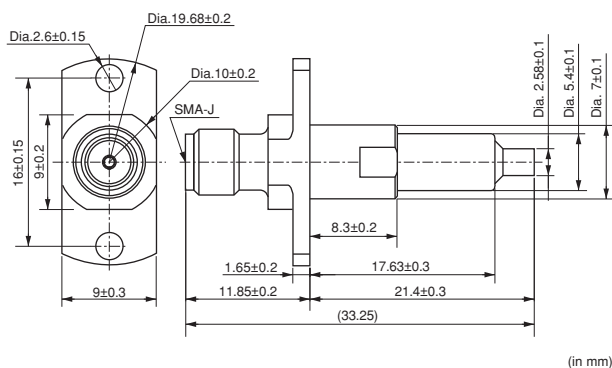


Measurement Probe for MM8030-2610
(P/N: MXHQ87WA3000)

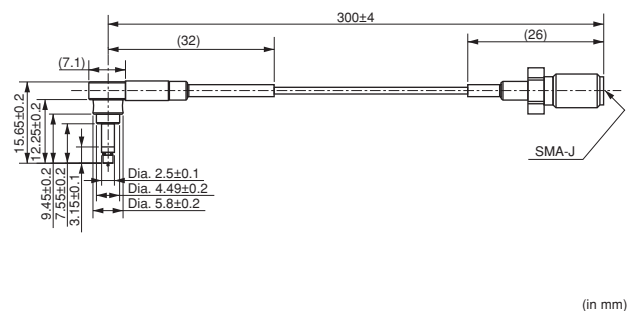


Measurement Probe for MM8130-2600/MM8430-2610
(P/N: MM126036)

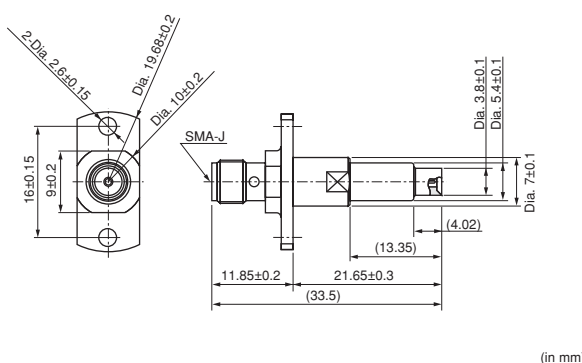


Measurement Probe for MM8130-2600/MM8430-2610
(P/N: MXHS83QE3000)

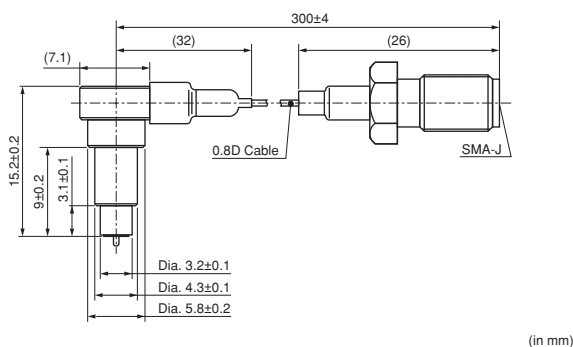

Continued on the following page.

 Continued from the preceding page.

Measurement Probe for MM8130-2600/MM8430-2610
(P/N: MXHS83QH3000)

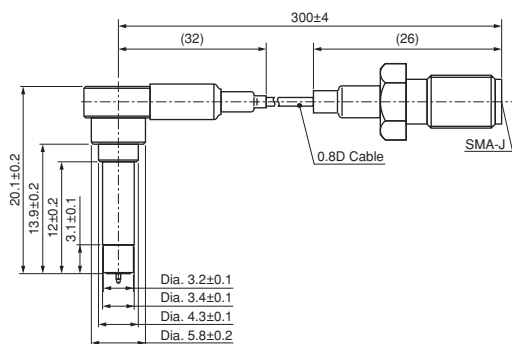

(in mm)

Part Number	Rated Voltage (Vrms)	Frequency Rating (GHz)	Temperature Range	VSWR (1)
MM8030-2610	30	to 11	-40 to +85°C	1.2 max. (DC to 3GHz)
MM8130-2600	30	to 6	-40 to +85°C	1.2 max. (DC to 3GHz)
MM8430-2610	30	to 6	-40 to +85°C	1.2 max.(DC to 3GHz)

Impedance: 50ohm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Murata:

[MM126036](#) [MXHS83QE3000](#) [MM126310](#) [MXHQ87WA3000](#)