



muRata

MM4829-2702

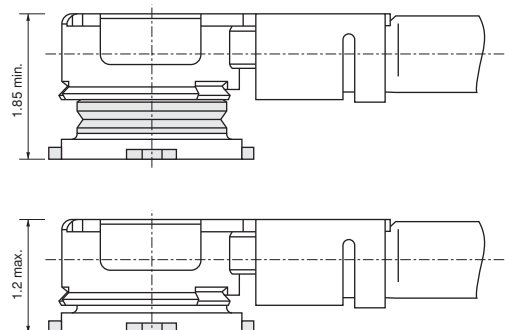


(in mm)

Dimensions

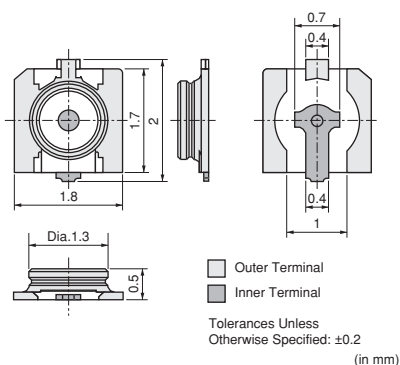

(in mm)

Dimensions

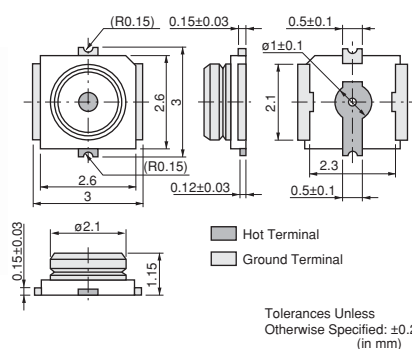

(in mm)

Dimensions


Impedance: 50ohm

Microwave Coaxial Connectors




Coaxial Connectors with Switch

MM8030-2610

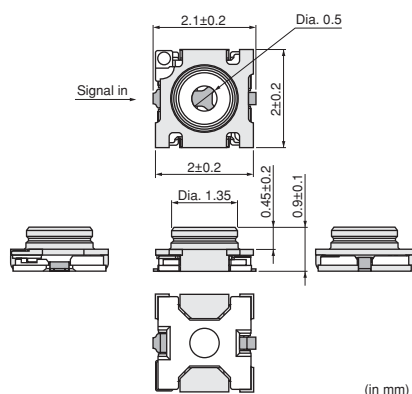


(in mm)

MM8130-2600

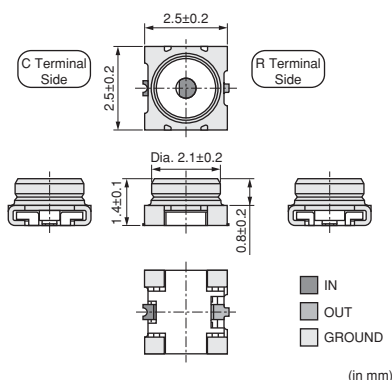


(in mm)

MM8430-2610

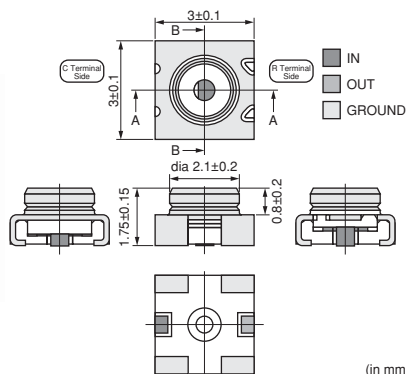


(in mm)

Measurement Probe for MM8030-2610
(P/N: MM126310)

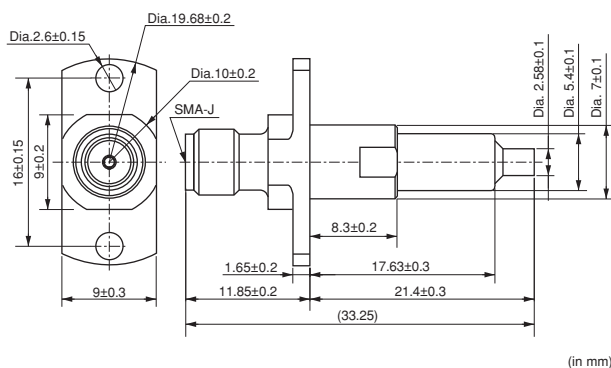


(in mm)

Measurement Probe for MM8030-2610
(P/N: MXHQ87WA3000)

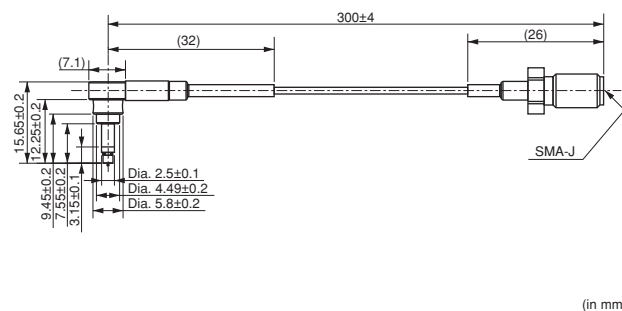


(in mm)

Measurement Probe for MM8130-2600/MM8430-2610
(P/N: MM126036)

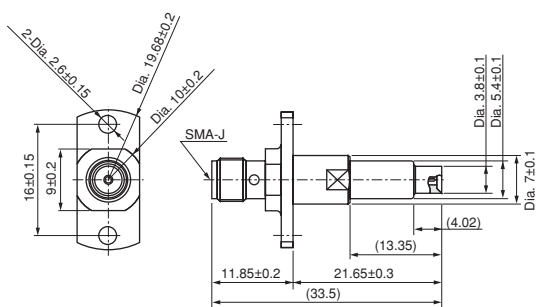


(in mm)

Measurement Probe for MM8130-2600/MM8430-2610
(P/N: MXHS83QE3000)

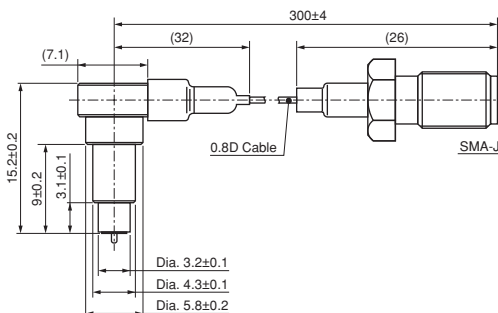


(in mm)

 Continued on the following page.

 Continued from the preceding page.

Measurement Probe for MM8130-2600/MM8430-2610
(P/N: MXHS83QH3000)

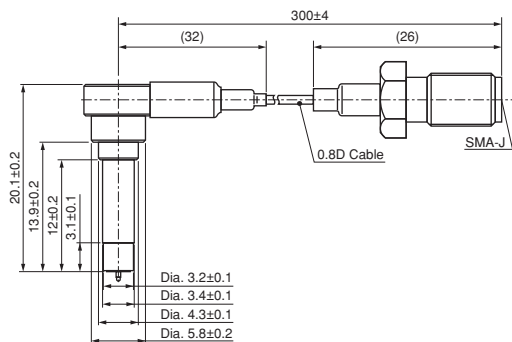

(in mm)

Part Number	Rated Voltage (Vrms)	Frequency Rating (GHz)	Temperature Range	VSWR (1)
MM8030-2610	250	to 11	-40 to +85°C	1.2 max. (DC to 3GHz)
MM8130-2600	250	to 6	-40 to +85°C	1.2 max. (DC to 3GHz)
MM8430-2610	250	to 6	-40 to +85°C	1.2 max.(DC to 3GHz)

Impedance: 50ohm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Murata:

[MM8430-2610RA1](#)