


酸化銀電池
 Silver oxide batteries

SR726

■外形寸法 Dimensions(mm)

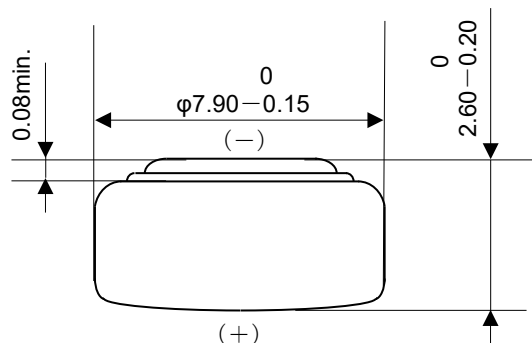


■刻印 Monogram



■定格 Specifications


公称電圧 Nominal Voltage	1.55 V
公称容量 (終止電圧 1.2 V) Nominal Capacity (1.2V cutoff)	35 mAh
標準放電負荷 Standard Discharge Load ※公称電圧/抵抗 Nominal Voltage/Standard Load	22 k Ω ($\approx$ 0.07mA)
標準質量 Weight	0.49 g
使用温度範囲 Operating Temperature	-10 ~ +60°C
水銀使用率 0% No mercury added	

■放電特性 Discharge Characteristics

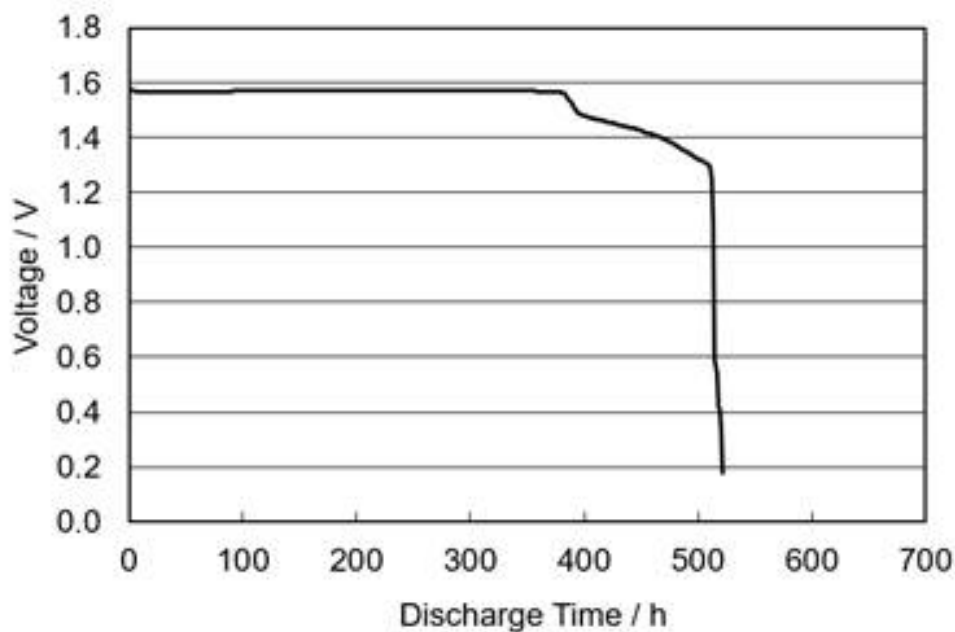 load : 22k Ω temperature: 23°C


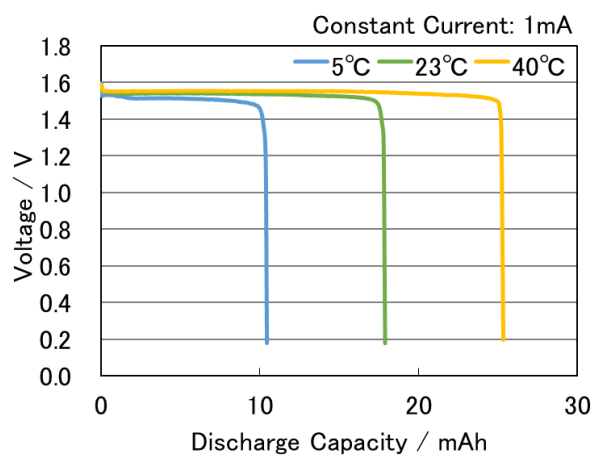
■放電負荷特性

Discharge Characteristics on Load

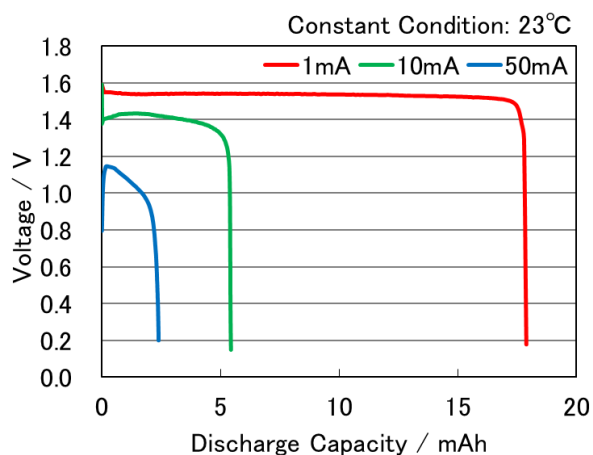


■放電温度特性

Discharge Characteristics by Temperature



■放電負荷と放電容量

Discharge Load vs. Discharge Capacity

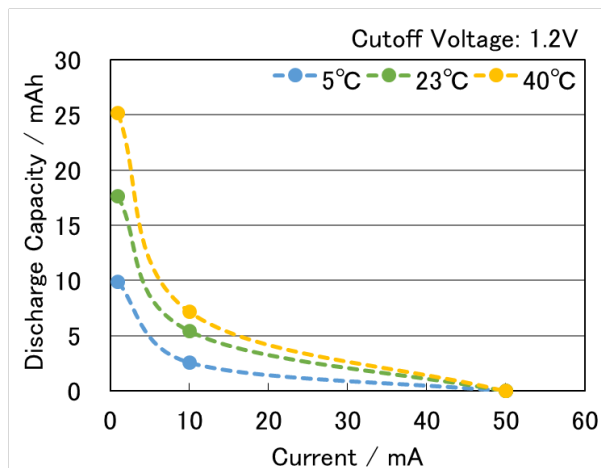

*記載のデータ及び数値は、参考値であり保証値ではありません。

*Data is not guaranteed, and is provided for reference purposes only.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Murata:](#)

[97384753](#)