


# Chip Multilayer Hybrid Dividers



LDD21 Series

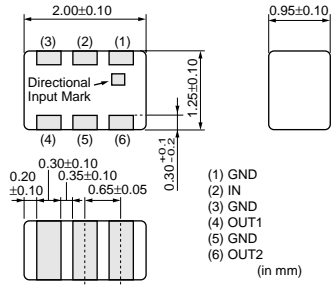

100ohm external resistor is required between Out 1 and Out 2.

All the technical data and information contained herein are subject to change without prior notice.

Part Number	Frequency Range (MHz)	Insertion Loss (OUT1,OUT2) (dB)	Isolation (min.) (dB)	VSWR (max.)	Application
<b>LDD182G4503A-196</b>	2450.0 ±50.0MHz	3.4 ±0.6dB	15.0	1.5	WLAN/BT
<b>LDD211G7503A-067</b>	1750.0 ±30.0MHz	3.4 ±0.4dB	20.0	1.5	CDMA
<b>LDD212G1403A-075</b>	2140.0 ±30.0MHz	3.4 ±0.4dB	22.0	1.5	UMTS(Band1)
<b>LDD21967M03A-068</b>	967.0 ±13.0MHz	3.4 ±0.4dB	20.0	1.4	CDMA

Characteristics Impedance (Nominal): 50ohm    Operating Temperature Range: -40°C to +85°C

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Murata:](#)

[LDD211G3703A-088](#) [LDD211G4003A-087](#) [LDD211G6203A-086](#) [LDD211G6103A-095](#)