


Chip Multilayer Hybrid Couplers

3dB Hybrid

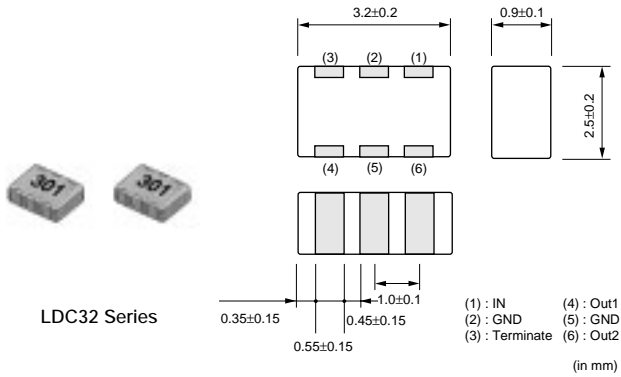

Part Number	Insertion Loss (dB)	Amplitude Balance (max.) (dB)	Phase Deviation (deg.)	Isolation (min.) (dB)	VSWR (max.)	Power Capacity (W)
LDC32900M03B-703	3.3 ±0.48dB	1.0	90 ±3.0°	20.5	1.43	3 max. (50ohm Load)

Characteristic Impedance: 50ohm Operating Temperature Range: -40°C to +85°C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Murata:](#)

[LDC32900M03B-703](#)