
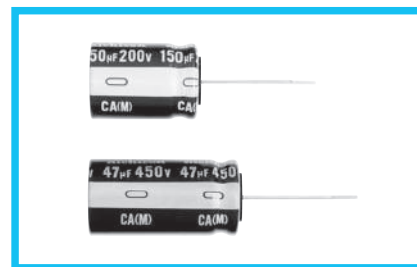


Miniature Sized, High Ripple Current, Long Life

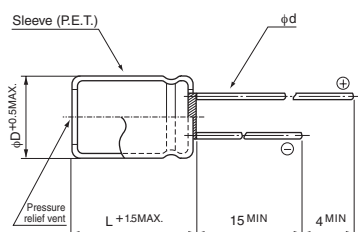

High Ripple

- UCS UCSY**

[illegible]

	(mm)			
ϕD	10	12.5	16	18
P	5.0	5.0	7.5	7.5
ϕd	0.6	0.6	0.8	0.8

1 2 3 4 5 6 7 8 9 10 11 12
U C A 2 E 1 0 1 M H D

ϕ D	Pb-free leadwire Pb-free PET sleeve
10	PD
12.5 to 18	HD

Frequency	50Hz	120Hz	1kHz	10kHz	100kHz or more
Coefficient	0.40	0.50	0.80	0.90	1.00

UCA

■ Dimensions

Rated Voltage (V) (code)	Rated Capacitance (μF)	Case Size φD×L (mm)	tan δ	Leakage Current (μA) (at 20°C after 1 minute)	Rated Ripple (mArms) (105°C/100kHz)	Part Number
160 (2C)	10	10×16	0.15	164	250	UCA2C100MPD
	22	10×20	0.15	240.8	500	UCA2C220MPD
	33	10×20	0.15	311.2	565	UCA2C330MPD
	47	12.5×20	0.15	400.8	725	UCA2C470MHD
	68	12.5×25	0.15	535.2	950	UCA2C680MHD
	68	16×20	0.15	535.2	970	UCA2C680MHD6
	100	16×25	0.15	740	1280	UCA2C101MHD
	100	18×20	0.15	740	1180	UCA2C101MHD6
	150	16×31.5	0.15	1060	1360	UCA2C151MHD
	150	18×25	0.15	1060	1360	UCA2C151MHD6
	220	16×31.5	0.15	1508	1400	UCA2C221MHD
	220	18×25	0.15	1508	1400	UCA2C221MHD6
200 (2D)	10	10×16	0.15	180	250	UCA2D100MPD
	22	10×20	0.15	276	500	UCA2D220MPD
	33	12.5×20	0.15	364	600	UCA2D330MHD
	47	12.5×20	0.15	476	780	UCA2D470MHD
	68	12.5×25	0.15	644	950	UCA2D680MHD
	68	16×20	0.15	644	970	UCA2D680MHD6
	100	16×25	0.15	900	1280	UCA2D101MHD
	100	18×20	0.15	900	1180	UCA2D101MHD6
	150	16×31.5	0.15	1300	1360	UCA2D151MHD
	150	18×25	0.15	1300	1360	UCA2D151MHD6
	220	18×31.5	0.15	1860	1700	UCA2D221MHD
250 (2E)	10	10×20	0.15	200	300	UCA2E100MPD
	22	12.5×20	0.15	320	600	UCA2E220MHD
	33	12.5×20	0.15	430	630	UCA2E330MHD
	47	12.5×25	0.15	570	720	UCA2E470MHD
	47	16×20	0.15	570	750	UCA2E470MHD6
	68	16×25	0.15	780	1000	UCA2E680MHD
	68	18×20	0.15	780	920	UCA2E680MHD6
	100	16×31.5	0.15	1100	1400	UCA2E101MHD
	100	18×25	0.15	1100	1345	UCA2E101MHD6
	150	18×31.5	0.15	1600	1500	UCA2E151MHD
350 (2V)	6.8	10×16	0.20	195.2	220	UCA2V6R8MPD
	10	10×20	0.20	240	280	UCA2V100MPD
	22	12.5×20	0.20	408	350	UCA2V220MHD
	33	16×20	0.20	562	600	UCA2V330MHD
	47	16×25	0.20	758	700	UCA2V470MHD
	47	18×20	0.20	758	750	UCA2V470MHD6
	68	16×31.5	0.20	1052	1100	UCA2V680MHD
	68	18×25	0.20	1052	875	UCA2V680MHD6

For cut leads, formed leads or taped parts, please add the appropriate code after the size code (12th digit).
If there is no size code in the part number, please add size code "1" and then add the appropriate code.

UCA

■ Dimensions

Rated Voltage (V) (code)	Rated Capacitance (μ F)	Case Size ϕ D $\times$ L (mm)	$\tan \delta$	Leakage Current (μ A) (at 20°C after 1 minute)	Rated Ripple (mA _{rms}) (105°C/100kHz)	Part Number
400 (2G)	6.8	10 $\times$ 16	0.20	208.8	220	UCA2G6R8MPD
	10	10 $\times$ 20	0.20	260	280	UCA2G100MPD
	22	12.5 $\times$ 20	0.20	452	430	UCA2G220MHD
	22	16 $\times$ 20	0.20	452	600	UCA2G220MHD6
	33	16 $\times$ 25	0.20	628	640	UCA2G330MHD
	33	18 $\times$ 20	0.20	628	640	UCA2G330MHD6
	47	16 $\times$ 31.5	0.20	852	840	UCA2G470MHD
	47	18 $\times$ 25	0.20	852	840	UCA2G470MHD6
	68	18 $\times$ 31.5	0.20	1188	1000	UCA2G680MHD
450 (2W)	6.8	10 $\times$ 20	0.20	222.4	150	UCA2W6R8MPD
	10	12.5 $\times$ 20	0.20	280	320	UCA2W100MHD
	22	16 $\times$ 25	0.20	496	560	UCA2W220MHD
	22	18 $\times$ 20	0.20	496	560	UCA2W220MHD6
	33	16 $\times$ 31.5	0.20	694	700	UCA2W330MHD
	33	18 $\times$ 25	0.20	694	700	UCA2W330MHD6
	47	18 $\times$ 31.5	0.20	946	900	UCA2W470MHD

For cut leads, formed leads or taped parts, please add the appropriate code after the size code (12th digit).

If there is no size code in the part number, please add size code "1" and then add the appropriate code.

- For formed lead or taped product specifications and minimum order quantity, please refer to the Guidelines for Aluminum Electrolytic Capacitors.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Nichicon:](#)

[UCA2D221MHD1AA](#) [UCA2E470MHD1CV](#)