


TYPICAL INDICATOR ORDERING EXAMPLE

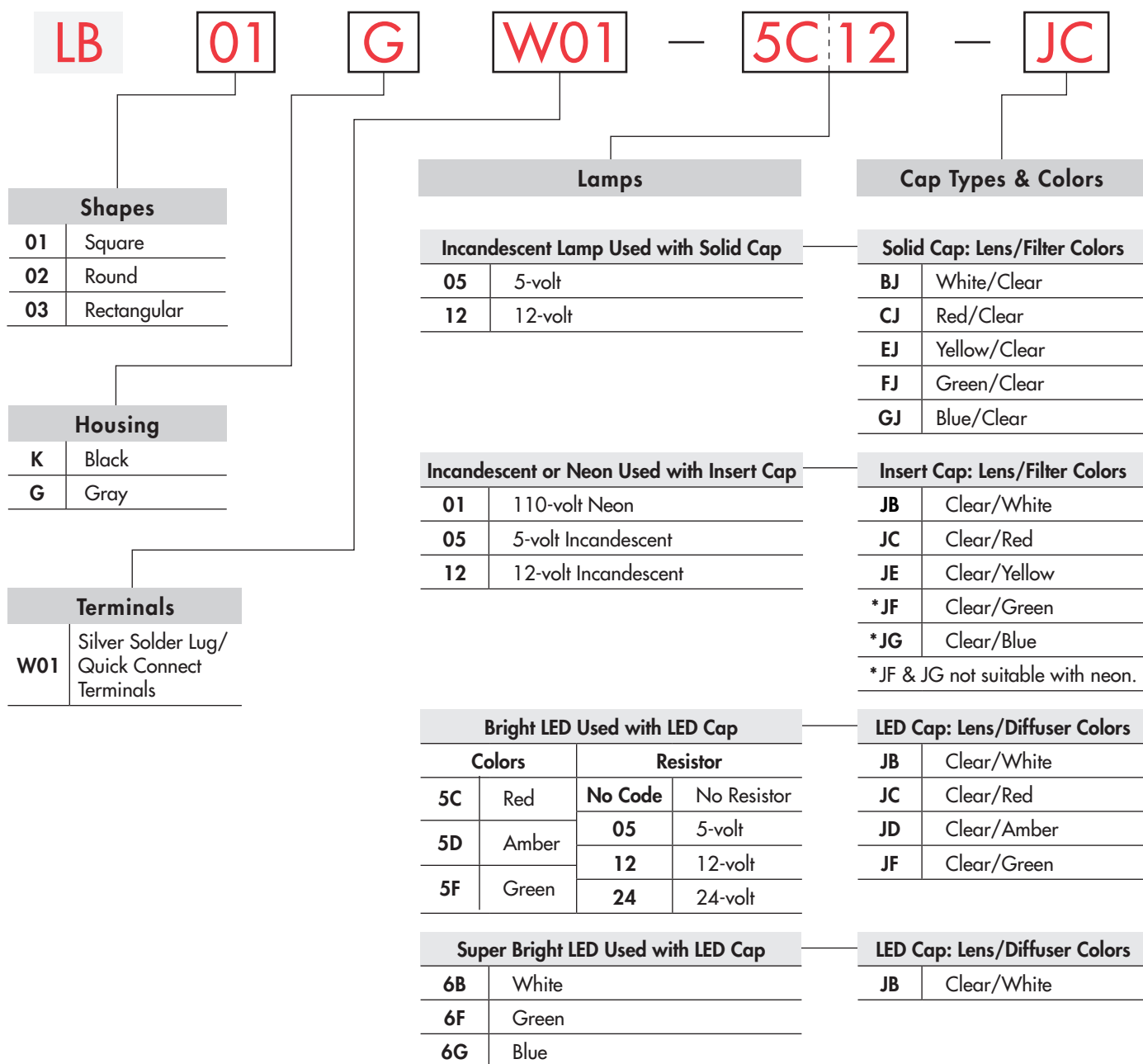

DESCRIPTION FOR TYPICAL ORDERING EXAMPLE



LB01GW01-5C12-JC



SHAPES & PANEL CUTOUTS



01

.622" (15.8mm)
Square

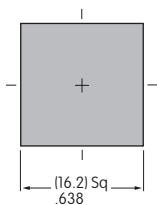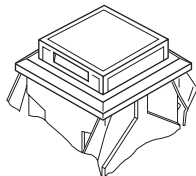



02

.854" (21.7mm)
Round

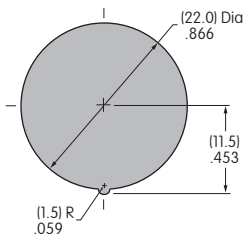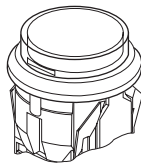

03

.622" x .866" (15.8mm x 22.0mm)
Rectangular

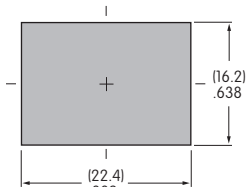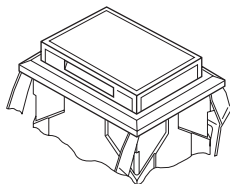

Panel Thickness: .039" ~ .157" (1.0 ~ 4.0mm)

HOUSING

Housing Colors Available:

K

Black


G

Gray

TERMINALS

W01

Silver Solder Lug/.110" (2.8mm) Quick Connect

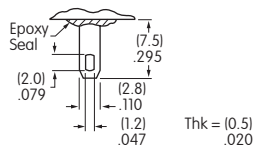

LAMP CODES & SPECIFICATIONS

Incandescent Lamp for Solid Colored and Colored Insert Caps

AT607  T-1 Bi-pin		05	12	
	Voltage	V	5V AC	12V AC
	Current	I	115mA	60mA
	Endurance	Hours	10,000 average	
	Ambient Temp. Range		-25°C ~ +50°C	

Neon Lamp for Colored Insert Cap






AT607N  T-1 Bi-pin		01	
	Voltage	V	110V AC
	Current	I	1.5mA
	Endurance	Hours	10,000 average
	Ambient Temp. Range		-25°C ~ +50°C
	Recommended Resistors: 33K ohms for 110V AC; 100K ohms for 220V AC		

The electrical specifications shown are determined at a basic temperature of 25°C.

CAP TYPES & COLOR COMBINATIONS

Color Codes: B White C Red D Amber E Yellow F Green G Blue J Clear






Solid Cap for Incandescent Lamp

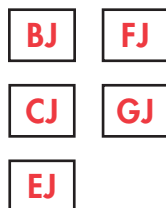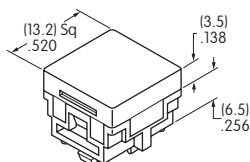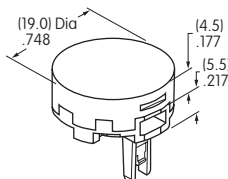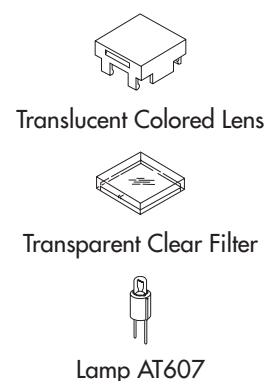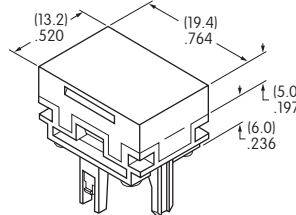Lens/Filter
Colors Available:**AT476**
Square**AT4012**
Round**AT4026**
Rectangular

Material: Polycarbonate Finish: Glossy

Lamp AT607





Insert Cap for Incandescent or Neon Lamp

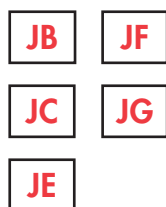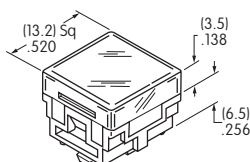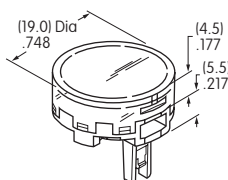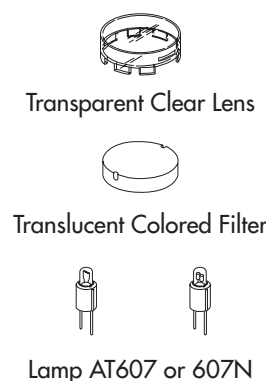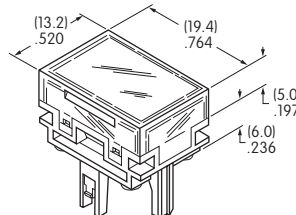Lens/Filter
Colors Available:**AT477**
Square**AT4013**
Round**AT4027**
RectangularJF and JG not suitable
with neon lamp.

Material: Polycarbonate Finish: Glossy

Lamp AT607 or 607N





Cap for Bright LED without Resistor

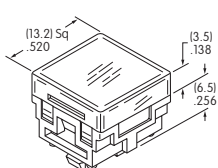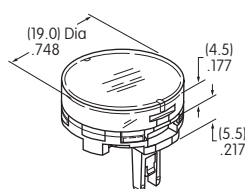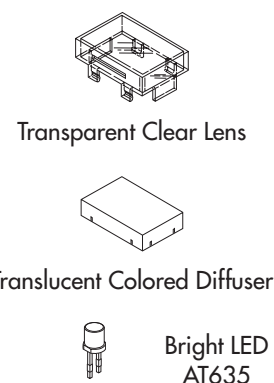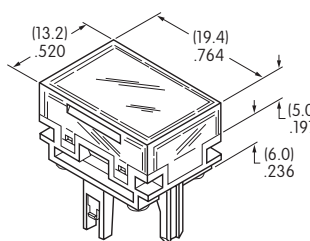Lens/Diffuser
Colors Available:**AT4176**
Square**AT4178**
Round**AT4177**
Rectangular

Material: Polycarbonate Finish: Glossy

Bright LED
AT635

Cap for Bright LED with Resistor

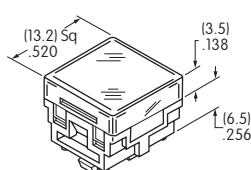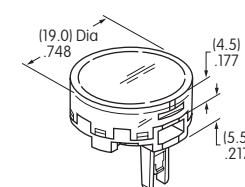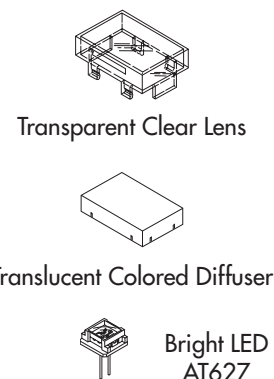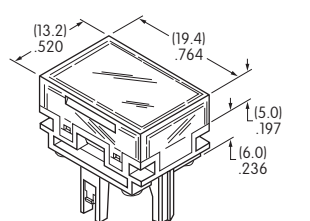Lens/Diffuser
Colors Available:**AT4162**
Square**AT4164**
Round**AT4163**
Rectangular

Material: Polycarbonate Finish: Glossy

Bright LED
AT627

CAP TYPES & COLOR COMBINATIONS

Cap for Super Bright LEDs




**Clear Lens
White Diffuser**


**AT4129
Square**

**AT4128
Round**

 **AT4130
Rectangular**



**Transparent
Clear Lens**



 


**Translucent
White Diffuser**






**LEDs AT625
AT631 AT632**

Material:
Polycarbonate
Finish: Glossy

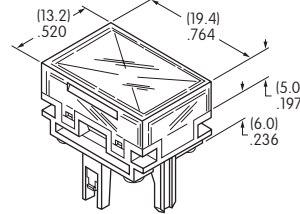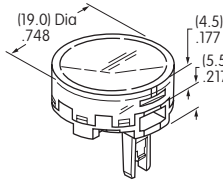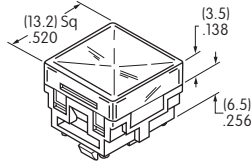




TYPICAL INDICATOR DIMENSIONS

Square

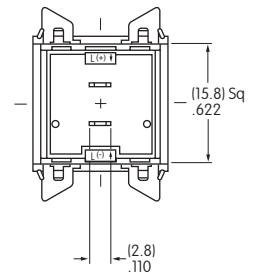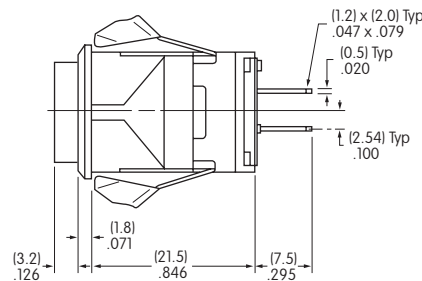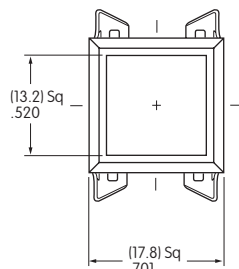




LB01KW01-12-CJ

Round

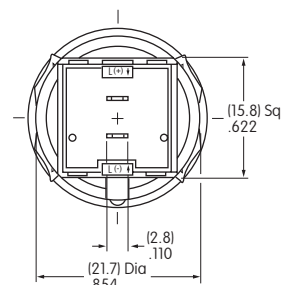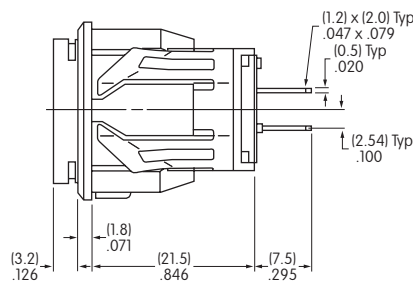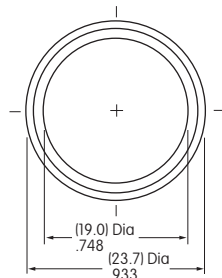

LB02KW01-12-CJ

Rectangular

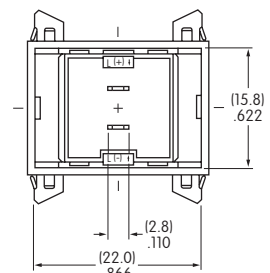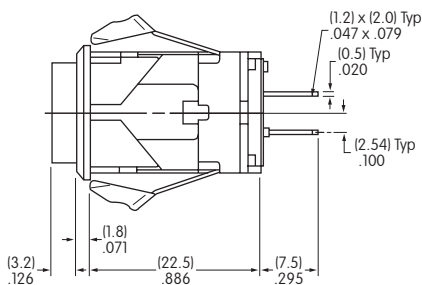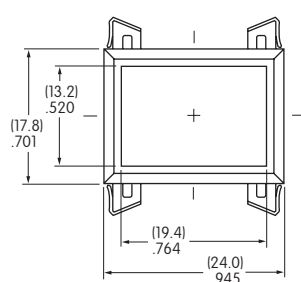

LB03KW01-12-CJ

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

NKK Switches:

[LB01KW01-05-FJ](#) [LB01KW01-5F05-JF](#) [LB03KW01-5D24-JD](#) [LB01KW01-5C05-JC](#) [LB01KW01-5C-JC](#) [LB01KW01-6F-JB](#) [LB01KW01-6G-JB](#) [LB02KW01](#) [LB02KW01-5C12-JC](#) [LB02KW01-5D24-JD](#) [LB02KW01-5F24-JF](#) [LB02KW01-6B-JB](#) [LB02KW01-6G-JB](#) [LB03GW01](#) [LB03GW01-6G-JB](#) [LB03KW01](#) [LB03KW01-5C24-JC](#) [LB03KW01-6F-JB](#) [LB03KW01-6G-JB](#) [LB01KW01-12-FJ](#) [LB01KW01-12-JF](#) [LB01KW01-5C12-JB](#) [LB01KW01-5D-JB](#) [LB01KW01-5F12-JB](#) [LB02GW01](#) [LB02GW01-5C24-JC](#) [LB02GW01-5D24-JD](#) [LB02GW01-5F24-JF](#) [LB02KW01-5C05-JC](#) [LB03KW01-5C05-JC](#) [LB01KW01-6B-JB](#) [LB03KW01-12-CJ](#) [LB03GW01-01-JB](#) [LB03GW01-5C12-JC](#) [LB01KW01-12-CJ](#) [LB01KW01-5C05-JB](#) [LB01KW01-5D24-JB](#) [LB01KW01-5F24-JB](#) [LB01KW01-05-GJ](#) [LB01GW01-12-GJ](#) [LB01GW01-5D24-JB](#) [LB01GW01-5F24-JF](#) [LB01KW01-05-JC](#) [LB02GW01-12-FJ](#) [LB03KW01-5D12-JD](#) [LB03KW01-01-JC](#) [LB03KW01-05-BJ](#) [LB01KW01-5F05-JB](#) [LB02KW01-5F05-JB](#) [LB02KW01-5F12-JF](#) [LB01KW01-12-GJ](#) [LB02KW01-12-GJ](#) [LB02KW01-6F-JB](#) [LB02KW01-5C-JC](#) [LB02GW01-01-JB](#) [LB03KW01-01-JB](#) [LB02KW01-05-JF](#) [LB02KW01-12-BJ](#) [LB03KW01-5D12-JB](#) [LB01GW01-12-FJ](#) [LB01GW01-5C24-JB](#) [LB03KW01-05-FJ](#) [LB01GW01-05-JF](#) [LB02KW01-5C12-JB](#) [LB01KW01-5D-JD](#) [LB01GW01-12-CJ](#) [LB02KW01-5D-JD](#) [LB03KW01-5D-JB](#) [LB01GW01-5F-JF](#) [LB02KW01-05-FJ](#) [LB03KW01-5F24-JF](#) [LB01GW01-5C05-JB](#) [LB03KW01-05-JC](#) [LB01GW01-5C-JC](#) [LB01GW01-05-CJ](#) [LB02KW01-01-JC](#) [LB02GW01-01-JE](#) [LB03KW01-5F12-JB](#) [LB03KW01-12-JC](#) [LB03KW01-01-JE](#) [LB03KW01-12-EJ](#) [LB01KW01-28-EJ](#) [LB03KW01-5F-JB](#) [LB03KW01-5F05-JB](#) [LB03KW01-12-BJ](#) [LB01KW01-5C24-JB](#) [LB03KW01-5D-JD](#) [LB01GW01-5D-JD](#) [LB02KW01-5F-JF](#) [LB03KW01-5C-JB](#) [LB03GW01-28-BJ](#) [LB01KW01-01-JC](#) [LB02GW01-01-JC](#) [LB03KW01-5C12-JB](#) [LB01KW01-5D05-JB](#) [LB02KW01-12-FJ](#) [LB02KW01-28-BJ](#) [LB03KW01-5F12-JF](#) [LB03KW01-5C-JC](#) [LB03GW01-5D24-JD](#)