


TYPICAL INDICATOR ORDERING EXAMPLE

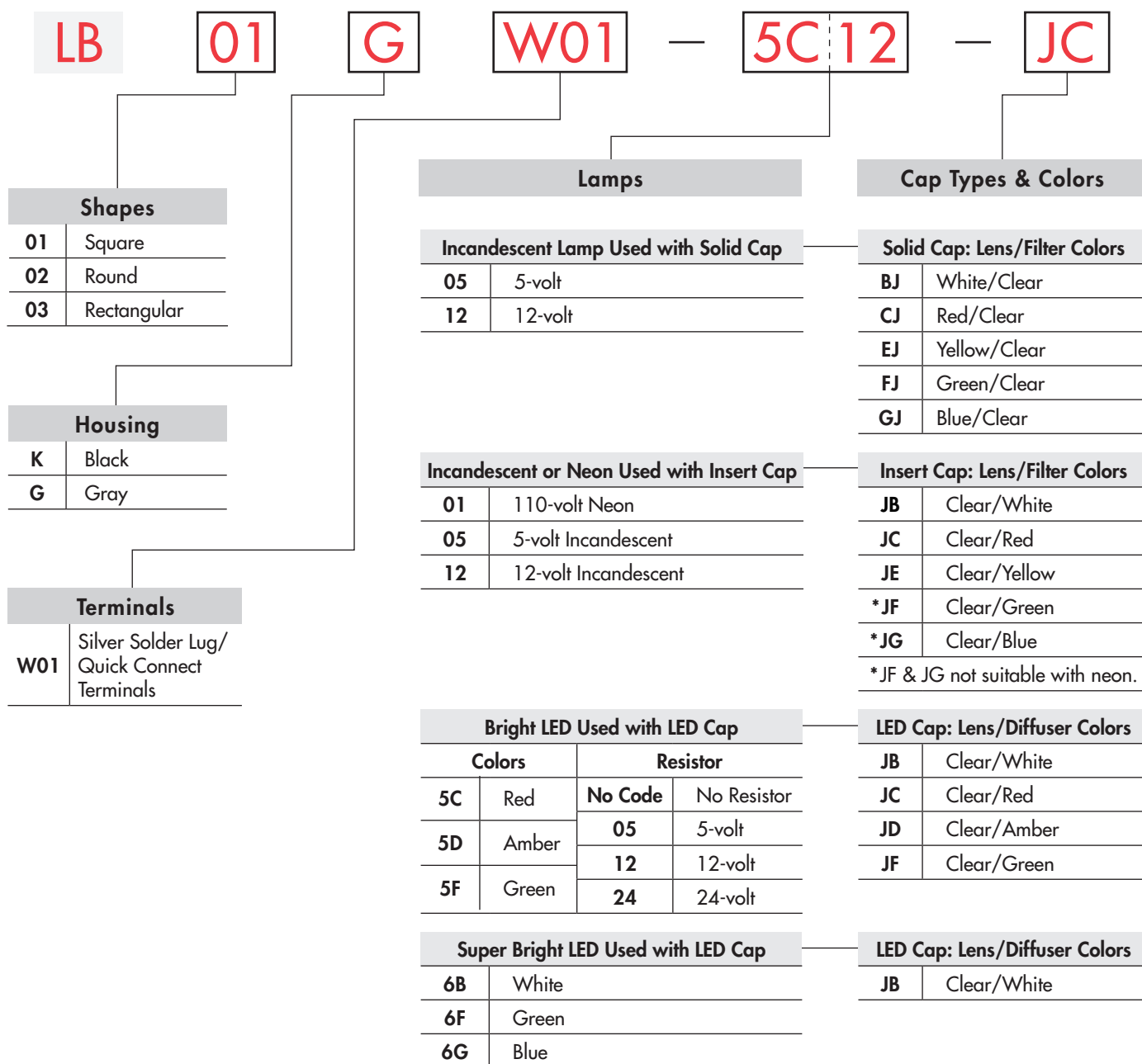

DESCRIPTION FOR TYPICAL ORDERING EXAMPLE



LB01GW01-5C12-JC



SHAPES & PANEL CUTOUTS



01

.622" (15.8mm)
Square

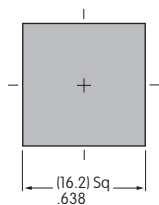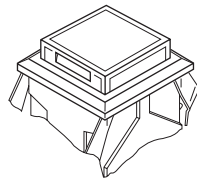



02

.854" (21.7mm)
Round

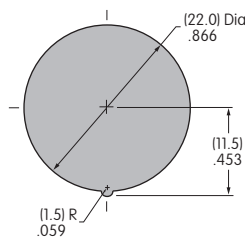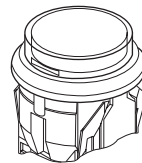

03

.622" x .866" (15.8mm x 22.0mm)
Rectangular

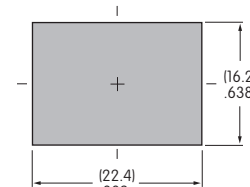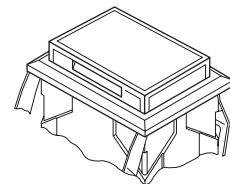

Panel Thickness: .039" ~ .157" (1.0 ~ 4.0mm)

HOUSING

Housing Colors Available:

K

Black


G

Gray

TERMINALS

W01

Silver Solder Lug/.110" (2.8mm) Quick Connect

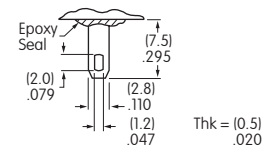

LAMP CODES & SPECIFICATIONS

Incandescent Lamp for Solid Colored and Colored Insert Caps

AT607  T-1 Bi-pin		05	12	
	Voltage	V	5V AC	12V AC
	Current	I	115mA	60mA
	Endurance	Hours	10,000 average	
	Ambient Temp. Range		-25°C ~ +50°C	

Neon Lamp for Colored Insert Cap

AT607N  T-1 Bi-pin		01	
	Voltage	V	110V AC
	Current	I	1.5mA
	Endurance	Hours	10,000 average
	Ambient Temp. Range		-25°C ~ +50°C
	Recommended Resistors: 33K ohms for 110V AC; 100K ohms for 220V AC		


The electrical specifications shown are determined at a basic temperature of 25°C.

CAP TYPES & COLOR COMBINATIONS


Color Codes: B White C Red D Amber E Yellow F Green G Blue J Clear

Solid Cap for Incandescent Lamp


Lens/Filter
Colors Available:

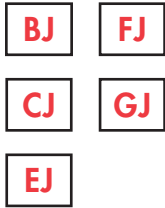


AT476
Square

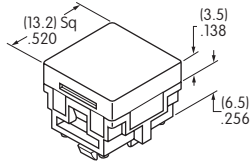


AT4012
Round

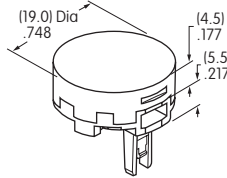

AT4026
Rectangular

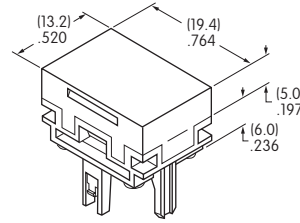

Translucent Colored Lens

 

Transparent Clear Filter




Lamp AT607


Material: Polycarbonate Finish: Glossy

Insert Cap for Incandescent or Neon Lamp


Lens/Filter
Colors Available:

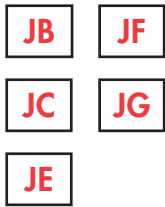


AT477
Square

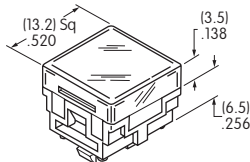


AT4013
Round

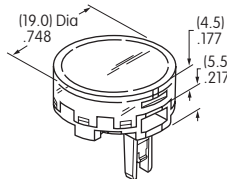

AT4027
Rectangular

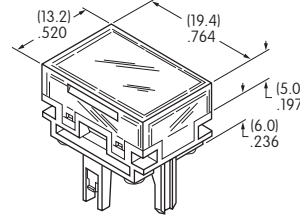

Transparent Clear Lens

 

Translucent Colored Filter



Lamp AT607 or 607N

Material: Polycarbonate Finish: Glossy


JF and JG not suitable with neon lamp.

Cap for Bright LED without Resistor


Lens/Diffuser
Colors Available:




AT4176
Square

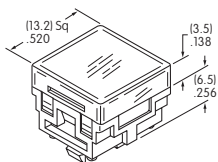


AT4178
Round

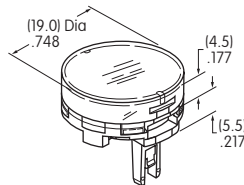


AT4177
Rectangular

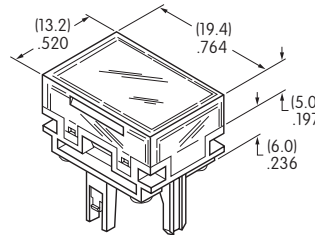

Transparent Clear Lens

 

Translucent Colored Diffuser

 

Bright LED
AT635


Material: Polycarbonate Finish: Glossy

Cap for Bright LED with Resistor


Lens/Diffuser
Colors Available:




AT4162
Square

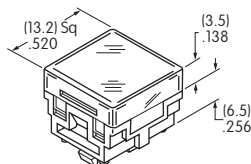


AT4164
Round

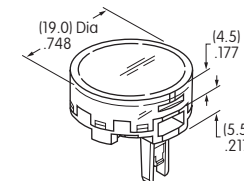


AT4163
Rectangular

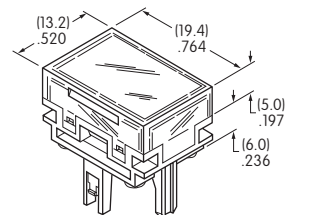

Transparent Clear Lens

 

Translucent Colored Diffuser

 

Bright LED
AT627

Material: Polycarbonate Finish: Glossy

CAP TYPES & COLOR COMBINATIONS

Cap for Super Bright LEDs




**Clear Lens
White Diffuser**


**AT4129
Square**

**AT4128
Round**

 **AT4130
Rectangular**



**Transparent
Clear Lens**



 


**Translucent
White Diffuser**






**LEDs AT625
AT631 AT632**

Material:
Polycarbonate
Finish: Glossy

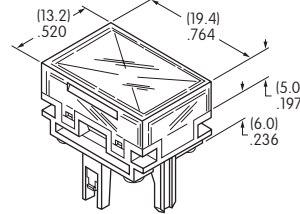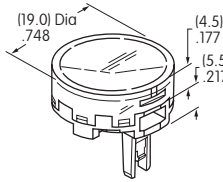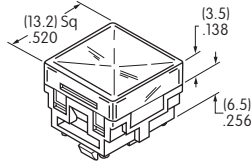




TYPICAL INDICATOR DIMENSIONS

Square

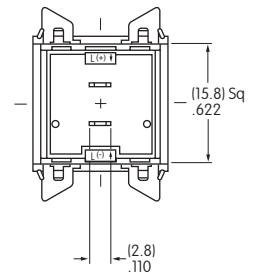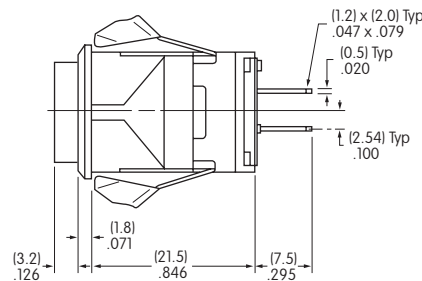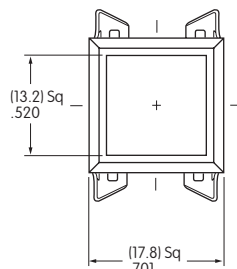




LB01KW01-12-CJ

Round

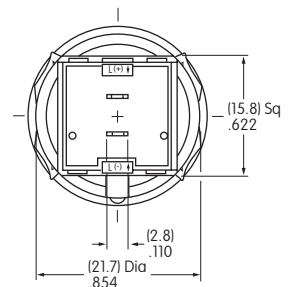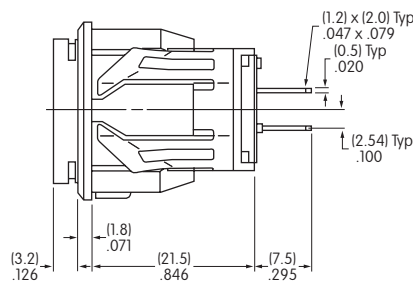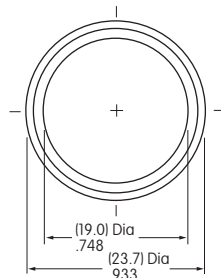

LB02KW01-12-CJ

Rectangular

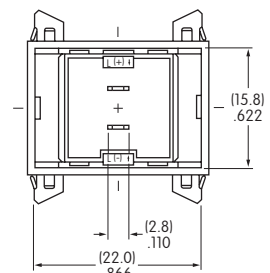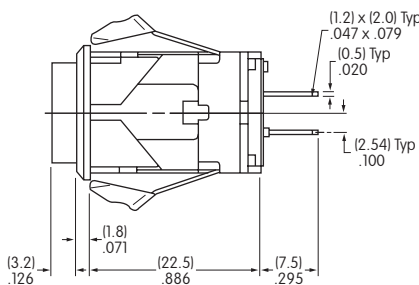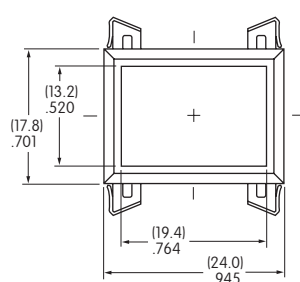

LB03KW01-12-CJ

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[NKK Switches:](#)

[LB02GW01-5F05-JB](#) [LB01KW01-5D12-JD](#) [LB01KW01-5F12-JF](#) [LB03KW01-5D24-JB](#) [LB02KW01-5D-JB](#)
[LB02KW01-5F-JB](#) [LB01KW01-12-JE](#) [LB01KW01-12-EJ](#) [LB01KW01-5D24-JD](#) [LB03KW01-5C24-JB](#) [LB01KW01-5D05-JD](#) [LB01KW01-5D12-JB](#)