






DESCRIPTION: -PIN FEMALE / FEMALE GENDER CHANGER

SPECIFICATION:

INSULATOR: PBT GLASS FIBER REINFORCED  
UL 94VO  
CONTACT: BRASS  
CONTACT PLATING: GOLD PLATED OVER NICKEL  
SHELL: TIN PLATED SHELL  
CURRENT RATING: 5 AMP  
DIELECTRIC STRENGTH: 1,000VAC FOR 1 MINUTE  
INSULATION RESISTANCE: 1,000 MegOHMS MIN @500 VDC  
TEMPERATURE: -55° C - +105° C

NOTE:


LABEL: YELLOW COLOR WITH  
BLACK CHARACTORS  
ONE SIDE: MINI GENDER CHANGER  
OTHER SIDE: U.S.A. PATENT 5199906

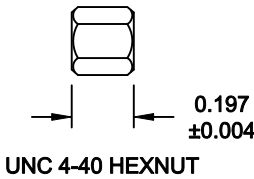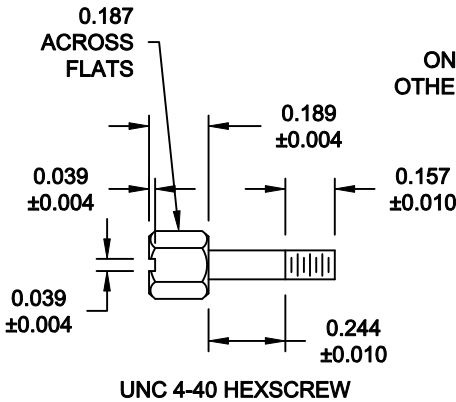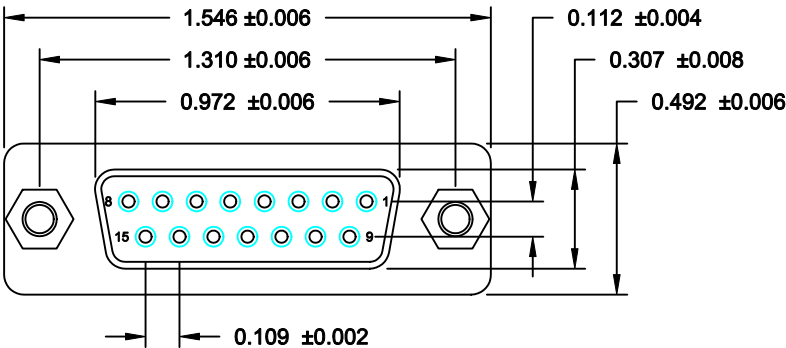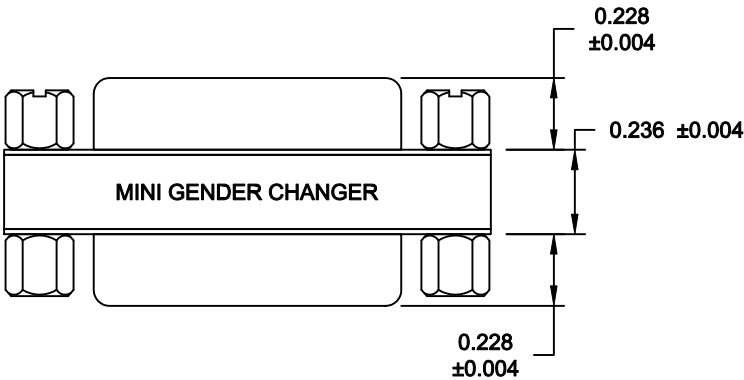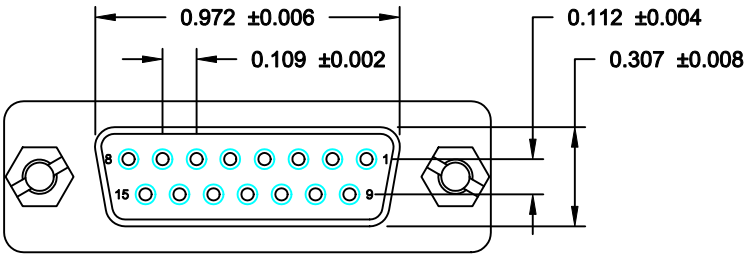

15-PIN FEMALE		15-PIN FEMALE
1	---	1
2	---	2
3	---	3
~		
14	---	14
15	---	15
SHELL	---	SHELL
PIN OUT		

DO NOT SCALE FROM DRAWING

RoHS COMPLIANT



THESE DRAWINGS AND SPECIFICATIONS ARE THE PROPERTY OF NorComp AND SHALL NOT BE REPRODUCED, COPIED OR USED AS THE BASIS FOR THE MANUFACTURE OF SALE OF APPARATUS WITHOUT WRITTEN PERMISSION.

NorComp

DO NOT SCALE FROM DRAWING

DRAWN:  
C. SMITH

CHECKED:

SCALE:  
1.5 : 1

DWG NO.  
GCLP15F15F

DATE:  
10-15-07

DATE:

SHEET  
1 OF  
1

REV  
1

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

NorComp:

GCLP15F15F