


# MHDTPPK Series | Plastic D-Sub Hood

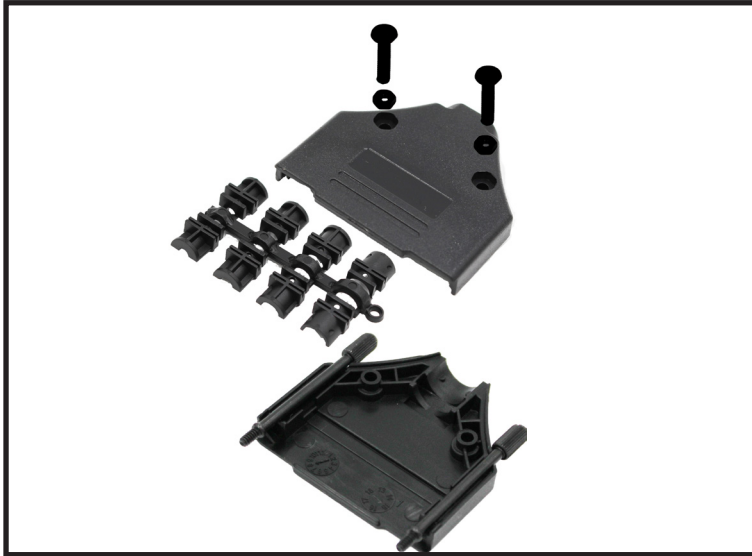

## Description

- Available in 9,15, 25 or 37 way
- Quick Snap together locking system
- Re-openable
- Cable entry, Top entry
- Operating Temperature, -55°C to 110°C
- Will accommodate up to 13 mm diameter cable
- Cable clamp is secured with 2 screws
- 4-40UNC Jackscrews



## The Kit Contains:

Backshell halves	x 2
4-40 Jackscrews	x 2
Plastic strain relief	x 1
Backshell screws	x 2

## Specification

- Ways: 9, 15, 25 or 37
- Housing Material: Polyamide UL- Recognised
- Cable Entry: Straight, 90°
- Cable OD: Up to 13 mm

Dimensions			
Size	A	B	C
09	31.2	39.9	15.0
15	39.5	41.5	15.0
25	53.4	48.6	15.0
37	69.7	53.6	15.0

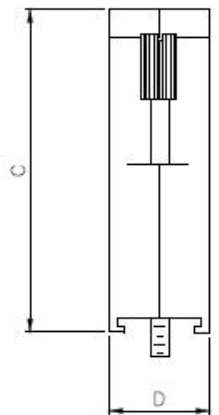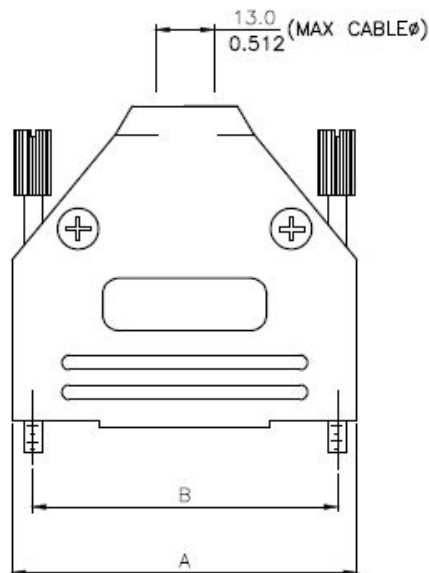

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

NorComp:

[MHDTPPK25-DB25P-K](#) [MHDTPPK25-DB25S-K](#)