
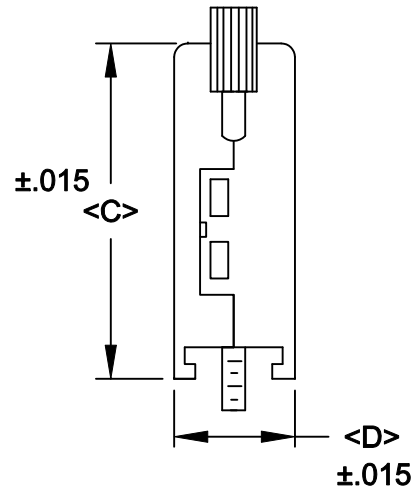


DESCRIPTION: 972 SERIES D-SUB SLIM-LINE BACKSHELL

BACKSHELL KIT INCLUDES:

- (1) BACKSHELL
- (2) 4-40 THUMBSCREWS
- (1) PLASTIC STRAIN RELIEF
- (1) METAL STRAIN RELIEF CLAMP
- (2) STRAIN RELIEF SCREWS

TORQUE VALUE ON PLASTIC FOR STRAIN RELIEF SCREWS = 4 INCH POUNDS MAX.

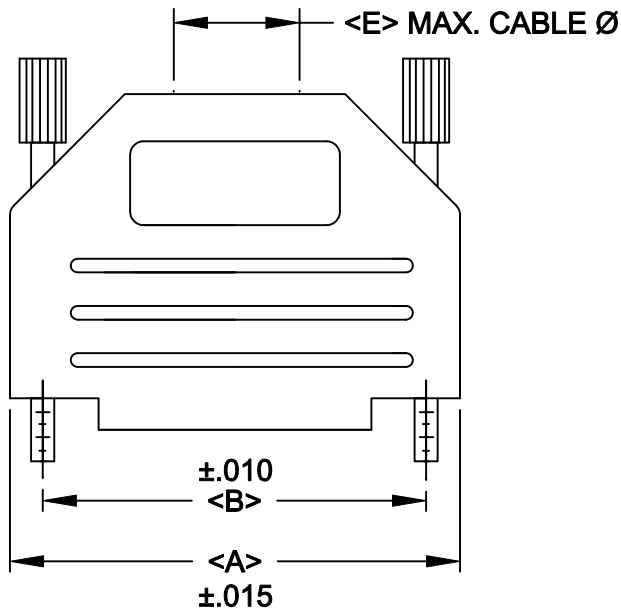

SERIES 972-YYY-01SRYY1
POSITIONS 009, 015, 025, 037
MATERIAL 01S = PLASTIC/SLIM LINE
COLOR: 01 = BLACK, 03 = LIGHT GREY, 04 = GREEN, 06 = RED, 07 = BLUE, 08 = YELLOW, 11 = DEC GREY
PUT-UPS 1 = KIT

****SEE PAGE 2 FOR PANTONE COLOR CODES**

POS.	A	B	C	D	E
9	1.240	.984	1.339	.591	.315
	31.50	24.99	34.00	15.00	8.00
15	1.575	1.312	1.339	.591	.453
	40.00	33.32	34.00	15.00	11.50
25	2.106	1.852	1.575	.591	.453
	53.50	47.04	40.00	15.00	11.50
37	2.795	2.500	1.575	.591	.453
	71.00	63.50	40.00	15.00	11.50

MATERIAL: POLYAMIDE PA66 - UL 94H-B
MANY COLORS AVAILABLE
THUMBSCREWS: STEEL

OPERATING TEMP: -30°C TO +110°C
RoHS COMPLIANT



THESE DRAWINGS AND SPECIFICATIONS ARE THE PROPERTY OF NorComp AND SHALL NOT BE REPRODUCED, COPIED OR USED AS THE BASIS FOR THE MANUFACTURE OF SALE OF APPARATUS WITHOUT WRITTEN PERMISSION.

DRAWN:
PAM JENKINS

CHECKED:

DATE:
6-10-05

DATE:

SCALE:

SHEET 1 OF 2

REV 5

DWG NO. 972-YYY-01SRYY1

NorComp

	COLOR RANGE	
COLOR	UPPER	LOWER
01 = BLACK	PANTONE BLACK 3C	PANTONE BLACK 3C
03 = LIGHT GREY	427C	427C
04 = GREEN	7731C	7732C
06 = RED	186C	187C
07 = BLUE	2190C	2191C
08 = YELLOW	108C	109C
11 = DEC GREY	7527C	7534C

	THESE DRAWINGS AND SPECIFICATIONS ARE THE PROPERTY OF NorComp AND SHALL NOT BE REPRODUCED, COPIED OR USED AS THE BASIS FOR THE MANUFACTURE OF SALE OF APPARATUS WITHOUT WRITTEN PERMISSION.	DRAWN: PAM JENKINS		DATE: 6-10-05	
		CHECKED:		DATE:	
		SCALE:	SHEET 2	OF 2	REV 5
NorComp		DWG NO. 972-YYY-01SRYY1			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[NorComp:](#)

[972-025-01SR071](#) [972-025-01SR011](#) [972-025-01SR031](#) [972-025-01SR061](#) [972-025-01SR081](#) [972-009-01SR031](#)
[972-009-01SR061](#) [972-009-01SR081](#) [972-009-01SR041](#) [972-009-01SR071](#) [972-025-01SR041](#)