

868/915MHz ISM/LoRA Flexible PCB Antenna



AANI-FB-0085

Request Samples



Check Inventory



79 x 10 x 0.2 mm
RoHS Compliant
MSL Level = N/A


Features

- Compact Design with High Efficiency Up to 70%
- Easy Installation on Both Flat and Curved Surfaces
- Can be Installed on Plastic and Human Body
- Strong Adhesive in High-Temperature and Humid Environment
- Fully Customizable Cable Length and Connector Options
- RoHS Compliant

Applications

- Sub-GHz/LoRa/Sigfox
- Smart Lighting
- Utility & Smart Metering
- Amazon Sidewalk
- Traffic Control and Monitoring
- Energy Generation and Storage System

Product Image

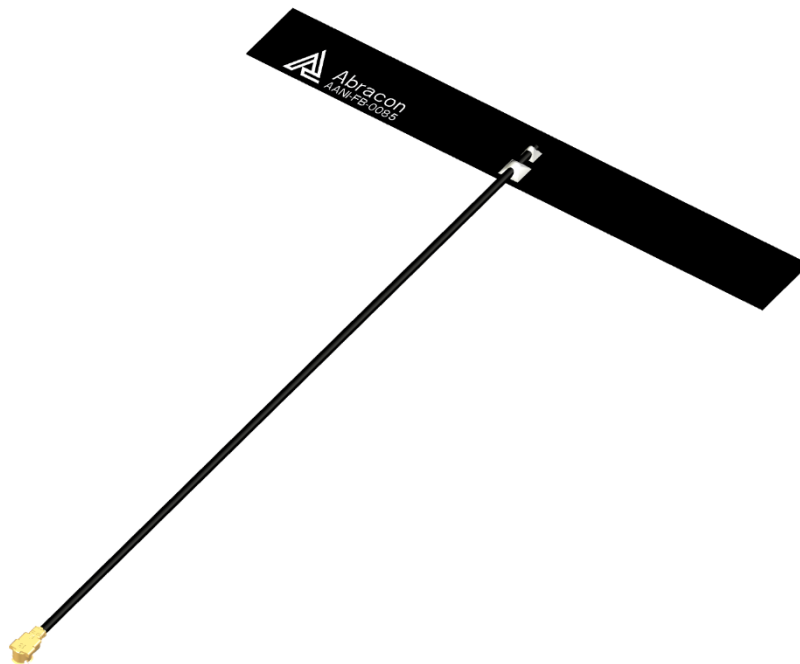

868/915MHz ISM/LoRA Flexible PCB Antenna



AANI-FB-0085

Request Samples



Check Inventory



79 x 10 x 0.2 mm
RoHS Compliant
MSL Level = N/A

Electrical Specification

Parameter	Specification		Unit
Operating Frequency	868	915	MHz
VSWR (Typ.)	< 2.0		
Peak Gain	0.4	1.5	dBi
Efficiency	60	70	%
Impedance	50		Ω
Polarization	Linear		
Radiation Pattern (Azimuth)	Omni-directional		

Mechanical Specification

Parameter	Specification
Antenna Dimensions	79 x 10 x 0.2 mm
Antenna Type	Flexible Printed Circuit
Mounting Type	Adhesive
RF Connector ⁽¹⁾	u.FL/IPEX-1/MHF1, w.FL/IPEX-4/MHF4
RF Cable Type ⁽¹⁾	Ø1.13 mm
Cable Length ⁽¹⁾	100 mm, 150 mm, 200 mm

(1): Fully customizable RF Cable & Connector

Environmental Specification

Parameter	Specification
Operating Temperature	-40°C to +85°C
Storage Temperature	-40°C to +85°C
RoHS Complaint	Yes
PB Free	Yes

868/915MHz ISM/LoRA Flexible PCB Antenna



AANI-FB-0085

Request Samples



Check Inventory



79 x 10 x 0.2 mm
RoHS Compliant
MSL Level = N/A

Ordering Information

Part Number	Description	Connector Option
AANI-FB-0085-0100I	868/915MHz ISM/LoRA Flexible PCB Antenna with MHF1 connector and 100mm cable	u.FL/IPEX-1/MHF1
AANI-FB-0085-0100W	868/915MHz ISM/LoRA Flexible PCB Antenna with MHF4 connector and 100mm cable	w.FL/IPEX-4/MHF4
AANI-FB-0085-0150I	868/915MHz ISM/LoRA Flexible PCB Antenna with MHF1 connector and 150mm cable	u.FL/IPEX-1/MHF1
AANI-FB-0085-0150W	868/915MHz ISM/LoRA Flexible PCB Antenna with MHF4 connector and 150mm cable	w.FL/IPEX-4/MHF4
AANI-FB-0085-0200I	868/915MHz ISM/LoRA Flexible PCB Antenna with MHF1 connector and 200mm cable	u.FL/IPEX-1/MHF1
AANI-FB-0085-0200W	868/915MHz ISM/LoRA Flexible PCB Antenna with MHF4 connector and 200mm cable	w.FL/IPEX-4/MHF4

Note: Different cable and connector configurations that are not listed may be available upon request via [Abracon online support](#)



868/915MHz ISM/LoRA Flexible PCB Antenna

AANI-FB-0085

Request Samples



Check Inventory




79 x 10 x 0.2 mm


RoHS Compliant

MSL Level = N/A


Product Dimensions

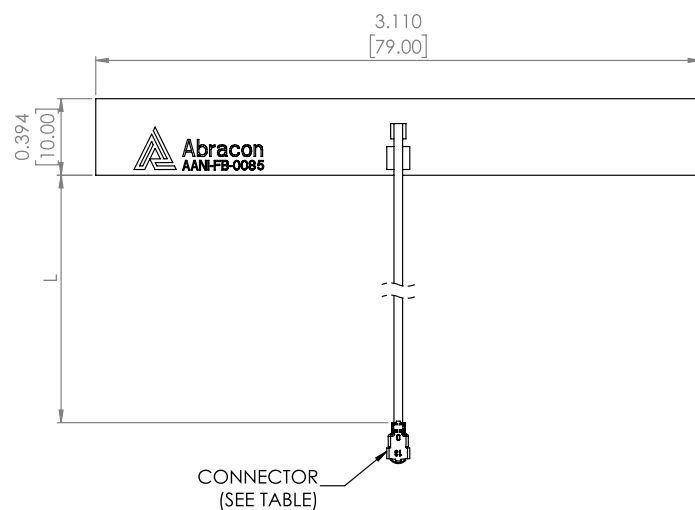


FRONT VIEW

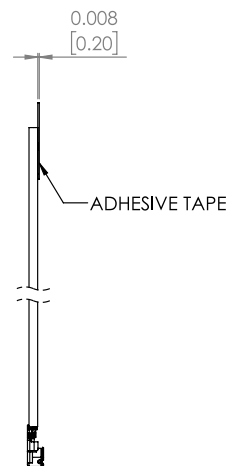

SIDE VIEW

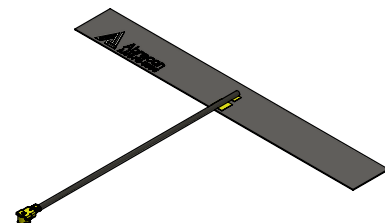

CONNECTOR

 

u.FL/IPEX-1/MHF1



w.FL/IPEX-4/MHF4

PART NUMBER	CABLE LENGTH (L)	CONNECTOR
AANI-FB-0085-0100I	3.937[100]	u.FL/IPEX-1/MHF1
AANI-FB-0085-0100W	3.937[100]	w.FL/IPEX-4/MHF4
AANI-FB-0085-0150I	5.905[150]	u.FL/IPEX-1/MHF1
AANI-FB-0085-0150W	5.905[150]	w.FL/IPEX-4/MHF4
AANI-FB-0085-0200I	7.874[200]	u.FL/IPEX-1/MHF1
AANI-FB-0085-0200W	7.874[200]	w.FL/IPEX-4/MHF4

Unit : inches[mm]

868/915MHz ISM/LoRA Flexible PCB Antenna



AANI-FB-0085

Request Samples




Check Inventory



79 x 10 x 0.2 mm
RoHS Compliant
MSL Level = N/A

Measurement Setup photo

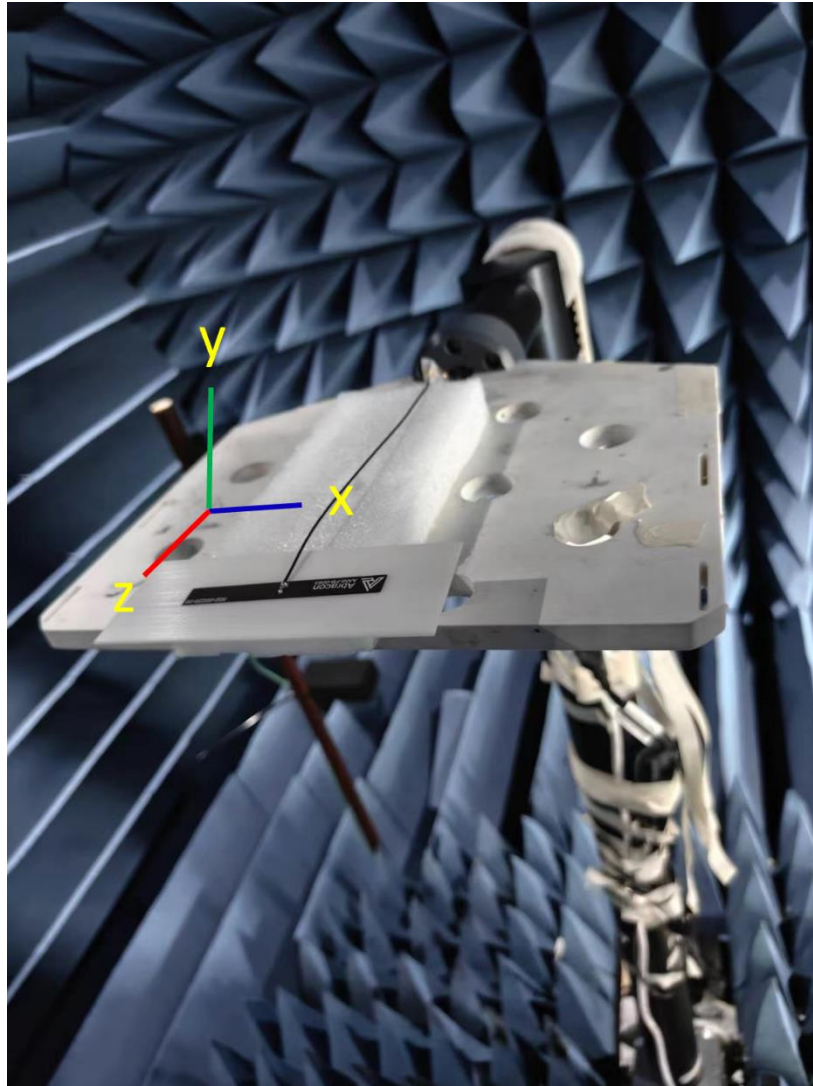

868/915MHz ISM/LoRA Flexible PCB Antenna



AANI-FB-0085

Request Samples





Check Inventory



79 x 10 x 0.2 mm
RoHS Compliant
MSL Level = N/A

Reflection Characteristics – Return Loss & VSWR

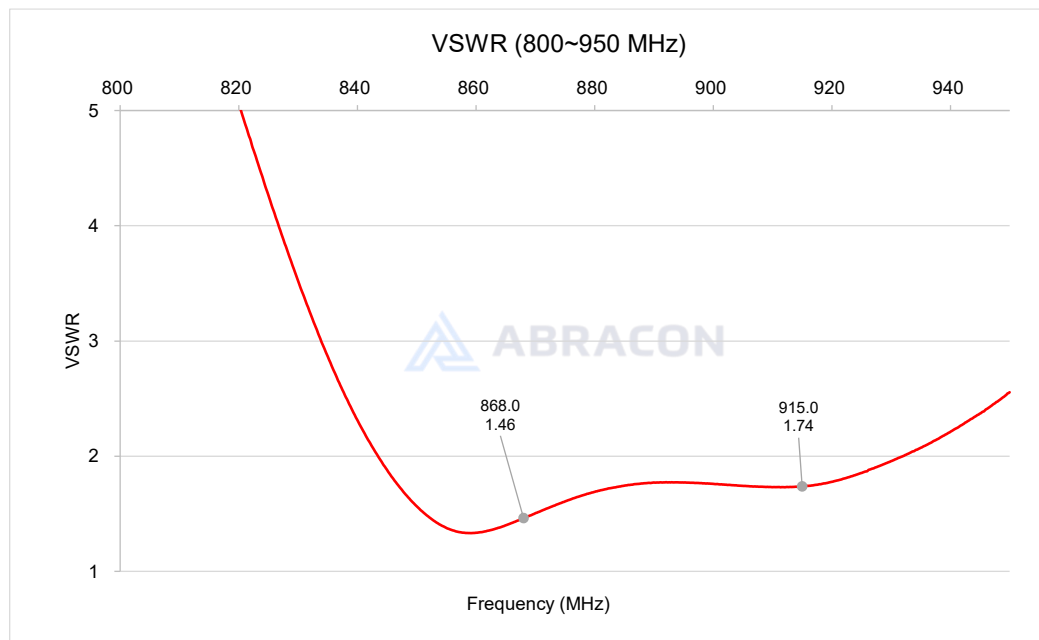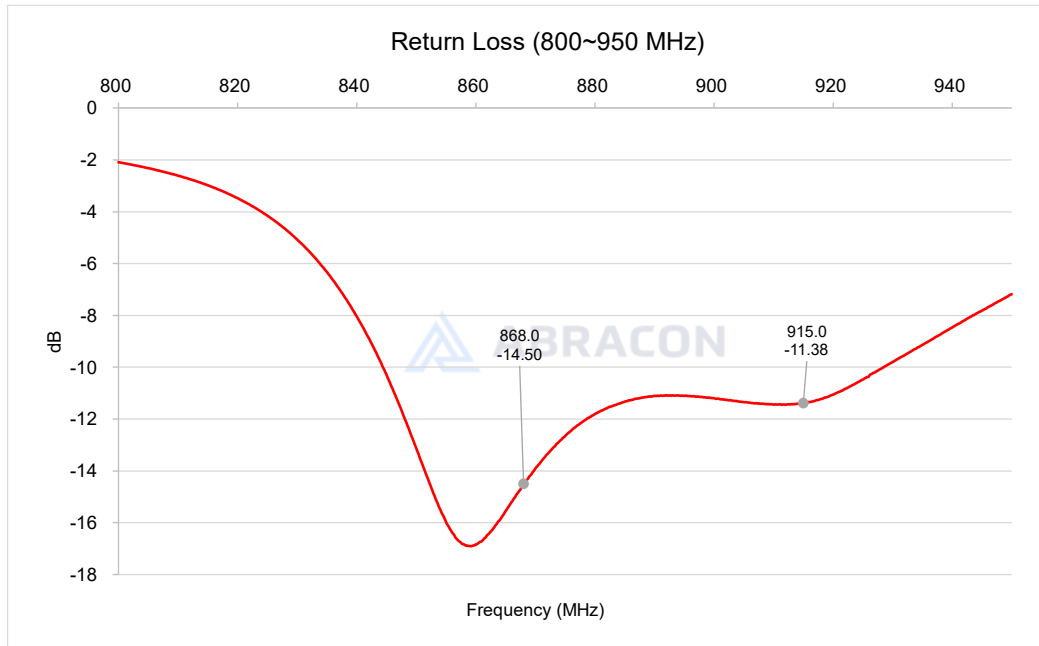

868/915MHz ISM/LoRA Flexible PCB Antenna



AANI-FB-0085

Request Samples



Check Inventory




79 x 10 x 0.2 mm

RoHS Compliant

MSL Level = N/A

Radiation Characteristics – Peak Gain

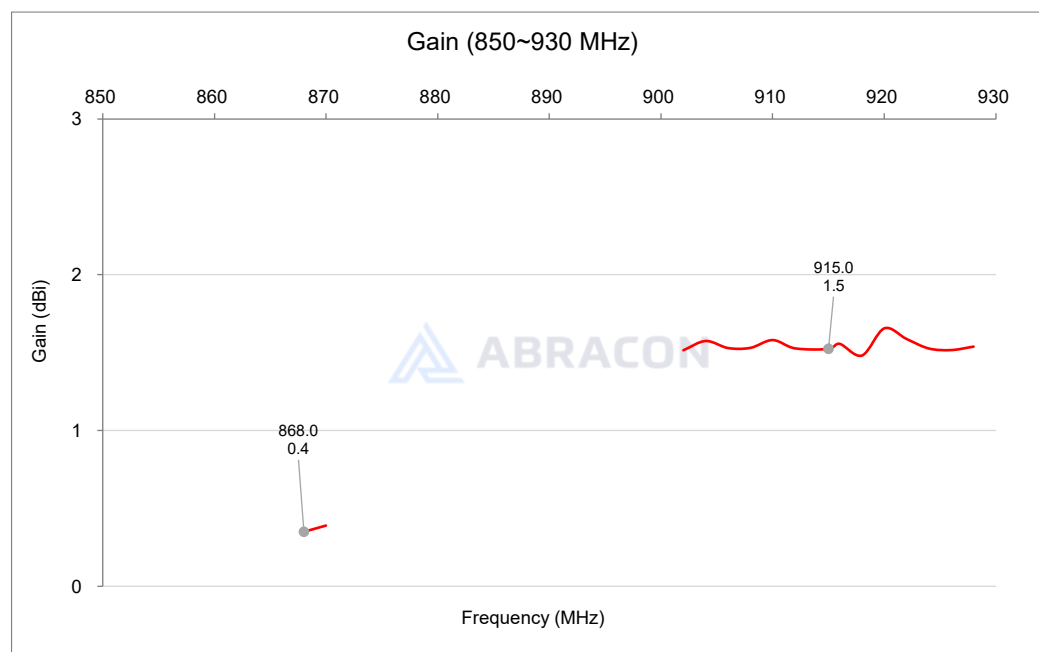

868/915MHz ISM/LoRA Flexible PCB Antenna



AANI-FB-0085

Request Samples



Check Inventory




79 x 10 x 0.2 mm

RoHS Compliant

MSL Level = N/A

Radiation Characteristics – Total Efficiency (%)

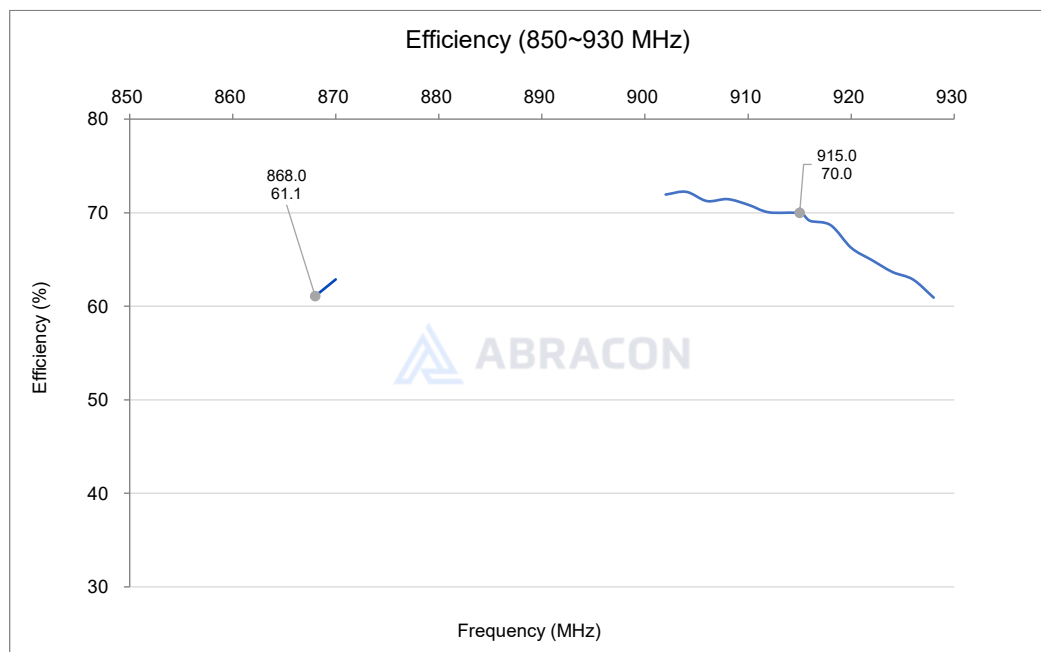

868/915MHz ISM/LoRA Flexible PCB Antenna



AANI-FB-0085

Request Samples



Check Inventory








79 x 10 x 0.2 mm

RoHS Compliant

MSL Level = N/A

Radiation Characteristics – 3D & 2D pattern

868MHz

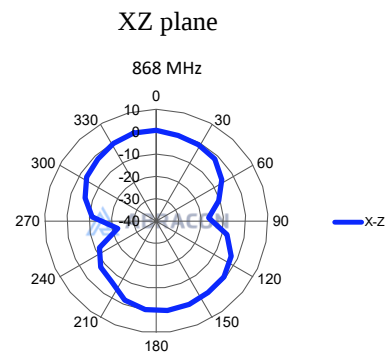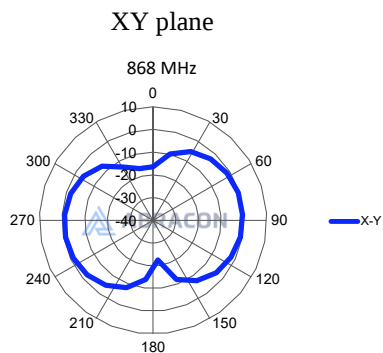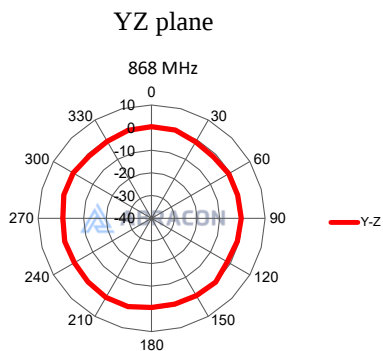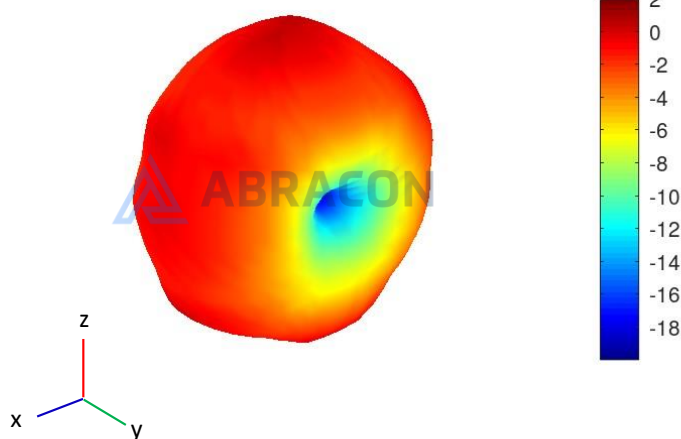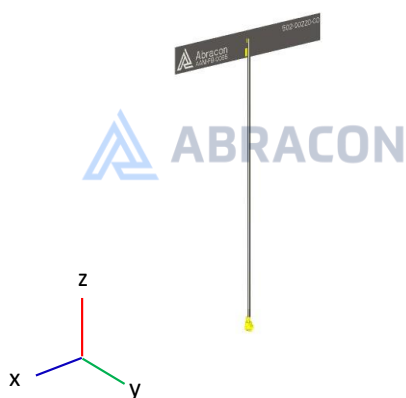

868/915MHz ISM/LoRA Flexible PCB Antenna



AANI-FB-0085

Request Samples



Check Inventory







79 x 10 x 0.2 mm

RoHS Compliant

MSL Level = N/A

915MHz

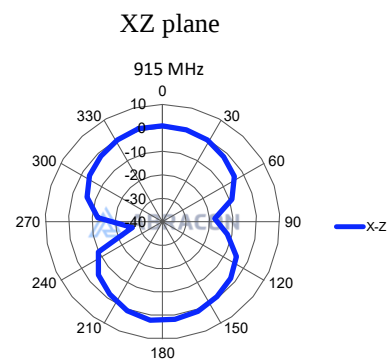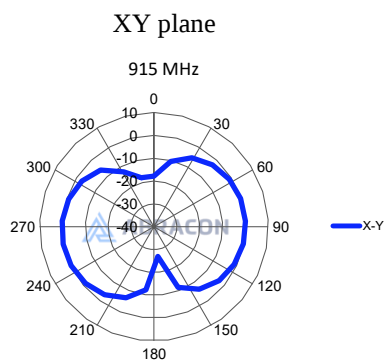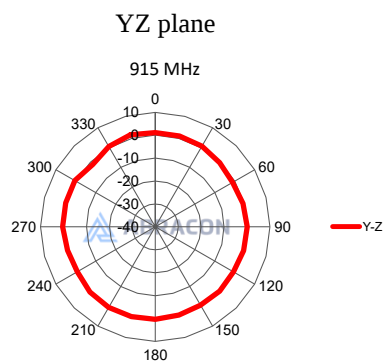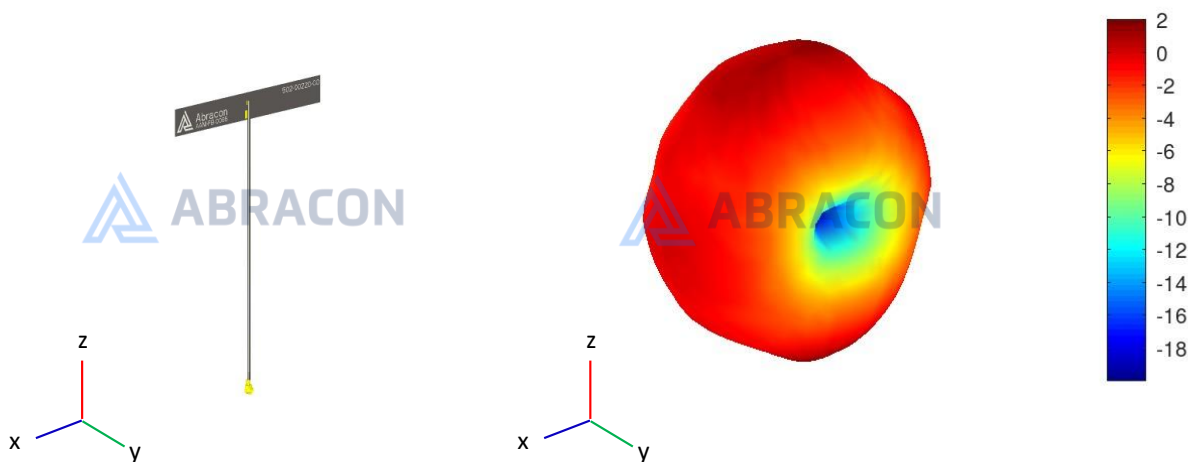

868/915MHz ISM/LoRA Flexible PCB Antenna



AANI-FB-0085

Request Samples



Check Inventory



79 x 10 x 0.2 mm

RoHS Compliant

MSL Level = N/A

Packaging

Number of Antenna/ bags: 50 pcs

Total Pcs / package: 1000 pcs

ATTENTION: Abracon LLC's products are Commercial-Off-The-Shelf ('COTS'), which are designed, intended, and validated for use in commercial, industrial, and automotive applications. The customer is responsible for testing and verifying the performance of an Abracon solution to meet their system-level requirements.



5101 Hidden Creek Ln Spicewood TX 78669
Phone: 512-371-6159 | Fax: 512-351-8858
For terms and conditions of sales, please visit:
www.abracon.com

REVISED: 10-01-24

ABRACON IS
ISO9001-2015
CERTIFIED

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ABRACON:](#)

[AANI-FB-0085-0200I](#)