

32.768kHz SMD LOW PROFILE CRYSTAL

ABS06L

ABS06L

 RoHS/RoHS II Compliant

2.0 x 1.2 x 0.38mm

Moisture Sensitivity Level (MSL) – This product is Hermetically Sealed and not Moisture Sensitive - MSL = N/A: Not Applicable

FEATURES:

- Lowest height kHz package for 32.768kHz Crystals
- 0.38mm height ideal for high density circuit boards
- Ceramic package offers excellent environmental & heat resistance
- Extended temperature -40°C to +85°C for industrial applications

APPLICATIONS:

- Smart Display Credit Cards
- Wide range in communication & measuring equipment
- Commercial & Industrial applications
- Wireless communications
- PDA and Palm Pilots
- Credit Cards with Security Technology

STANDARD SPECIFICATIONS:

Parameters	Minimum	Typical	Maximum	Units	Notes
Frequency	32.768			kHz	
Operation Mode	Flexural Mode (Tuning Fork)				
Operating Temperature	-40		+85	°C	
Storage Temperature	-55		+125	°C	
Frequency Tolerance @+25°C	-20		+20	ppm	See options
Temperature Coefficient	-0.04	-0.03	-0.02	ppm/T ²	
Turn-over temperature	+20	+25	+30	°C	
Equivalent series resistance (ESR)			100	kΩ	
Load capacitance		12.5		pF	See options
Drive Level		0.1	0.5	μW	
Aging (@ 25°C)	-3		+3	ppm	First year
Insulation Resistance	500			MΩ	@ DC 100±15V

OPTIONS AND PART IDENTIFICATION:

(Left blank if standard)

ABS06L - 32.768 kHz - - -

Load Capacitance

Blank: 12.5pF

9: 9pF

Contact Abracon for non-standard capacitance

Frequency Tolerance

Blank: ±20ppm

4: ±30ppm

±10ppm tolerance is available.
Please contact Abracon for more information.

Packaging

Blank: Bulk

T: Tape & Reel
(3000pcs/reel)

32.768kHz SMD LOW PROFILE CRYSTAL


ABS06L

ABS06L

 RoHS/RoHS II Compliant


2.0 x 1.2 x 0.38mm

OUTLINE DRAWING:

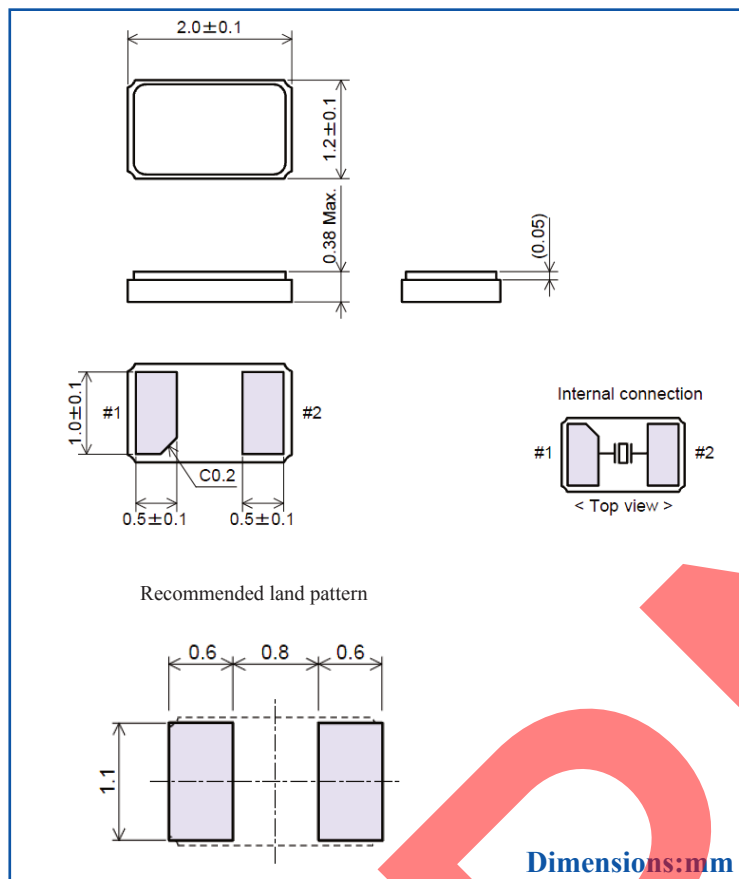


TAPE & REEL:

T=Tape and reel (3,000pcs/reel)

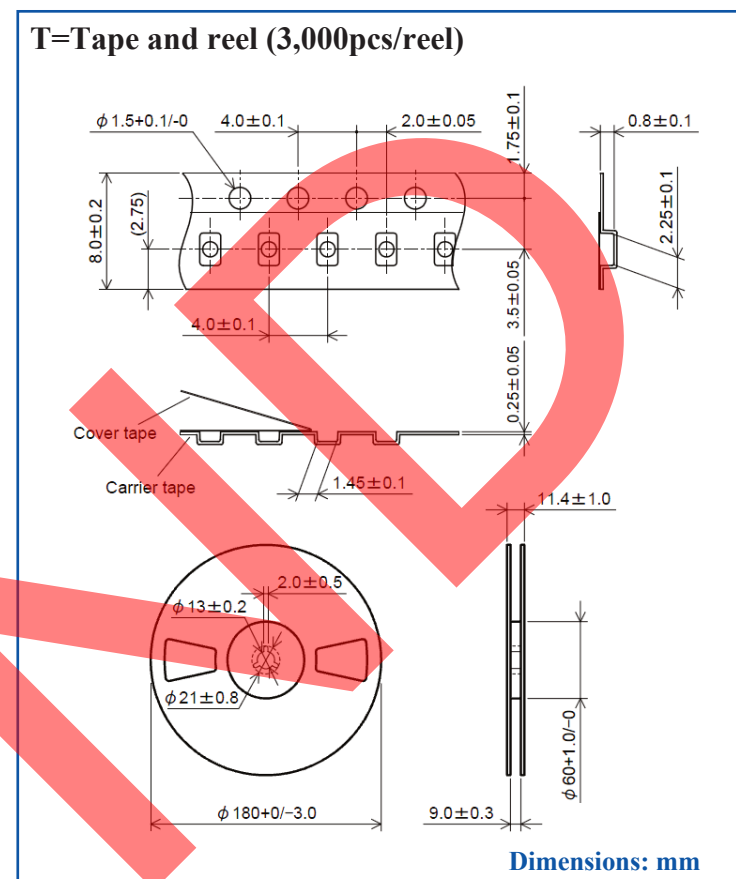

REFLOW PROFILE:

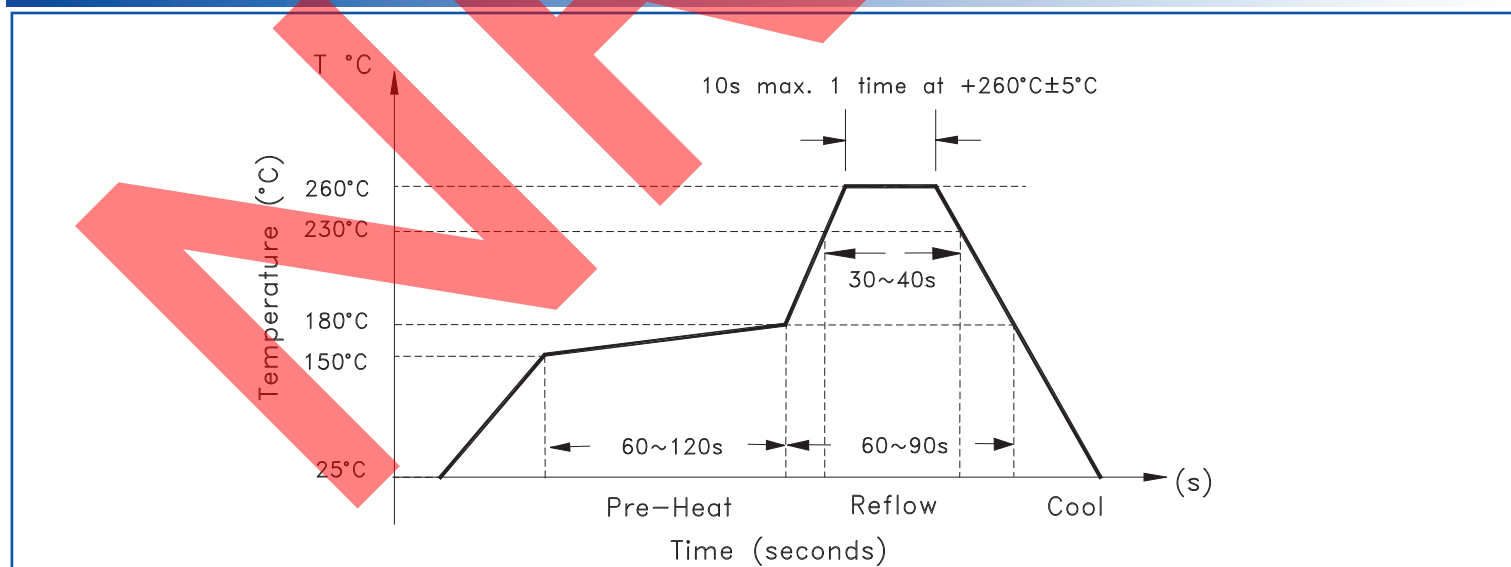

Need a test socket for the ABS06 Series? To view compatible **PRECISION TEST & BURN-IN SOCKETS** for these parts, [click here](#). P/N AXS-2012-02-04

ATTENTION: Abracon Corporation's products are COTS – Commercial-Off-The-Shelf products; suitable for Commercial, Industrial and, where designated, Automotive Applications. Abracon's products are not specifically designed for Military, Aviation, Aerospace, Life-dependant Medical applications or any application requiring high reliability where component failure could result in loss of life and/or property. For applications requiring high reliability and/or presenting an extreme operating environment, written consent and authorization from Abracon Corporation is required. Please contact Abracon Corporation for more information.

ABRACON IS
ISO 9001:2008
CERTIFIED



ABRACON
CORPORATION

Visit www.abracon.com for Terms & Conditions of Sale

30332 Esperanza, Rancho Santa Margarita, California 92688
tel 949-546-8000 | fax 949-546-8001 | www.abracon.com

Revised: 09.21.14

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ABRACON:](#)

[ABS06L-32.768KHZ-T](#)