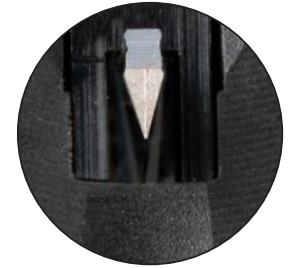



RCS-25

RCS-30


These ratcheting cable slitters are designed to dismantle heavy-duty cables. The RCS-25 and RCS-30 both slit and ring round cables greater than 1" (25 mm) in diameter, and the RCS-30 can also be used to make window cuts in ducts up to 5 mm thick. These slitters feature the following:

- Slit and ring cables made of PVC, PE, rubber, and other jacket materials
- Fixed jaws and ratcheting feature make it easy to grip and slit heavy-duty cable
- Perfect for mid-span or end cable slitting and ringing
- 10, 20, and 30 mm ruler marked on tools for accurate and precise slitting lengths
- Blades are made of steel, ground, and heat-treated for a razor-sharp edge and long term durability
- The aggressive narrow blade design of the RCS-30 allows for mid span entry into ducts and can create widow cuts in the ducts if needed
- Replaceable double-ended blades have an adjustable cutting depth of 0 to 5 mm (0" to 0.20"). The RCS-25RB is the replacement blade for the RCS-25 and the RCS-30RB is the replacement blade for the RCS-30

| SPECIFICATIONS | RCS-25 | RCS-30 | RCS-25RB | RCS-30RB |
|-------------------------------|----------------------------|----------------------------|----------------------------|----------------------------|
| APPLICATION | Cables | Cables & Ducts | Cables | Cables & Ducts |
| MINIMUM CABLE DIAMETER | 0.98" (25 mm) | 0.98" (25 mm) | 0.98" (25 mm) | 0.98" (25 mm) |
| BLADE DEPTH | 0.00"-0.20" (0 mm-5 mm) | 0.00"-0.20" (0 mm-5 mm) | 0.00"-0.20" (0 mm-5 mm) | 0.00"-0.20" (0 mm-5 mm) |
| OVERALL LENGTH | 6" (152 mm) | 6" (152 mm) | 1 1/8" (28.6 mm) | 1 1/8" (28.6 mm) |
| WEIGHT | 0.4 lb (181.43 g) | 0.358 lb (167 g) | 0.045 lb (20.41 g) | 0.043 lb (19.5 g) |
| UPC # | 811490018822 | 811490018693 | 811490018839 | 811490018709 |

MADE FOR LIFE®

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Jonard Industries:](#)

[RCS-30](#) [RC-30RB](#)