

# EmETX-a55E0

## AMD Fusion G-T56N ETX CPU Module



### Features

- Soldered Onboard AMD Fusion G-T56N Processor
- Support LVDS, Analog RGB and DDI Port
- SATA RAID supported
- **Extended Operating Temp.: -20 ~ 70°C**

### System

|                       |                                                                          |
|-----------------------|--------------------------------------------------------------------------|
| <b>CPU</b>            | AMD Fusion G-T56N 1.65GHz processor                                      |
| <b>Memory</b>         | 1 x 204-pin DDR3 SO-DIMM socket, supporting 1066/1333MHz SDRAM up to 4GB |
| <b>Chipset</b>        | AMD FCH A55E                                                             |
| <b>BIOS</b>           | AMI PnP Flash UEFI BIOS                                                  |
| <b>Watchdog Timer</b> | 1~255 levels reset                                                       |

### I/O

|                         |                                                                     |
|-------------------------|---------------------------------------------------------------------|
| <b>Super IO Chipset</b> | Fintek F71869ED                                                     |
| <b>Serial Port</b>      | 2 x COM ports                                                       |
| <b>Parallel Port</b>    | SPP/EPP/ECP mode selectable                                         |
| <b>USB Port</b>         | 4 x USB 2.0 ports                                                   |
| <b>KB/MS</b>            | PS/2 interface for Keyboard and Mouse                               |
| <b>Expansion Bus</b>    | PCI (4 x PCI masters) and ISA bus<br>LPC (Low Pin Count) connector  |
| <b>Storage</b>          | 2 x Serial ATA ports with 600MB/s HDD transfer rate                 |
| <b>Ethernet Chipset</b> | 1 x Realtek 8105E PCIe 10/100Base-T Ethernet controller             |
| <b>Audio Interface</b>  | Realtek ALC886 7.1 Channel HD Audio CODEC, Mic-in/ Line-in/Line-out |

### Display


|                           |                                                                             |
|---------------------------|-----------------------------------------------------------------------------|
| <b>Graphics Chipset</b>   | Integrated in AMD G-series processor<br>Analog RGB supports up to 2560x1600 |
| <b>Graphics Interface</b> | LCD: Dual Channels 24-bit LVDS<br>1 x DDI port                              |

All specifications are subject to change without notice.


### Mechanical & Environmental

|                           |                           |
|---------------------------|---------------------------|
| <b>Power Requirement</b>  | +5V, 5VSB                 |
| <b>Power Consumption</b>  | 3.23A@+5V (Typical)       |
| <b>Operating Temp.</b>    | -20 ~ 70°C (-4 ~ 158°F)   |
| <b>Operating Humidity</b> | 0 ~ 95% (non-condensing)  |
| <b>Dimension (L x W)</b>  | 114 x 95 mm (4.5" x 3.7") |

### Dimensions

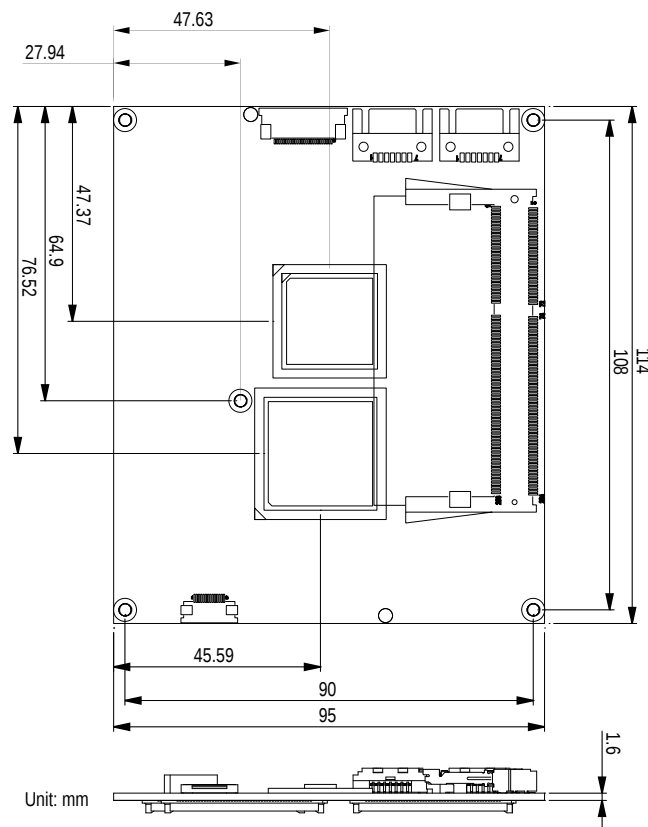

## Block Diagram

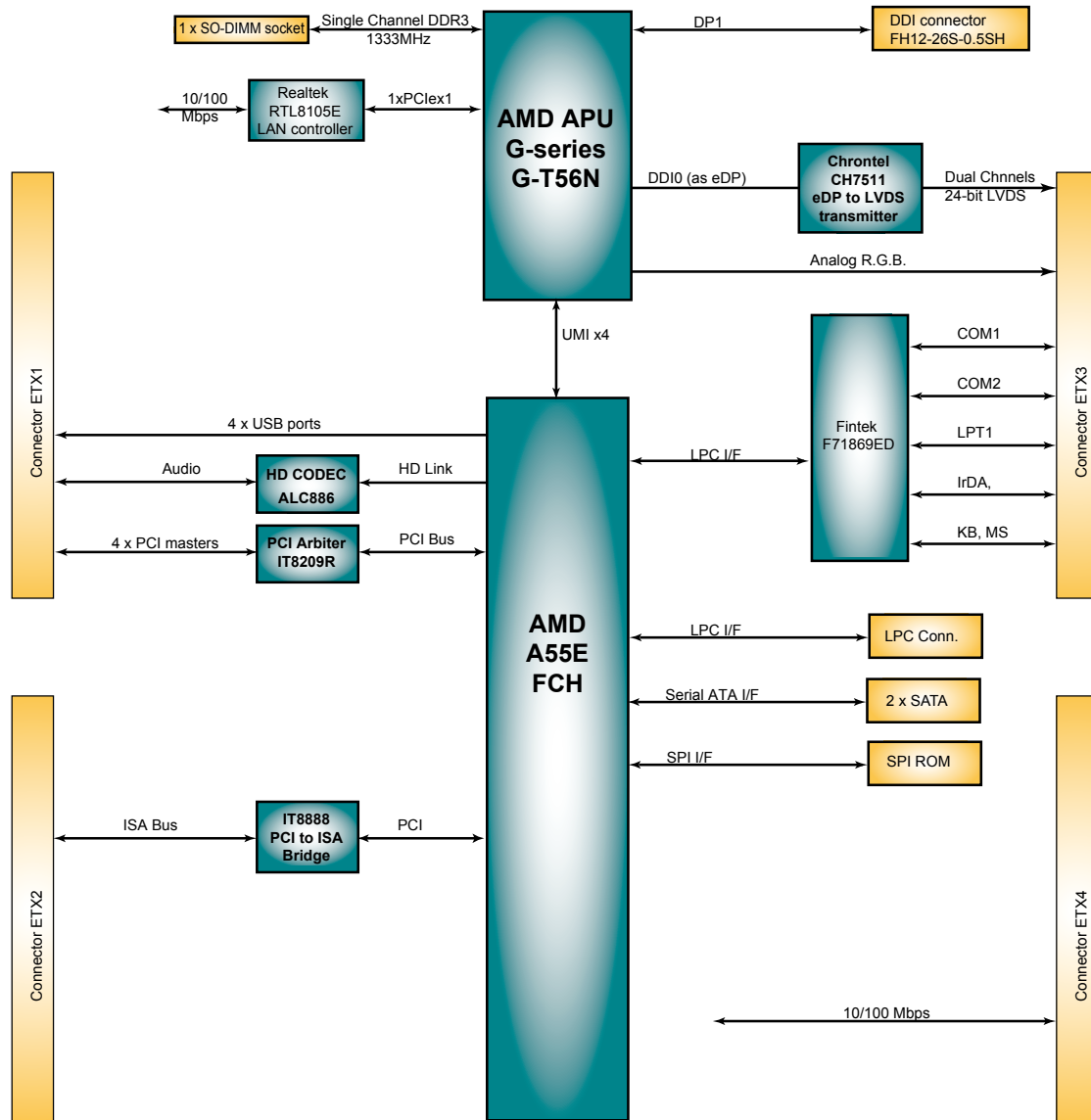

## Ordering Information

|                         |                                                                     |
|-------------------------|---------------------------------------------------------------------|
| <b>EmETX-a55E0-T56N</b> | AMD G-T56N Dual Core ETX CPU Module                                 |
| <b>HS-55E0-F1</b>       | Heat spreader (114x95x18mm)                                         |
| <b>HS-55E0-C1</b>       | CPU module cooler for 18W APU (114x95x29mm)                         |
| <b>PBE-1000 R2.1</b>    | ETX® evaluation board in ATX form factor                            |
| <b>CBK-05-1000-00</b>   | Cable kit<br>3 x COM port cables<br>1 x USB cable<br>2 x IDE cables |

Page 56

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ARBOR Technology:](#)

[HS-55E0-C1](#)