

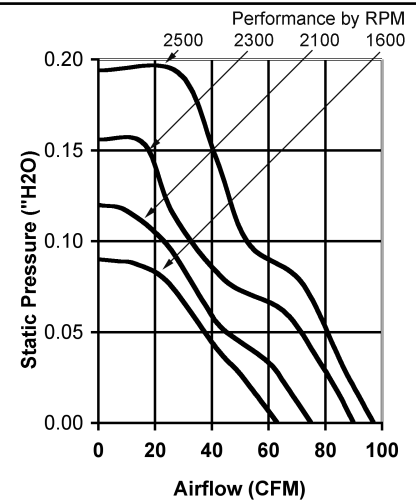
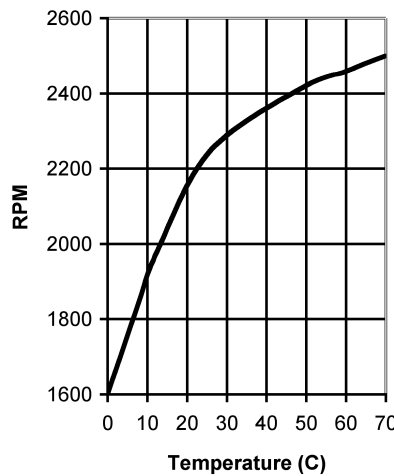



Temperature Control Series

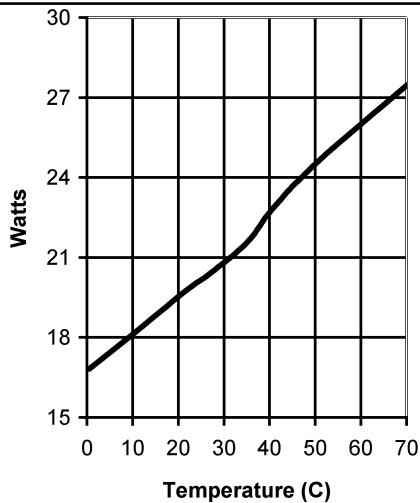

AC SMART FAN 120x38mm (4.7"x 1.5")

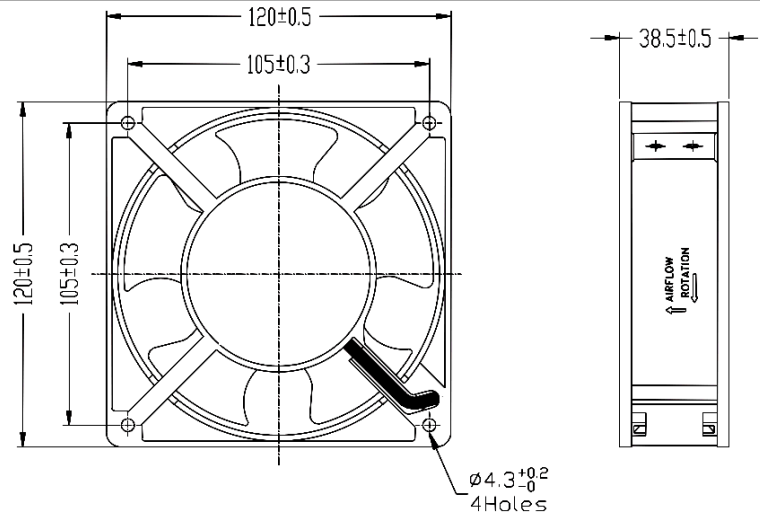

Part Number	OA109AP-11-1TB03
Frame	Aluminum Alloy
Impeller	PBT, UL94V-O plastic
Connection	Terminal
Motor	AC shaded pole, impedance overload protected
Bearing System	Dual ball
Insulation Resistance	>100M ohm between leadwire and frame (500VDC)
Dielectric Strength	1 min at 1500 VAC, 50/60Hz
Nominal Voltage	115 VAC (60Hz)
Nominal Current (0C ~ 70C)	0.20 ~ 0.25 A
Rated Power (0C ~ 70C)	16 ~ 27.6 W
Rated Speed (RPM) (0C ~ 70C)	1600 ~ 2500
Airflow (CFM)	63 ~ 100
Noise Level (dB)	37 ~ 45
Operating Temperature	-10C ~ +70C
Life Expectancy	60,000 hours L10 @ 40C

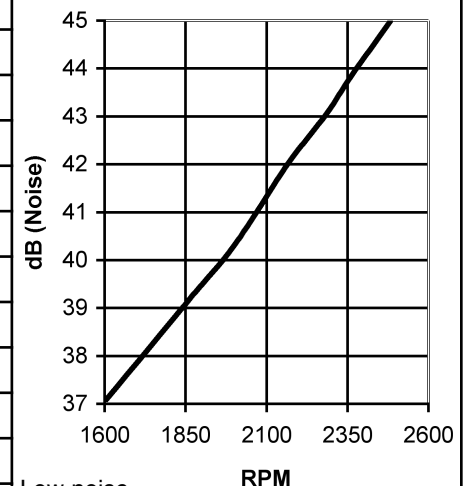

Low noise
Low power consumption
Ultra Low speed operation

OPTIONS

Automatic thermal control, hub mounted
or lead mounted
Manual Speed Control

10557 Metric Drive
Dallas, Texas 75243
214-340-0265



OrionFans.com
Information and data is subject to
change without prior notification.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OA109AP-11-1TB03](#)