
 
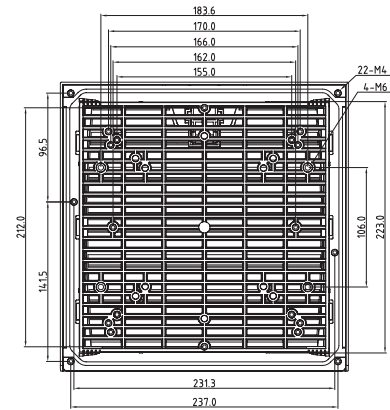


Louvered Fan Guards (hinged type)


Easy Access to Media



LFGH200 for
200mm fan

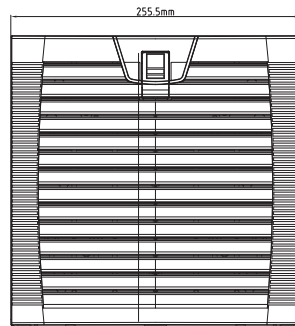

| | |
|----------------------|--|
| Part Number | LFGH200 |
| Frame Description | ABS Resin - flame resistant UL94V-0, with UV protection. Vents with screens at 45-degree angle. Includes high foam sealing edge - protection grade IP44-IP54. Snap-fit or screw mount. |
| Filter Mesh Material | Nylon Fiber - Synthetic Resin, filters to 8 microns. |
| Color | Gray is standard. Black is available upon request. Minimums may apply. |
| Matching Series | OA200AN, OD172, OA162, OA172S, OA5920, OA225, OA180, OD180 |
| Hardware | 1 bag - 6 ea. M4x8, washer, lock washer 1 bag - 4 ea. M4x12, nut, star washer 1 bag - 4 ea. M6x12, washer, lock washer |

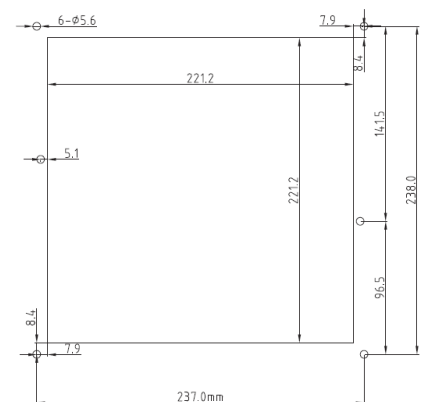

PANEL CUTOUT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

LFGH200