


# OA109EC XC Series



EC Fan Universal Voltage  
120x38mm (4.72" x 1.50")

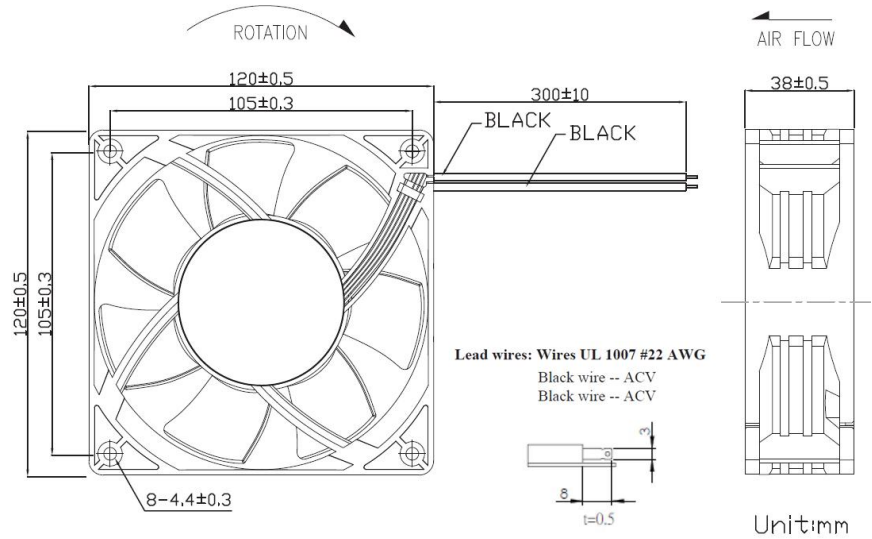

Frame	PBT UL94V0- Plastic	<u>Operating Temperature</u> -10°C ~ +70°C  <u>Storage Temperature</u> -40°C ~ +75°C  <u>Life Expectancy</u> 70,000 hours (L10 at 40°C)  Weight: ~ 0.68 lbs  m0	
Impeller	PBT UL94V0- Plastic		
Connection	Wire Leads or Terminals		
Motor	AC-DC Energy Saving, Electronically Protected		
Bearing System	Dual Ball Bearings		
Dielectric Strength	1500VAC/min		

Part Number	OA109EC-UR-1*XC
Rated Voltage	110/220 VAC
Voltage Range	85 ~ 256
Rated Input	10 ~ 8 (6.5)W
Rated Speed (RPM)	3000
Airflow (CFM)	133.8
Noise Level (dB)	47
Max. Static Pressure	0.42"H <sub>2</sub> O

\*Indicate "TB" (Terminal Ball Bearing), "WB" (Wire Leads, Ball Bearing)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OA109EC-UR-1WBXC](#) [OA109EC-UR-1TBXC](#)