



OA200AP-IP69K Series



AC Fan - 115V, 230V
220x72mm (8.7"x2.8")

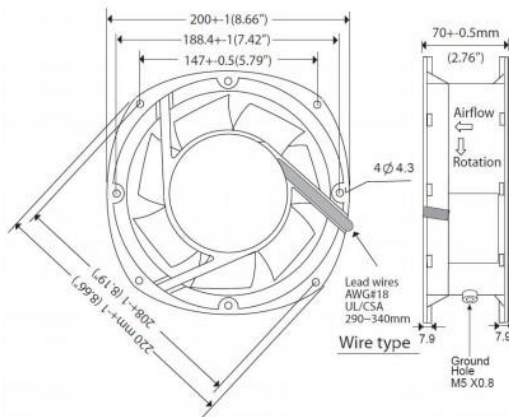

Frame	Die Cast Aluminum, Black Finish	<u>Operating Temperature</u> -30°C ~ +80°C <u>Storage Temperature</u> -40°C ~ +100°C <u>Life Expectancy</u> 50,000 hours (L10 at 55°C) <u>Available Options</u> Tachometer Alarm PWM Weight: 4.63 lbs m0
Impeller	Steel, All Metal, 7 Blades	
Connection	Lead Wires 18 AWG or Terminal	
Motor	AC, Outer Rotor, Capacitor Induction, Single Phase, Thermally Protected, IP69K	
Bearing System	Dual Ball Bearings	
Dielectric Strength	1500VAC/min	
Insulation Resistance	Over 100MΩ at DC 500V	

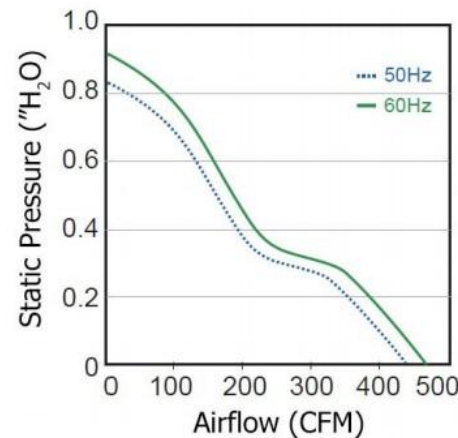

Part Number	Rated Voltage	Input Power	Frequency	Rated Speed (RPM)	Airflow (CFM)	Noise Level (dB)	Max. Static Pressure
OA200AP-11-1*B1869K	115 VAC	105 W	60Hz	3300	485	68	0.93" H ₂ O
OA200AP-22-1*B1869K	230 VAC	105 W	60Hz	3300	485	68	0.93" H ₂ O

*Insert "T" for Terminal or "W" for Lead Wire

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OA200AP-11-1TB1869K](#) [OA200AP-11-1WB1869K](#) [OA200AP-22-1TB1869K](#) [OA200AP-22-1WB1869K](#)