


OA225AP-IP69K Series



AC All Metal Axial Fan - 115V, 230V
225x80mm (8.9"x3.1")

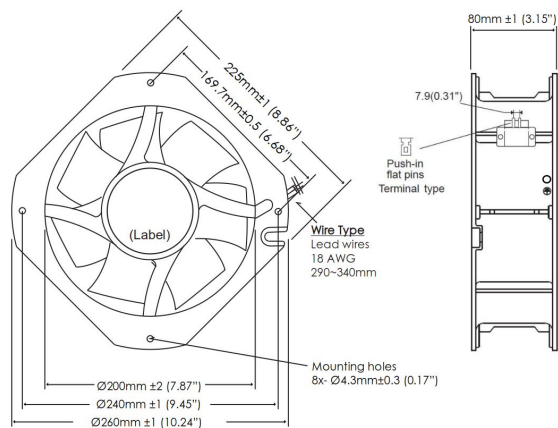

Frame	Die Cast Aluminum, Black	<u>Operating Temperature</u> -30°C ~ +80°C	
Impeller	7 Blade, All Metal	<u>Storage Temperature</u> -40°C ~ +100°C	
Connection	2x Lead Wires, 18 AWG	<u>Life Expectancy</u> 45,000 hours (L10 at 55°C)	
Motor	AC, Outer Rotor, Capacitor Induction, Single Phase, Thermally Protected IP69K	<u>Available Options</u> Tachometer Alarm Other Speeds Available	
Bearing System	Dual Ball Bearings	Weight: 4.81 lbs	
Dielectric Strength	1500VAC/min, 50/60Hz, 2mA	m0	
Insulation Resistance	Over 100M ohm (500 VDC)		

Part Number	Rated Voltage	Input Power	Frequency	Rated Speed (RPM)	Airflow (CFM)	Noise Level (dB)	Max. Static Pressure
OA225AP-11-1*BIP69K	115 VAC	80 W	60Hz	3100	620	66	0.74" H ₂ O
OA225AP-22-1*BIP69K	230 VAC	80 W	60Hz	3100	620	66	0.74" H ₂ O

*Insert "T" for Terminal or "W" for Lead Wire

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OA225AP-11-1TB1869K](#) [OA225AP-11-1WB1869K](#) [OA225AP-22-1TB1869K](#) [OA225AP-22-1WB1869K](#)