


OA406 Fan Tray

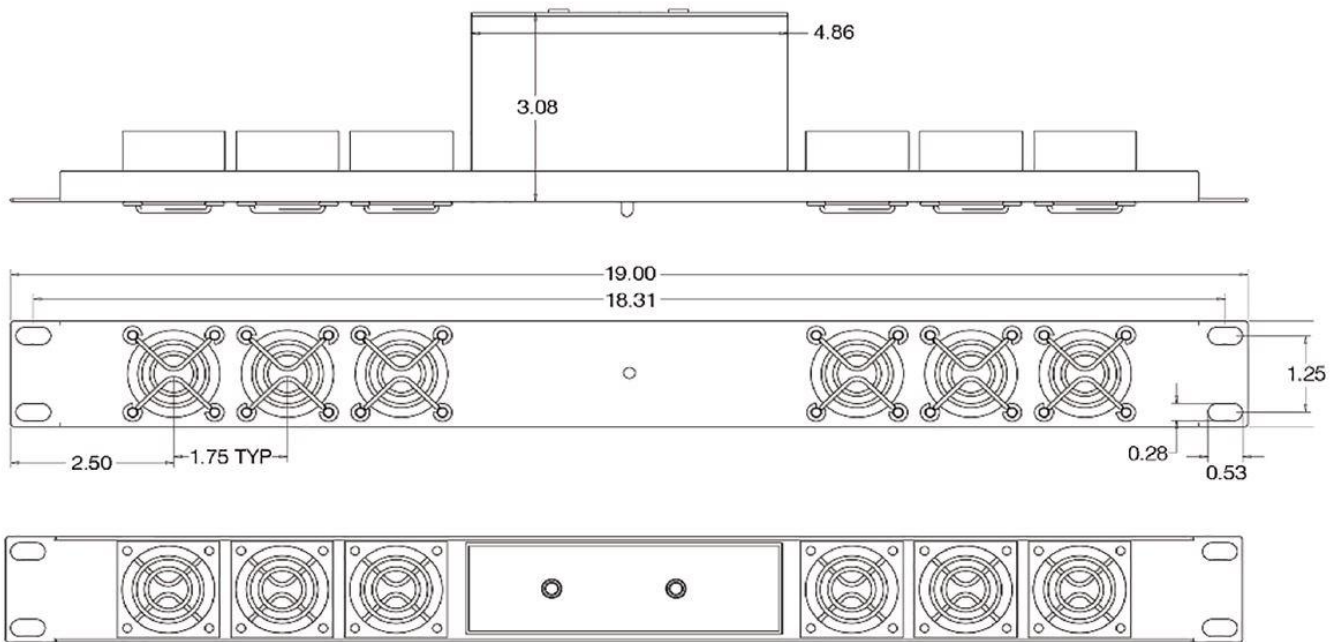

Universal Input 90 -264VAC



Switching AC/DC Adaptor	12V	<u>Operating Temperature</u> -10C ~ +50C, 20 - 90% RH
Output Power	60 W (Max load 5 A)	<u>Storage Temperature</u> -40 ~ +85C, 10 - 95% RH

Description	<ul style="list-style-type: none"> • Universal 90-264VAC Input external power supply • 1U high, panel mount configuration • Either N. American NEMA 5-15P or IEC320-C14 connection • High Airflow of 160CFM provided by 6x Orion OD4028-12HBXC • Bi-color LED alarm indicator lamp • Optional redundant 2nd power supply available • Redundant power switching is seamless and automatic • Redundant power input may be from customers 12VDC supply • Sturdy 16 Ga Powder Coated Steel Construction
-------------	--

OA406	Power Input NEMA 5-15 plug
OA406-IEC	C14 power supply plug
OA406-DUAL	With redundant power supply
OA406-IEC-DUAL	With redundant power supply, international version
OA406-PS:	Add-on power supply. Converts OA406 to DUAL
OA406-IEC-PS	Add-on power supply. International version



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OA406-PS](#) [OA406](#) [OA406-IEC-DUAL](#) [OA406-IEC-PS](#) [OA406-IEC](#) [OA406-DUAL](#)