


# OA80EC Series



EC Fan Universal Voltage  
80x38mm (3.15" x 1.50")

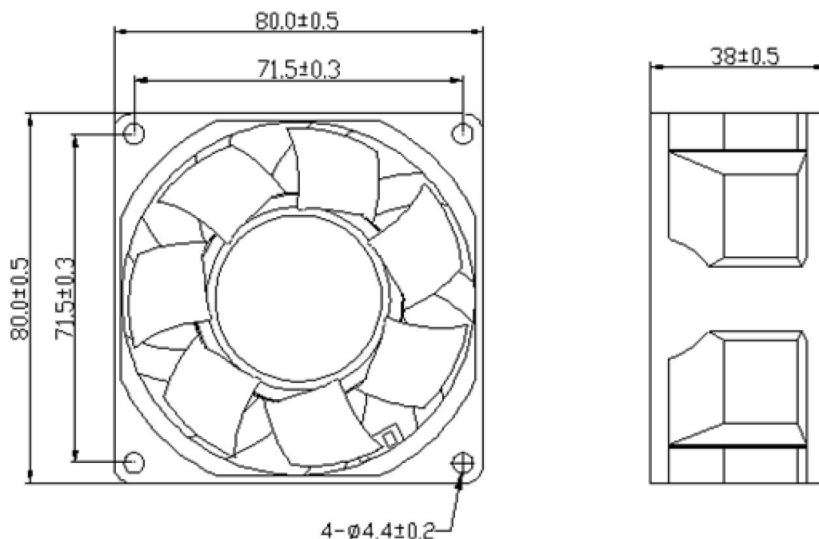

Frame	PBT UL94V0- Plastic	<u>Operating Temperature</u> -10C ~ +70C  <u>Storage Temperature</u> -40C ~ +75C  <u>Life Expectancy</u> 70,000 hours (L10 at 40C)  Weight: ~ 0.39 lbs  m0	
Impeller	PBT UL94V0- Plastic		
Connection	Wire Leads		
Motor	AC-DC Energy Saving, Electronically Protected		
Bearing System	Dual Ball Bearings		
Dielectric Strength	1500VAC/min		

Part Number	OA80EC-UR-1WB
Rated Voltage	110/220 VAC
Voltage Range	85 ~ 265
Rated Input	7 ~ 5 (1.5)W
Rated Speed (RPM)	3000
Airflow (CFM)	39
Noise Level (dB)	32
Max. Static Pressure	0.22"H <sub>2</sub> O

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OA80EC-UR-1WB](#)