


OA9232EC Series



EC Fan Universal Voltage
92x32mm (3.62" x 1.26")

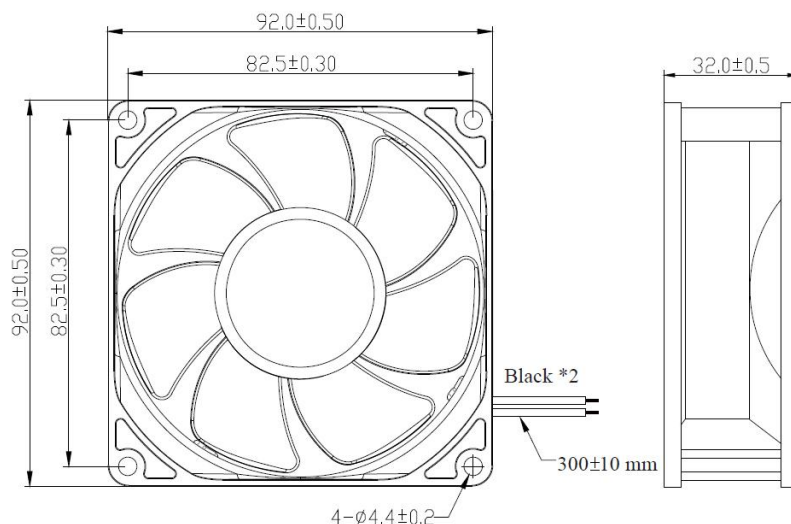

| | | | |
|---------------------|---|---|--|
| Frame | PBT UL94V0- Plastic | <u>Operating Temperature</u> -10C ~ +70C <u>Storage Temperature</u> -40C ~ +75C <u>Life Expectancy</u> 70,000 hours (L10 at 40C) Weight: ~ 0.31 lbs m0 | |
| Impeller | PBT UL94V0- Plastic | | |
| Connection | Wire Leads | | |
| Motor | AC-DC Energy Saving, Electronically Protected | | |
| Bearing System | Dual Ball Bearings | | |
| Dielectric Strength | 1500VAC/min | | |

| | |
|----------------------|-----------------------|
| Part Number | OA9232EC-UR-1WB |
| Rated Voltage | 110/220 VAC |
| Voltage Range | 85 ~ 265 |
| Rated Input | 8 ~ 6 (2.1)W |
| Rated Speed (RPM) | 3000 |
| Airflow (CFM) | 58 |
| Noise Level (dB) | 43 |
| Max. Static Pressure | 0.23"H ₂ O |

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OA9232EC-UR-1WB](#)