



OAB18055 Series

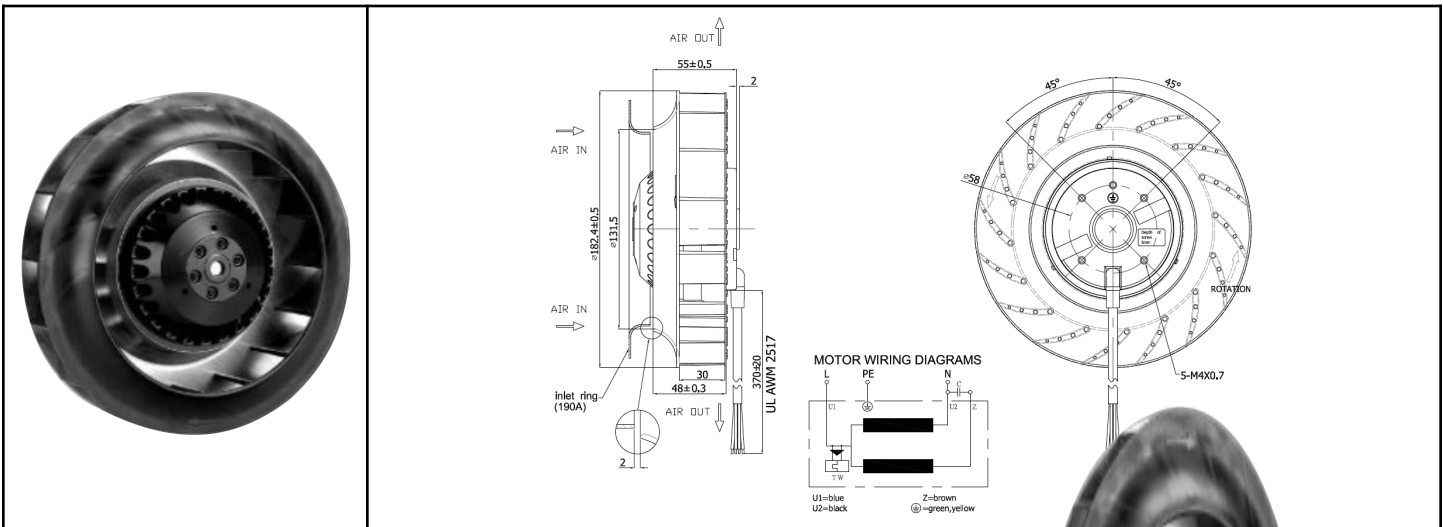

AC Blower, ball bearing
182x55 (7.17"x 2.17")



Backwards Curved Impeller

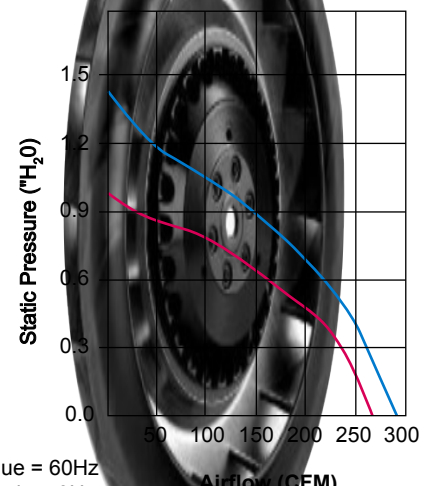Frame & Impeller	Frame - Diecast aluminum Impeller - UL94V-O Thermoplastic	<u>Insulation Housing:</u> AC1500V / 1 minute <u>Insulation Resistance:</u> > 100 M ohms DC500V <u>Operating Temperature</u> -40 C ~ +60C <u>Life Expectancy</u> 40,000 hours (L10, 40C) Ball bearing IP55 Rated Weight 2.65 lbs. m2	 Blue = 60Hz Red = 50Hz
Connection	Lead Wires		
Motor	AC Capacitor drive 10uF/250V (115V) 2uF/450V (230V) (Capacitor Included)		
Bearing System	Dual Ball		

Part Number	OAB18055-11-1WB	OAB18055-23-1WB
Nominal Voltage	115 VAC (50/60 Hz)	230 VAC (50/60 Hz)
Nominal Current (Amps)	0.60 / 0.70	0.30 / 0.34
Locked Current (Amps)	0.92 / 0.95	0.46 / 0.48
Rated Power	63 / 78 W	63 / 78 W
Rated Speed (RPM)	2550 / 2800	2550 / 2800
Airflow (CFM)	265 / 290	265 / 290
Noise Level (dB)	64 / 67	64 / 67
Max. Static Pressure	1.0 / 1.4" H ₂ O	1.0 / 1.4" H ₂ O

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OAB18055-11-1WB](#) [OAB18055-22-1WB](#)