


OAB22569 Series



AC Blower, ball bearing
225x69 (8.86"x 2.72")

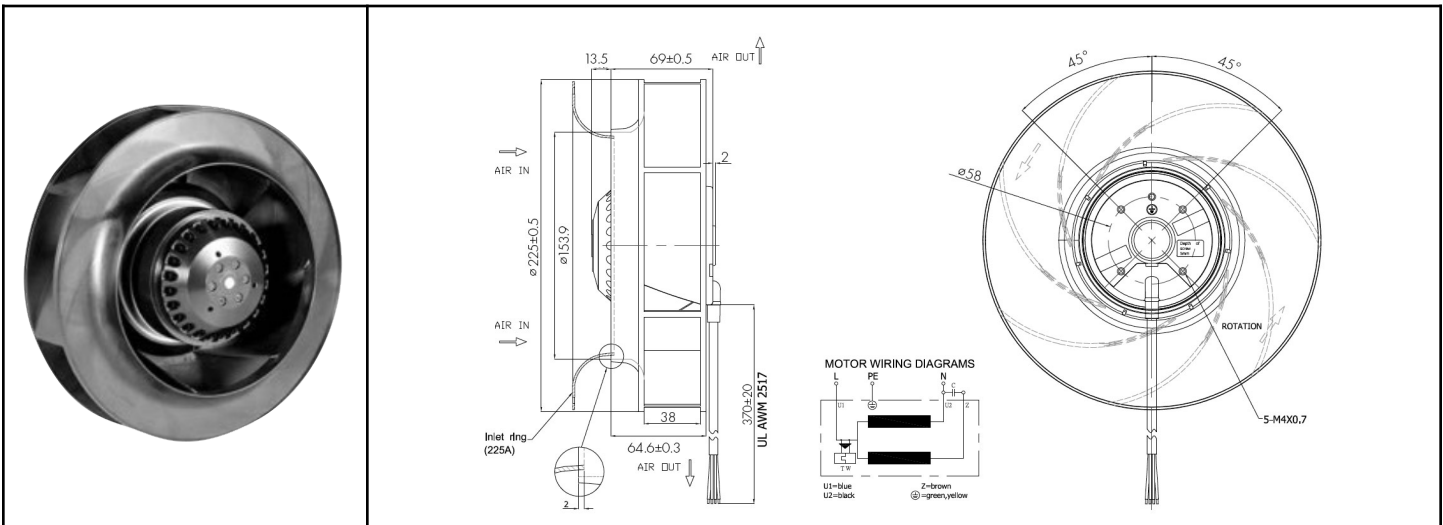

Backwards Curved Impeller

Frame & Impeller
Frame - Diecast aluminum
Impeller - UL94V-O Thermoplastic

Connection
Lead Wires

Motor
AC Capacitor drive
12uF/250V (115V)
3uF/450V (230V)
(Capacitor Included)

Bearing System
Dual Ball

Insulation Housing:

AC1500V / 1 minute

Insulation Resistance:

> 100 M ohms DC500V

Operating Temperature

-40 C ~ +60C

Life Expectancy


40,000 hours (L10, 40C)

Ball bearing

IP55 Rated

Weight 5.1 lbs.

m2

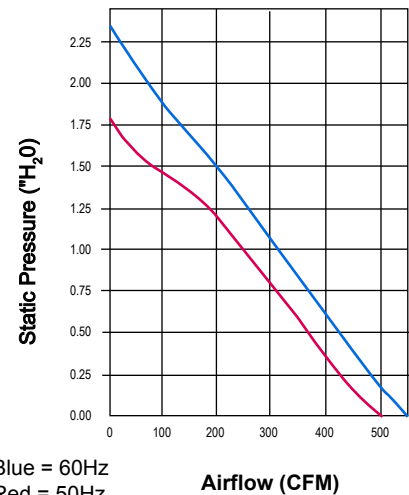

Part Number	OAB22569-11-1WB	OAB22569-22-1WB
Nominal Voltage	115 VAC (50/60 Hz)	230 VAC (50/60 Hz)
Nominal Current (Amps)	1.11 / 1.12	0.54 / 0.56
Locked Current (Amps)	2.22 / 2.30	1.14 / 1.15
Rated Power	105 / 125 W	105 / 125 W
Rated Speed (RPM)	2650 / 2950	2650 / 2950
Airflow (CFM)	500 / 550	500 / 550
Noise Level (dB)	70 / 72	70 / 72
Max. Static Pressure	1.8 / 2.3" H ₂ O	1.8 / 2.3" H ₂ O

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OAB22569111WB](#) [OAB22569221WB](#)