


OD1238-IP68 Series



DC Fan, 12, 24, 48V
120x38mm (4.7"x1.5")

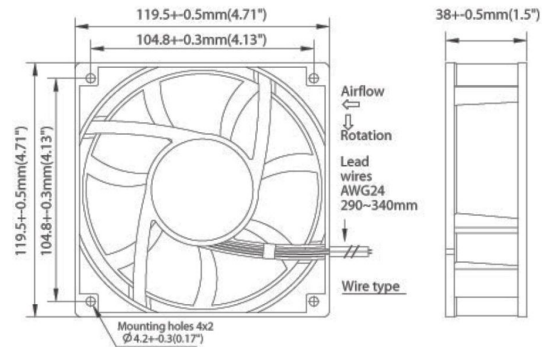

Frame	PBT, UL94 V-0 plastic	Operating Temperature -15°C ~ +65°C Storage Temperature -25°C ~ +70°C Life Expectancy 65,000 hours (L10 at 45°C) Available Options Tachometer Alarm PWM High Performance Available Weight: 0.57 lbs m0	
Impeller	PBT, UL94 V-0 plastic		
Connection	2x Lead wires 24 AWG		
Motor	Brushless DC, Auto Restart, Polarity Protected, Electronically Protected IP68		
Bearing System	Dual Ball Bearings		
Dielectric Strength	500VAC/min		
Insulation Resistance	10M ohm between leadwires and frame (500 VDC)		

Part Number	Rated Voltage	Input Power	Rated Current	Rated Speed (RPM)	Airflow (CFM)	Noise Level (dB)	Max. Static Pressure
OD1238-12HHBIP68	12 VDC	10 W	0.90 A	3200	136	48	0.56"H ₂ O
OD1238-12HBIP68	12 VDC	6.0 W	0.50 A	2900	124	44	0.47"H ₂ O
OD1238-12MBIP68	12 VDC	4.8 W	0.40 A	2600	115	41	0.43"H ₂ O
OD1238-24HHBIP68	24 VDC	11 W	0.48 A	3200	136	48	0.56"H ₂ O
OD1238-24HBIP68	24 VDC	12 W	0.5 A	2900	124	44	0.47"H ₂ O
OD1238-24MBIP68	24 VDC	8 W	0.34 A	2600	115	41	0.43"H ₂ O
OD1238-24LBIP68	24 VDC	5 W	0.19 A	2300	103	38	0.34"H ₂ O
OD1238-48HHBIP68	48 VDC	15 W	0.3 A	3200	136	48	0.56"H ₂ O
OD1238-48HBIP68	48 VDC	14 W	0.29 A	2900	124	44	0.47"H ₂ O
OD1238-48MBIP68	48 VDC	7 W	0.14 A	2600	115	41	0.43"H ₂ O
OD1238-48LBIP68	48 VDC	5 W	0.09 A	2300	103	38	0.34"H ₂ O

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OD1238-24MBIP68](#) [OD1238-48LBIP68](#) [OD1238-12MBIP68](#) [OD1238-24HBIP68](#) [OD1238-12HBIP68](#) [OD1238-24LBIP68](#) [OD1238-12HHBIP68](#) [OD1238-48MBIP68](#) [OD1238-48HBIP68](#) [OD1238-24HHBIP68](#) [OD1238-48HHBIP68](#)