


OD9238-IP68 Series



DC Fan, 24, 48V
92x38mm (3.62"x1.5")

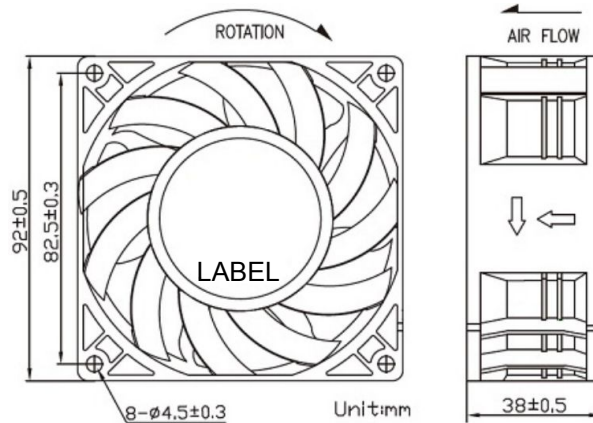

Frame	PBT, UL94V-0 plastic	<u>Operating Temperature</u> -10°C ~ +70°C	
Impeller	PBT, UL94V-0 plastic	<u>Storage Temperature</u> -40°C ~ +75°C	
Connection	2x Lead wires, 24 AWG	<u>Life Expectancy</u> 60,000 hours (L10 at 45°C)	
Motor	Brushless DC, Auto Restart, Polarity Protected, Electronically Protected, IP68	<u>Available Options</u> Tachometer Alarm PWM	
Bearing System	Dual Ball Bearings	Weight: 0.44 lbs	
Dielectric Strength	500VAC/min	m0	
Insulation Resistance	10M ohm between leadwires and frame (500 VDC)		

Part Number	Rated Voltage	Input Power	Rated Current	Rated Speed (RPM)	Airflow (CFM)	Noise Level (dB)	Max. Static Pressure
OD9238-24HHBIP68	24 VDC	10.8 W	0.45 A	5000	110	58	0.86"H ₂ O
OD9238-24HBIP68	24 VDC	9.6 W	0.4 A	4500	100	56	0.7"H ₂ O
OD9238-24MBIP68	24 VDC	7.2 W	0.3 A	4000	89	53	0.55"H ₂ O
OD9238-24LBIP68	24 VDC	4.8 W	0.2 A	3500	78	50	0.42"H ₂ O
OD9238-48HHBIP68	48 VDC	14.4 W	0.3 A	5000	110	58	0.86"H ₂ O
OD9238-48HBIP68	48 VDC	12 W	0.25 A	4500	100	56	0.7"H ₂ O
OD9238-48MBIP68	48 VDC	9.6 W	0.2 A	4000	89	53	0.55"H ₂ O
OD9238-48LBIP68	48 VDC	7.2 W	0.15 A	3500	78	50	0.42"H ₂ O

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OD9238-24HBIP68](#) [OD9238-48MBIP68](#) [OD9238-24LBIP68](#) [OD9238-48HHBIP68](#) [OD9238-48LBIP68](#) [OD9238-24MBIP68](#) [OD9238-24HHBIP68](#) [OD9238-48HBIP68](#)