


High Density Specialty Filter

LFG254FHD

 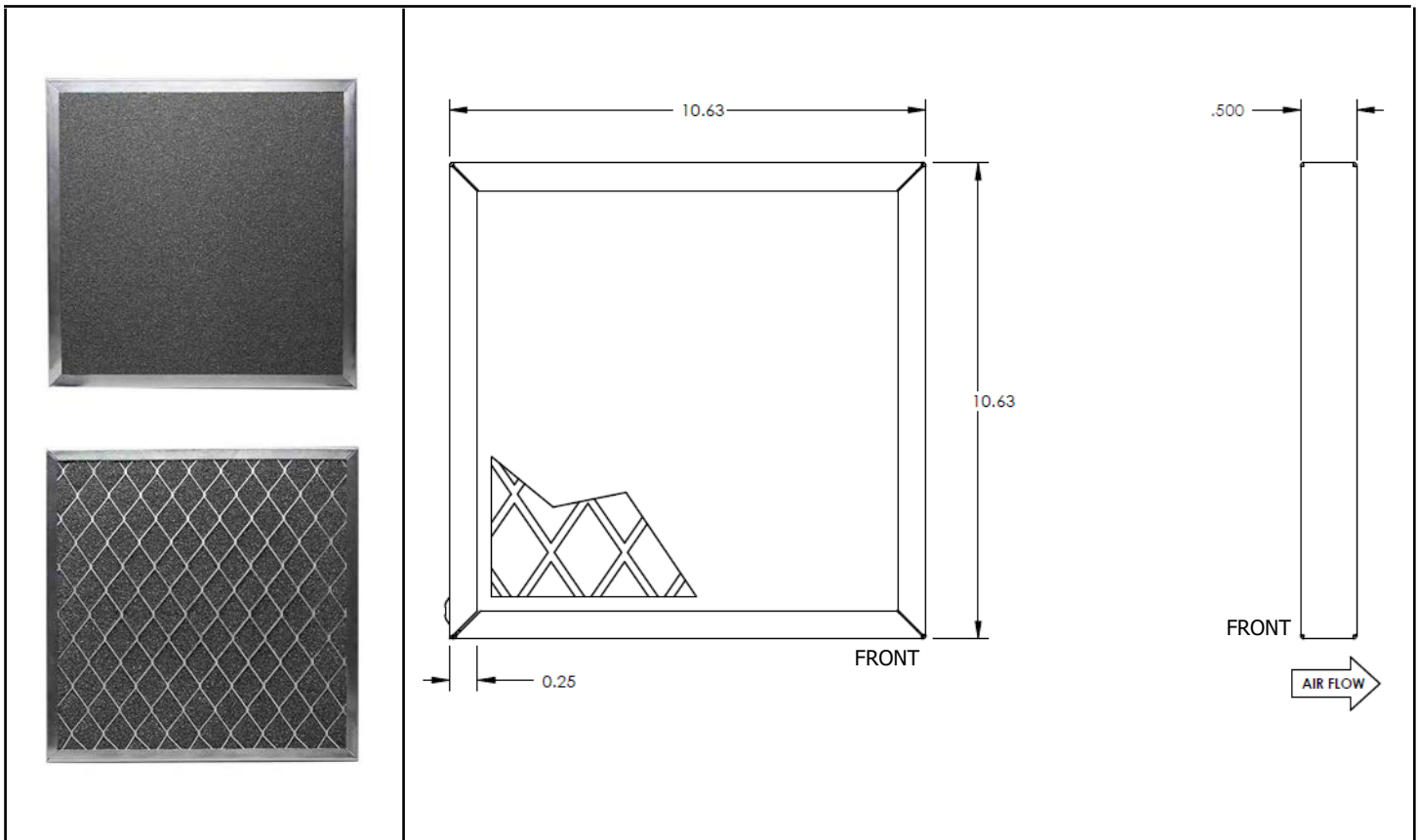


270 x 270 x 12.7mm (10.63" x 10.63" x 0.50")



Orion Fans high density air filters offer low pressure drop, fire resistance and the ability to capture large amounts of airborne dust in industrial enclosure applications. Designed for use in equipment where permanent, cleanable filters are most appropriate, these filters are ideal in networking, telecom and communications enclosures.

Part Number	LFG254FHD
Frame Description	Aluminum
Filter Material	45 PPI Gray High Density Foam, UL94 HF-1
Rivet Description	Aluminum
Grid Description	Aluminum Uni-grid support on downstream side
Matching Louvered Guards	LFG254, LFGS254, LFGH254, LFGS280, LFGH280



Standards & Classifications

UL 900-2004, UL 94 HF-1
NEBS GR-63-CORE
NEBS GR-78-CORE
NEMA
IP

MIL-STD
ATCA
MicroTCA
CompactPCI
FMVSS302

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

LFG254FHD