

CR123A

LITHIUM MANGANESE DIOXIDE




Features & Benefits

- Operating temperature range between -40°C to $+70^{\circ}\text{C}$
- High current pulse discharge capability
- Stable voltage level during discharge
- High safety and reliability


Specifications

Nominal Capacity:	1550 mAh
Nominal Voltage:	3V
Weight:	Approximately 17g
Operating Temperature:	-40°C - $+70^{\circ}\text{C}$

Dimensions

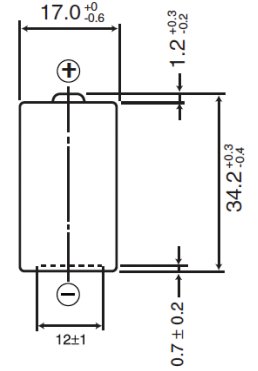


Temperature Characteristics

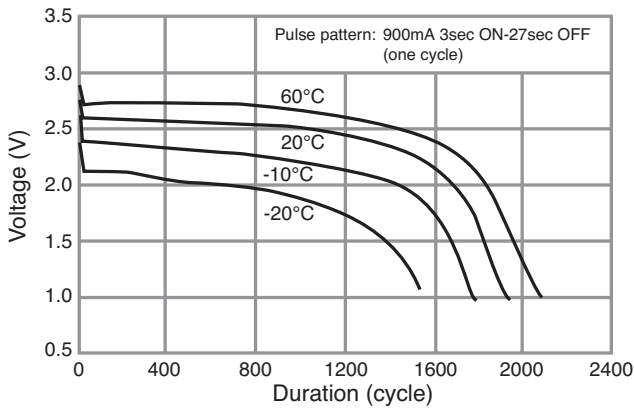


*Please consult Panasonic for use below and above -20°C to $+60^{\circ}\text{C}$


Continuous Discharge Characteristics (60°C)

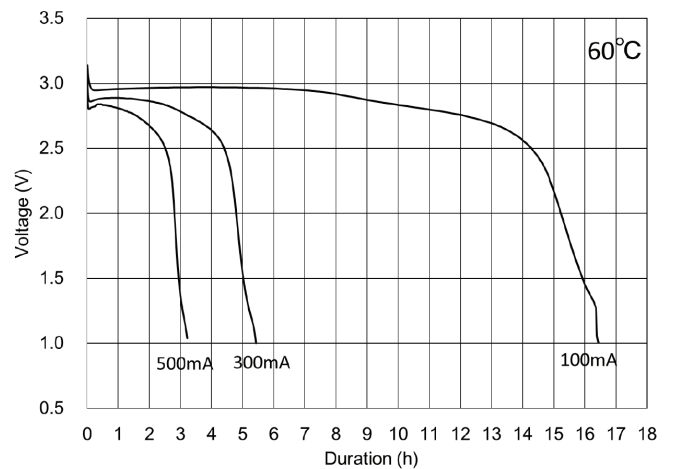

Continuous Discharge Characteristics (20°C)

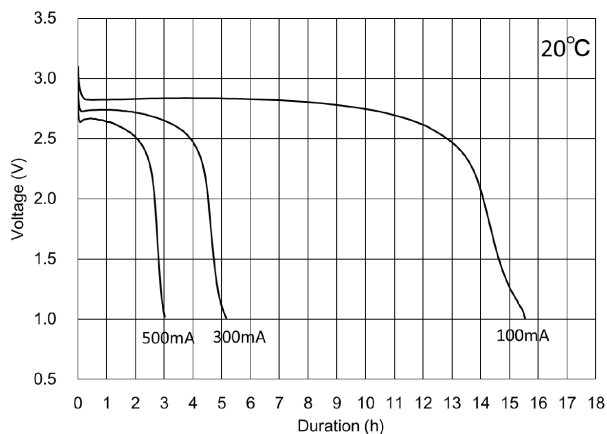

Continuous Discharge Characteristics (-20°C)

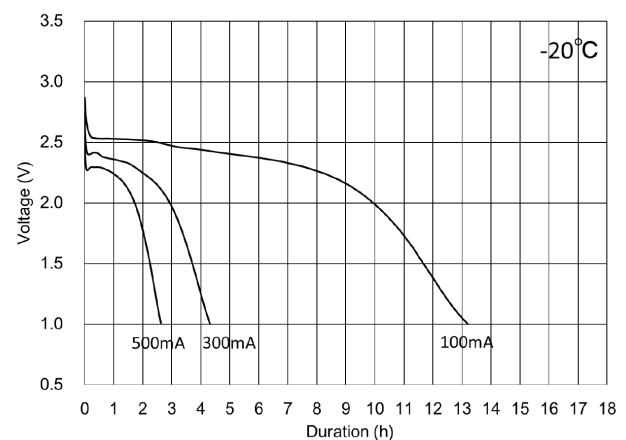

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Panasonic:](#)

[CR123A](#)