

NOTES

1. HIGH STRENGTH ELECTROLYTIC COPPER HIGHLY RESISTANT TO CORROSION AND SEASON CRACKING.
2. FOR COPPER AND COPPERWELD WIRES ONLY.
3. *CONNECTOR CAN BE USED WITH 3 WIRES, BUT IS NOT CSA APPROVED WITH 3 WIRES.
4. **THE CONDUCTOR SIZES SHOWN ARE FOR EQUAL RUN AND TAP COMBINATIONS FOR BOTH SOLID AND STRANDED UNLESS OTHERWISE LISTED.
5. PARTS ARE UL LISTED TO UL467 AND UL486. PARTS ARE CSA CERTIFIED.




LISTED
47FL



CERTIFIED

CATALOG NUMBER	COPPER CONDUCTOR			APPROXIMATE DIMENSIONS - INCHES				INSTALLATION TORQUE	
	RANGE OF EQUAL RUN & TAP		MIN. TAP WITH ONE MAX RUN						
	MIN.	MAX	A	B	C	D			
SBC8-C	10 STR	8 STR	16 STR	0.14	0.39	0.55	0.86	80	
SBC6S-C	8 STR	6 STR	16 STR	0.16	0.41	0.62	0.95	165	
*SBC6SL-C	8 STR	6 STR	16 STR	0.17	0.41	0.63	1.10	165	
SBC4S-C	8 STR	6 STR	14 STR	0.21	0.45	0.69	0.98	165	
*SBC4SL-C	8 STR	6 STR	14 STR	0.22	0.45	0.69	1.30	165	
SBC3-C	8 STR	4 STR	14 STR	0.27	0.58	0.81	1.16	275	
SBC2-C	6 STR	2 STR	14 STR	0.31	0.59	0.86	1.23	275	
SBC1/0-L	4 STR	1/0 STR	14 STR	0.37	0.75	0.93	1.55	385	
SBC2/0-Q	2 STR	2/0 STR	14 STR	0.42	0.79	1.05	1.72	385	
SBC3/0-Q	1 STR	3/0 STR	8 STR	0.53	0.95	1.24	2.07	500	
SBC250-Q	1 STR	250 kcmil	8 STR	0.58	1.03	1.36	2.09	650	
SBC350-1	2/0 STR	350 kcmil	1/0 STR	0.70	1.16	1.48	2.42	650	
SBC500-1	300 kcmil	500 kcmil	2/0 STR	0.81	1.33	1.74	2.83	825	

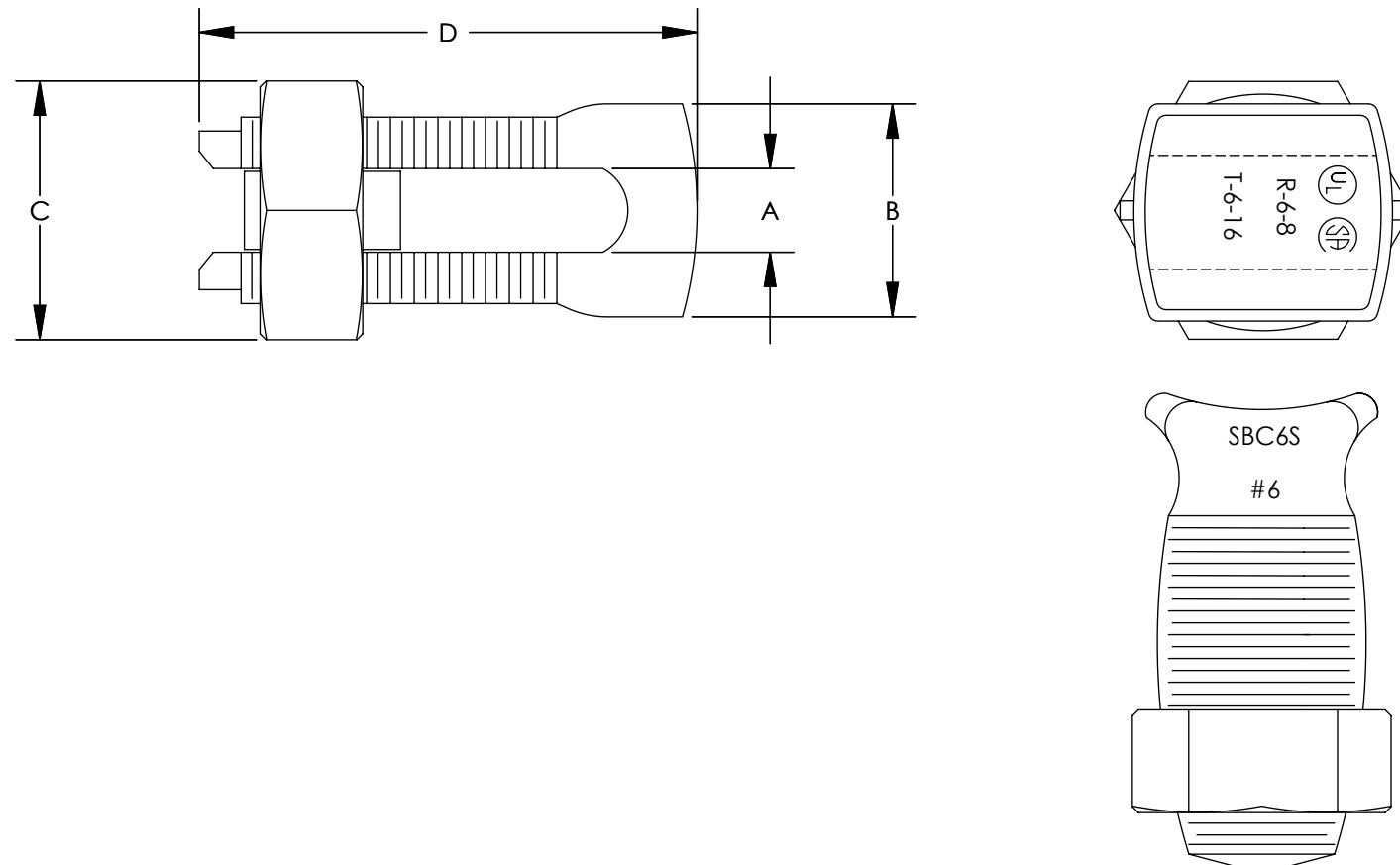

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[SBC4SL-C](#) [SBC6SL-C](#) [SBC8-C](#) [SBC3-C](#) [SBC6S-C](#) [SBC250-Q](#) [SBC3/0-Q](#) [SBC350-1](#) [SBC2/0-Q](#)