



Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	4 AWG, 3 AWG & 2 SOL
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-1/8 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	N/A
Panduit Color Code on Barrel	GRAY
Panduit Die Index No. on Barrel	P29
Alternate Industry Die Index No. () on Barrel	(8)

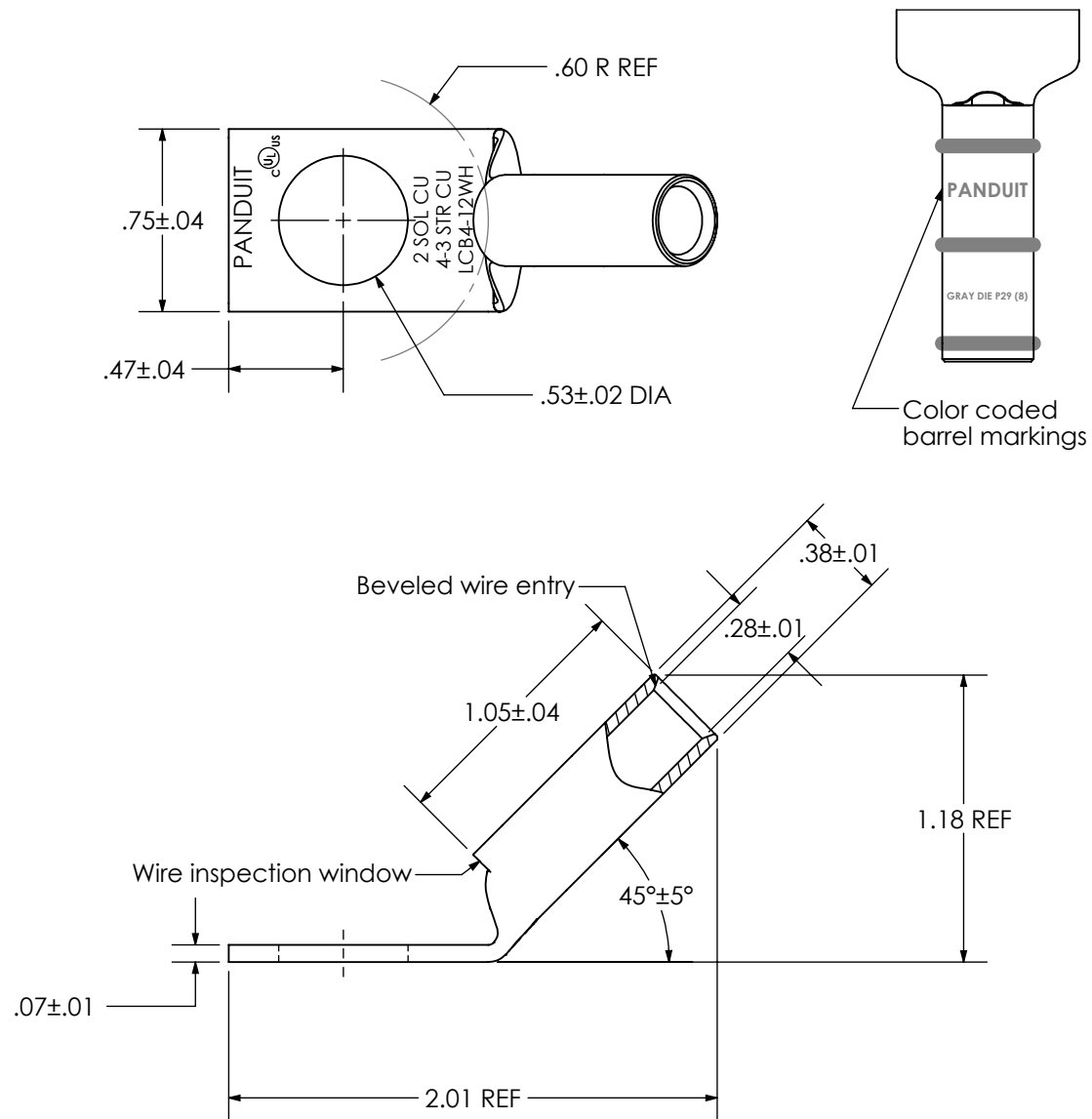

								 PANDUIT CORP. TINLEY PARK, ILLINOIS	
								LCB4-12WH-L Copper Lug - One-Hole, Long Barrel with Window, 45° Angle Tongue	
00	4/17	JHNU	JHNU	DRAWING RELEASED	021775	RGB	RGB		
REV	DATE	BY	CHK	DESCRIPTION	ECN	-R	SUP	SCALE N/A	DRAWING NO / CAD FILE LCB4-12WH-CUST

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[LCB4-12WH-L](#)