

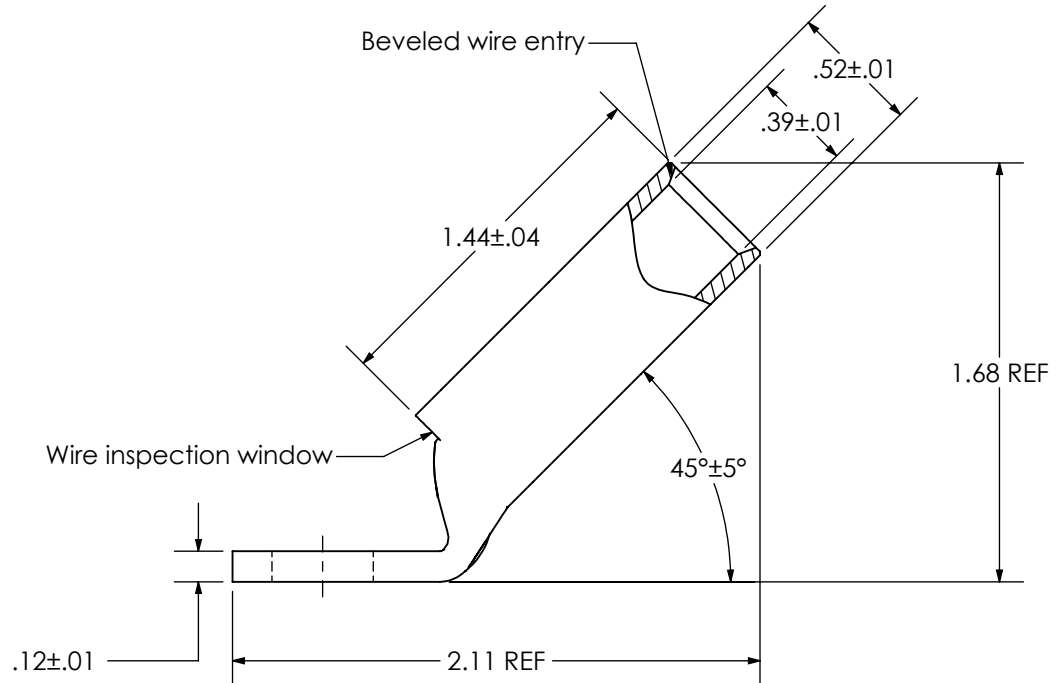


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	1/0 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-1/2 in.
Stud Size	3/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	PINK
Panduit Die Index No. on Barrel	P42
Alternate Industry Die Index No. () on Barrel	(12)

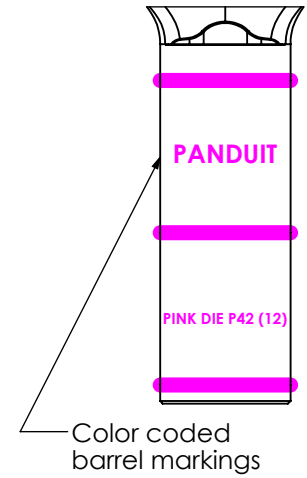

LISTED
Wire Connector

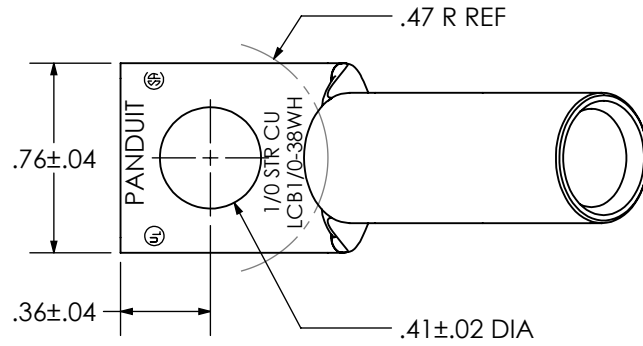

00	4/17	JHNU	JHNU
REV	DATE	BY	CHK

DRAWING RELEASED

DESCRIPTION

019765

ECN

RGB

-R

RGB

SUP

SCALE N/A

DRAWING NO / CAD FILE

LCB1_0-38WH-CUST

PANDUIT

CORP. TINLEY PARK, ILLINOIS

LCB1/0-38WH-X
Copper Lug - One-Hole, Long Barrel with Window, 45° Angle Tongue

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[LCB1/0-38WH-X](#)