

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.


| | |
|--|--|
| Material | High Conductivity Seamless Copper Tube |
| Plating | Electro-Tin |
| Wire Size | 1000 kcmil |
| Wire Type | Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric |
| Wire Strip Length | 3-1/16 in. |
| Stud Size | 1/2 in. |
| UL Listed Wire Connector | Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts. |
| UL Temperature Rating | 90 ° C |
| C.S.A Certified Wire Connector | Yes |
| Panduit Color Code on Barrel | WHITE |
| Panduit Die Index No. on Barrel | P125 |
| Alternate Industry Die Index No. () on Barrel | (27) |



CERTIFIED



LISTED
Wire Connector

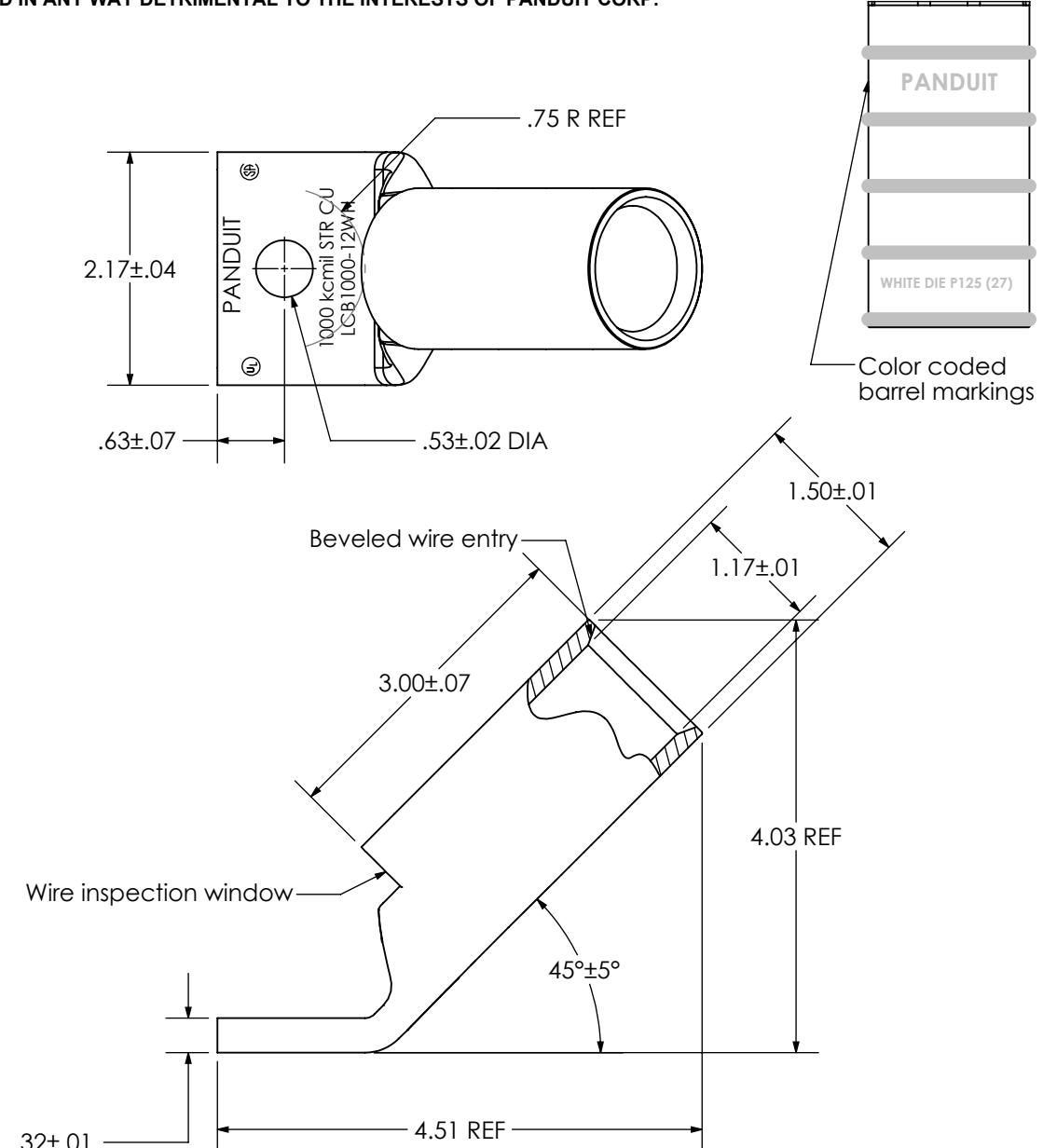

| 00 | 4/17 | JHNU | JHNU | DRAWING RELEASED | 021775 | RGB | RGB | PANDUIT | CORP. TINLEY PARK, ILLINOIS |
|-----|------|------|------|------------------|--------|-----|-----|---------|-----------------------------|
| REV | DATE | BY | CHK | DESCRIPTION | ECN | -R | RGB | SCALE | DRAWING NO / CAD FILE |
| | | | | | | | | N/A | LCB1000-12WH-CUST |

LCB1000-12WH-3
Copper Lug - One-Hole, Long Barrel with Window, 45° Angle Tongue

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

[LCB1000-12WH-3](#)